
 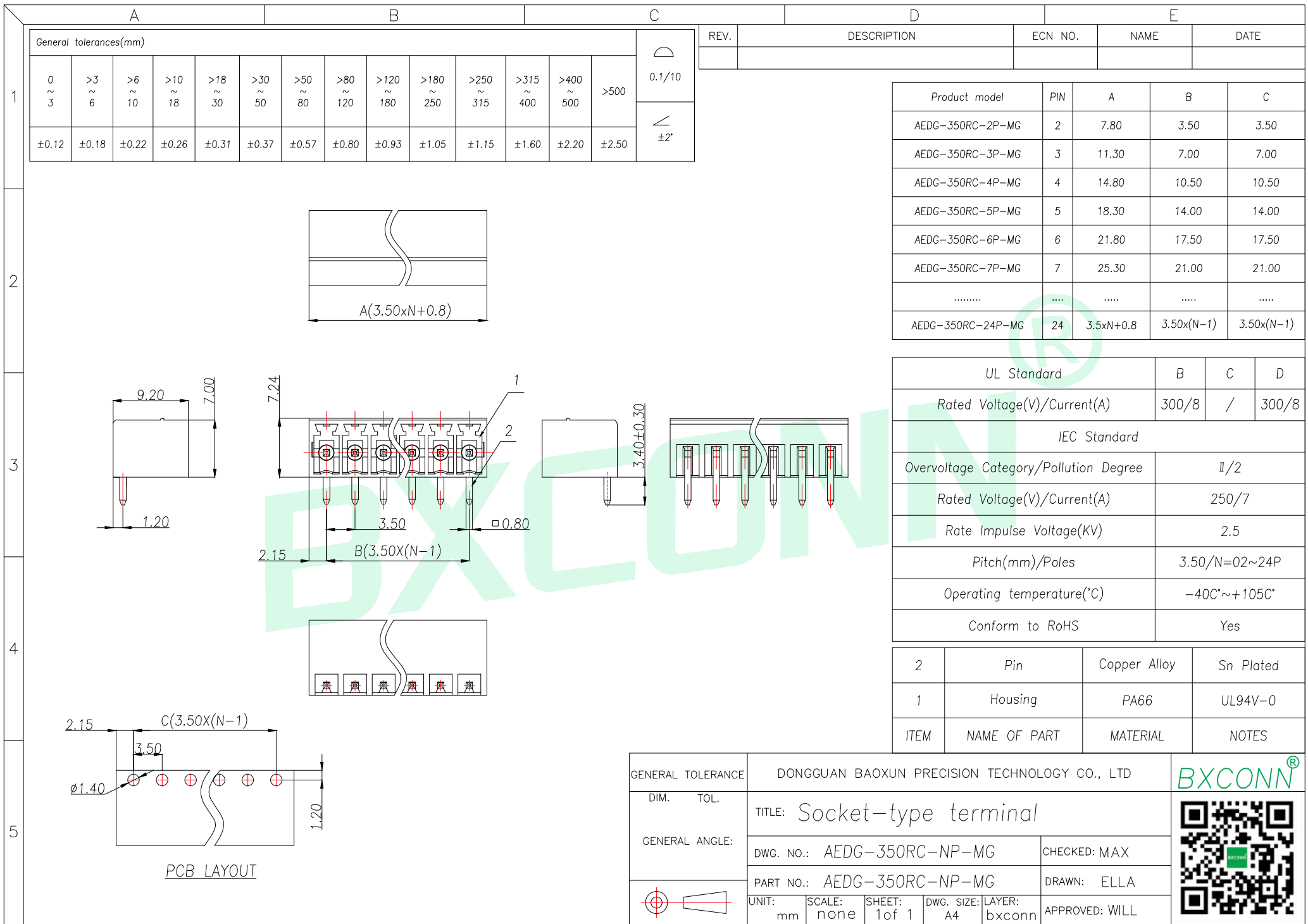




Product model	PIN	A	B	C
AEDG-350RC-2P-MG	2	7.80	3.50	3.50
AEDG-350RC-3P-MG	3	11.30	7.00	7.00
AEDG-350RC-4P-MG	4	14.80	10.50	10.50
AEDG-350RC-5P-MG	5	18.30	14.00	14.00
AEDG-350RC-6P-MG	6	21.80	17.50	17.50
AEDG-350RC-7P-MG	7	25.30	21.00	21.00
.....				
AEDG-350RC-24P-MG	24	3.5xN+0.8	3.50x(N-1)	3.50x(N-1)

UL Standard	B	C	D
Rated Voltage(V)/Current(A)	300/8	/	300/8
IEC Standard			
Overvoltage Category/Pollution Degree	II/2		
Rated Voltage(V)/Current(A)	250/7		
Rate Impulse Voltage(KV)	2.5		
Pitch(mm)/Poles	3.50/N=02~24P		
Operating temperature(°C)	-40C°~+105C°		
Conform to RoHS	Yes		

2	Pin	Copper Alloy	Sn Plated
1	Housing	PA66	UL94V-0
ITEM	NAME OF PART	MATERIAL	NOTES

GENERAL TOLERANCE		DONGGUAN BAOXUN PRECISION TECHNOLOGY CO., LTD					BXCONN[®] 	
DIM. TOL.		TITLE: Socket-type terminal						
GENERAL ANGLE:		DWG. NO.: AEDG-350RC-NP-MG			CHECKED: MAX			
		PART NO.: AEDG-350RC-NP-MG			DRAWN: ELLA			
		UNIT:	SCALE:	SHEET:	DWG. SIZE:	LAYER:		
		mm	none	1 of 1	A4	bxconn		