
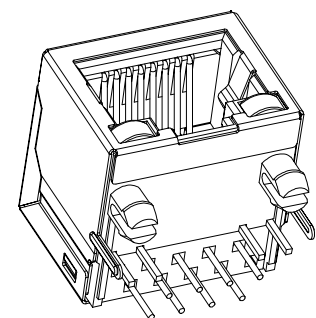
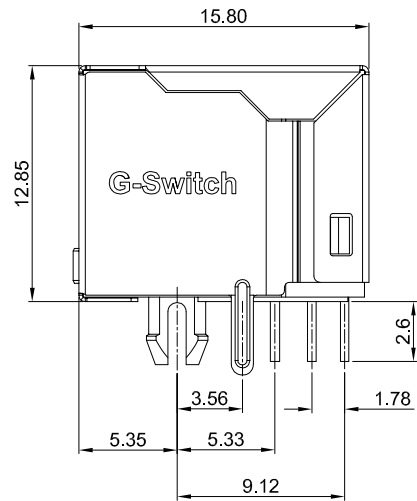



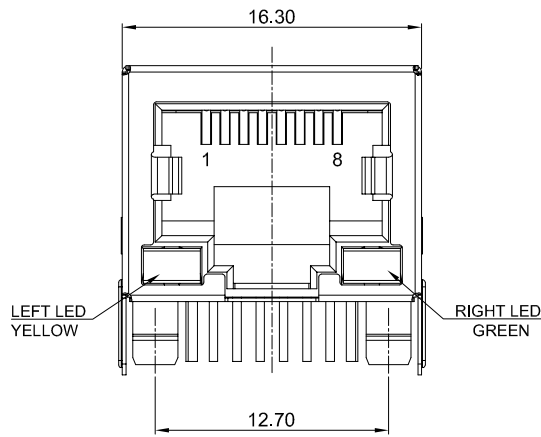


GT - RJ45 S L 00 - 004 A

G-Switch Series RJ45 Shield S=Shield Light L=with led

Serial code 00=Au G/F

Contact Plated 00=Au G/F

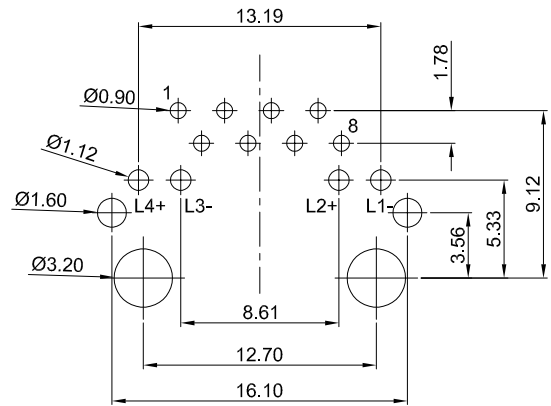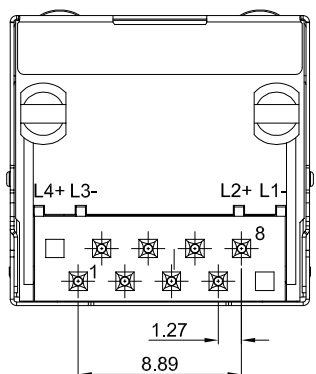

G-Switch Specification:

- 1.Current rating: 1.5A
- 2.Voltage rating: 125V AC RMS.
- 3.Insulation resistance: 500MQ min
- 4.Contact resistance: 40mΩ max
- 5.Dielectric strength: 500 megohms min @ 100V DC
- 6.Durability: 750 cycles
- 7.Operating temperature range: -40°C ~ +85°C

1	SHELL	COPPER ALLOY	NI PLATED
2	HOUSING	HIGH TEMPERATURE PLASTIC	BLACK UL 94V-0
3	TERMINALS	PHOSPHOR BRONZE	G/F PLATED ON CONTACT AREA Tin PLATED ON SOLDER AREA
NO.	PARTS	MATERIAL	REMARKS



SCALE: 1:1	UNIT: mm	Title: Horizontal RJ45 Conn 8P8C DIP 16.30×12.85×L15.80mm			
SIZE: A4		Molde Code: GT-RJ45SL00-004A			
Unless otherwise General tolerance: X. ±0.40 X.x ±0.30 X.xx ±0.20 Angles ±3°		DRAWN	CHECKED	APPROVED	DATE
		Wu	Xla	Chen	2025.04.10
		REV:	A0	SHEET: 1/1	

