

Φ10.0mm NFC 1.0uH Antenna

FEATURES



- Operating Frequency: 13.56 MHz
- RF Power: 2W
- RoHS: Yes
- Operating Temperature: -40 to +85°C




PRODUCTS

Part No.	Weight	Dimensions (L x WxH)	Color
AINM003	0.04g	Φ 10x0.32mm	Golden


SPECIFICATIONS

PARAMETER	SPECIFICATION
Frequency Bands, MHz	13.56MHz
Nominal Impedance	50 Ω
Max Power (ambient temp of 25°C)	10 Watts
Color	Black
Storage Temperature Range (°C)	-40° C to +85° C
Operational Temperature Range (°C)	-40° C to +85° C
Material Substance Compliance	REACH/RoHS Compliant

ELECTRICAL DATA

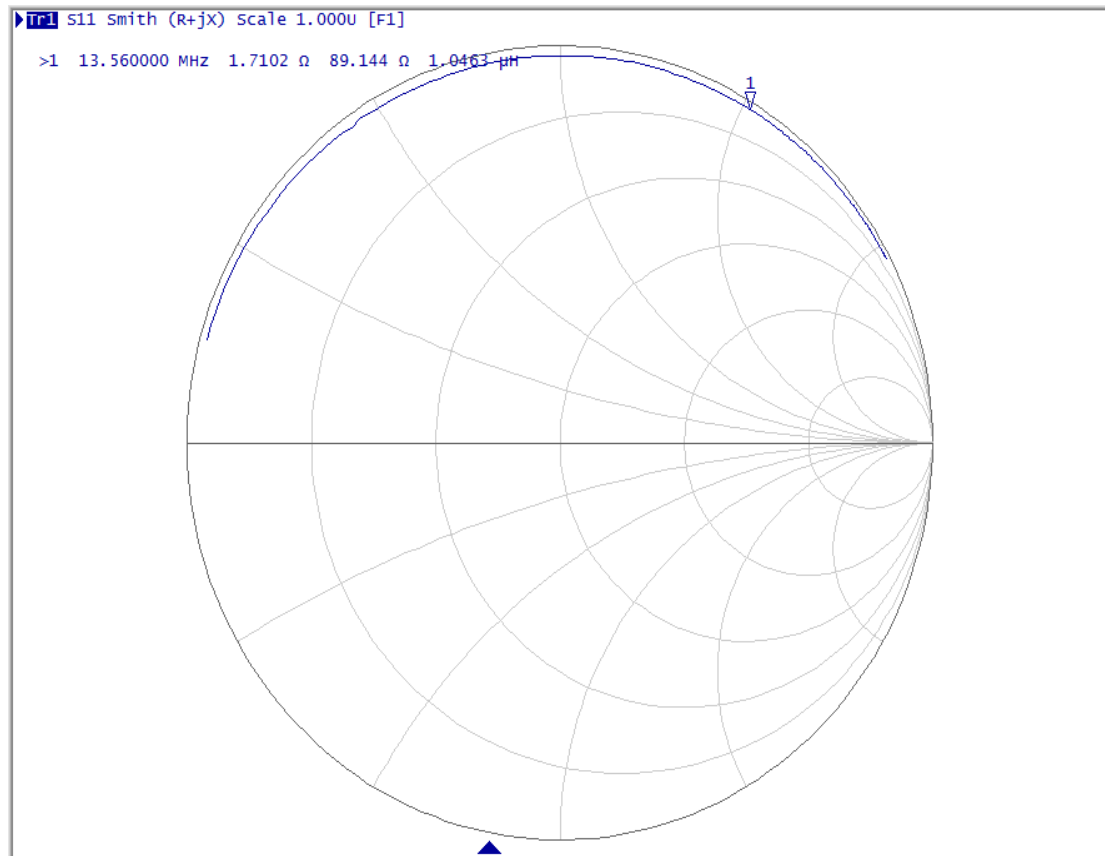

HOUSING CONFIGURATIONS

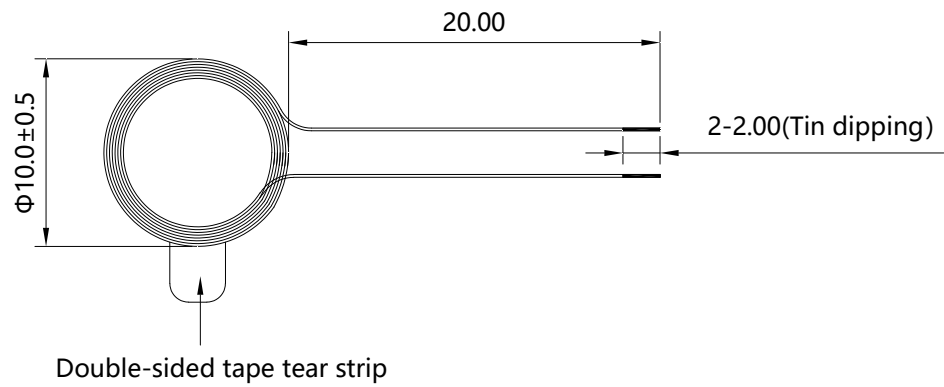

Aboosty™ is owned by Shenzhen MyAntenna RF Technology Co., Ltd. (often abbreviated as MyAntenna).