

Operation:DIP/卧插式 2.5Ø中型 三段音频连接器



ITEM NO.:PJ-205B (Series)

(L12.0×W9.0×H4.0mm 2.5 PHONE-JACK)

插件卧式 DIP

側向操作

精密部品

带导向柱

適合環保 RoHS


Technical parameter

PROJECT	LEVEL	A[better product]	B[average product]
Electrical Properties	Contact Rating	0.5A, 24V DC	
	Initial Contact Resistance	50mΩ max.	
	Insulation Resistance	100MΩ min.500V DC Skey/PD: 100MΩ min.300V DC	
	Withstand Voltage	500V AC for 1 minute	350 V AC for 1 minut
	There No Load	6,000 Cycles	5,000 Cycles
Durable Performance	Rated Load	5,000 Cycles	4,000 Cycles
	Storage temp.	-35℃~+75℃(Operating Temp:)	
	Operating Force	IF:5~15N MAX. (EF:10.0N MIN.)	
	Heat Rrsistance	225℃, 5sec. Manual: 350℃, 3sec.	


Material declaration

No	NAME	Description
①	接觸端子#1	C5191R-H (t=0.20mm)磷銅[鍍基銀]
②	接觸端子#2	C5191R-H (t=0.30mm)磷銅[鍍基銀]
③	接觸端子#3	C5191R-H (t=0.30mm)磷銅[鍍基銀]
④	接觸端子#4	C5191R-H (t=0.30mm)磷銅[鍍基銀]
⑤	接觸端子#5	C5191R-H (t=0.20mm)磷銅[鍍基銀]
⑥	基座 2	PPA (Black)耐熱塑膠
⑦	基座 1	PPA (Black)耐熱塑膠

CIRCUIT DIAGRAM

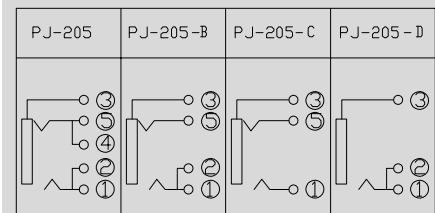

Unit:mm

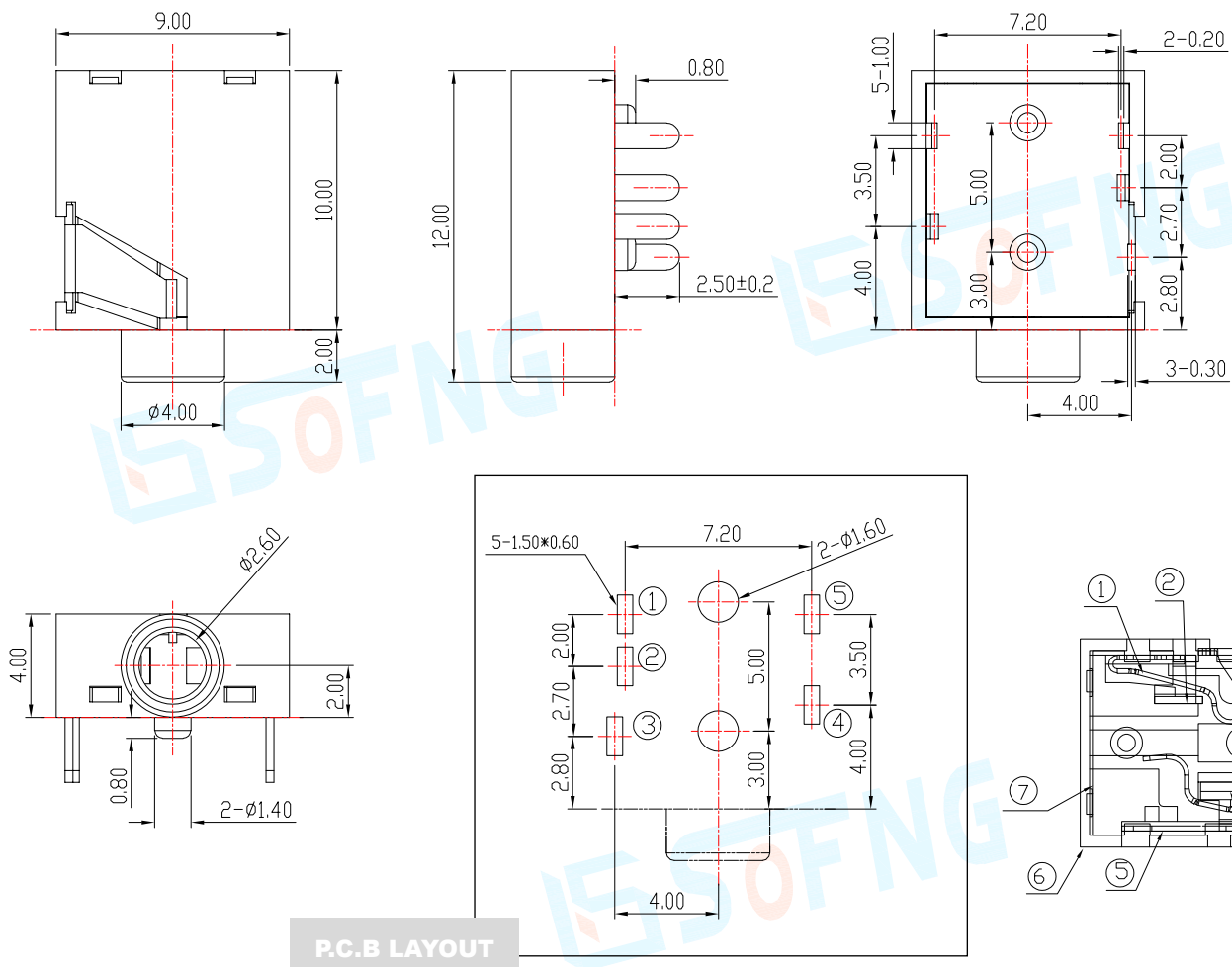

P.C.B LAYOUT

