

Operation: DIP/立插式 2.54mm 间距中型编码开关[1-12Positions]



ITEM NO.:D3-006-254 (Series)

(W6.2×H3.2mm CODIN SWITCH)

表面插装 DIP

正向操作

精密部品 NICETY


可靠 STABILIZE

適合環保 RoHS



Technical parameter

PROJECT	LEVEL	A[better product]	B[average product]
Electrical Properties	Contact Rating	0.25A, 24V DC	
	Initial Contact Resistance	50mΩ max.	
	Insulation Resistance	100MΩ min.500V DC Skey/PD: 100MΩ min.300V DC	
	Withstand Voltage	500V AC for 1 minute	350 V AC for 1 minut
Durable Performance	There No Load	3,500 Cycles	2,500 Cycles
	Rated Load	2,500 Cycles	2,000 Cycles
	Storage temp.	-40℃~+85℃(Operating Temp:)	
	Operating Force	10N MAX. (1N.=100gram-force)	
	Heat Rrsistance	IR Reflow:255℃, 5sec. Manual:350℃, 3sec.	



CIRCUIT DIAGRAM

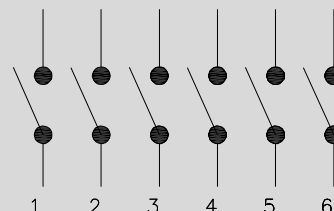

Unit:mm

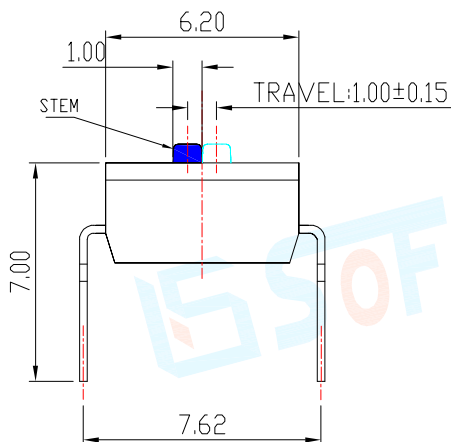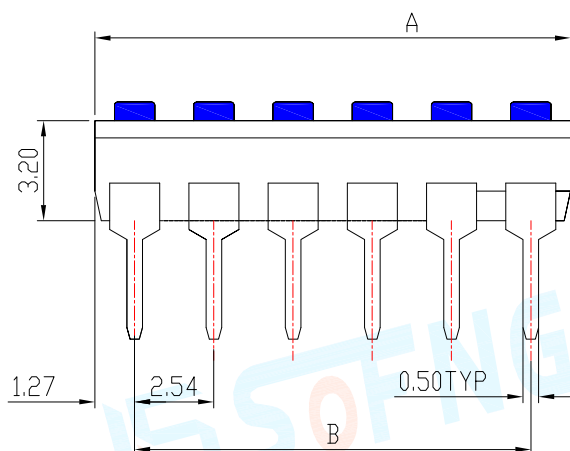

PART NO.	NO.OF POS.	DIM.A	DIM.B
D3-001	1	2.54	
D3-002	2	5.08	2.54
D3-003	3	7.62	5.08
D3-004	4	10.16	7.62
D3-005	5	12.70	10.16
D3-006	6	15.24	12.70
D3-007	7	17.78	15.24
D3-008	8	20.32	17.78
D3-009	9	22.86	20.32
D3-010	10	25.40	22.86
D3-012	12	30.48	27.94

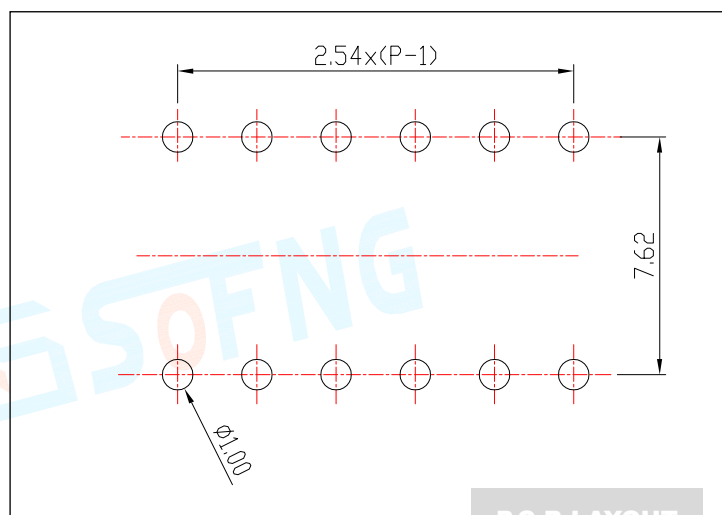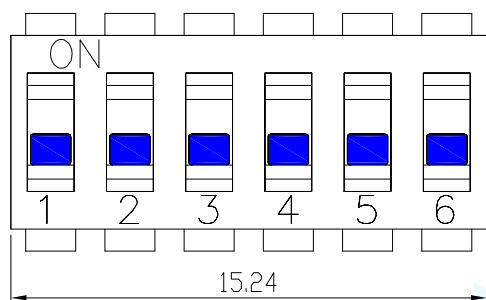

P.C.B LAYOUT

DECIMALS	ANGLES
.X :±0.25	X.° :±1.5°
.XX :±0.15	X.X° :±1.0°
.XXX :±0.10	.XXX° :±0.5°