

Operation: DIP/卧插式 2.5 Ø 中型 三段音频连接器



ITEM NO.: PJ-218A (Series)

(L11.6×W5.0×H4.0mm 2.5 PHONE-JACK)

插件卧式 DIP

側向操作

精密部品

带导向柱

適合環保 RoHS


Technical parameter

LEVEL		A[better product]	B[average product]
PROJECT			
Electrical Properties	Contact Rating	0.5A, 24V DC	
	Initial Contact Resistance	50mΩ max.	
	Insulation Resistance	100MΩ min.500V DC Skey/PD: 100MΩ min.300V DC	
Durable Performance	Withstand Voltage	500V AC for 1 minute	350 V AC for 1 minut
	There No Load	6,000 Cycles	5,000 Cycles
	Rated Load	5,000 Cycles	4,000 Cycles
	Storage temp.	-35℃~+75℃(Operating Temp:)	
	Operating Force	IF:5~15N MAX. (EF:10.0N MIN.)	
	Heat Rrsistance	225℃, 5sec. Manual: 350℃, 3sec.	

Material declaration

No	NAME	Description
①	基座	PBT (Black)耐热塑胶
②	接觸端子#2	C5191R-H (t=0.20mm)磷铜[鍍基銀]
③	接觸端子#3	C5191R-H (t=0.20mm)磷铜[鍍基銀]
④	接觸端子#4	C5191R-H (t=0.20mm)磷铜[鍍基銀]
⑤	接觸端子#5	C5191R-H (t=0.20mm)磷铜[鍍基銀]

CIRCUIT DIAGRAM

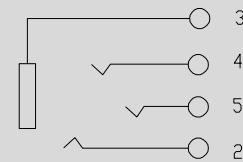

Unit:mm

