


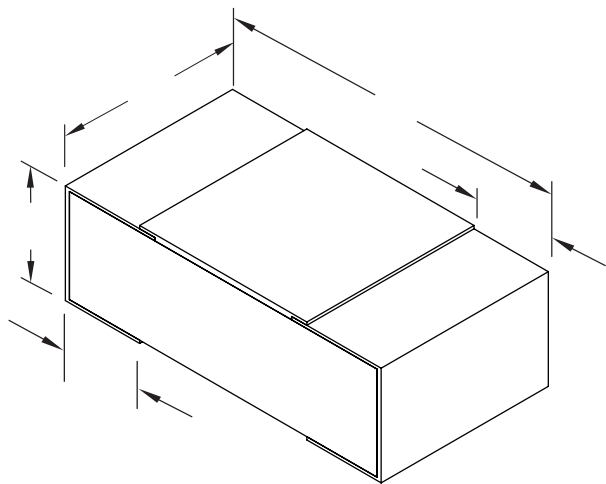

Click [here](#) for the 3D model.

General Information	
供应商	YAGEO
类别	RP
样式	SMD Chip
描述	Automotive Grade Thin Film Chip
RoHS	Yes
端子	Tin
认证	AEC-Q200
Chip Size / Footprint	0402 / 1005

Specifications	
阻值	25.5 kOhms
电阻容差	0.1%
功率	0.063 W (70C)
温度系数	-/+25 ppm/C
温度范围	-55/+155°C
直流电压	50 V (Max Continuous Voltage at Full Rated Power), 100 Max Over Voltage

Dimensions	
L	1mm +/-0.1mm
W	0.5mm +/-0.05mm
T	0.3mm +/-0.05mm
B1	0.2mm +/-0.1mm
B2	0.25mm +/-0.1mm

Packaging Specifications	
包装	T&R, 178mm, Paper Tape
包装数量	10000

Statements of suitability for certain applications are based on our knowledge of typical operating conditions for such applications, but are not intended to constitute - and we specifically disclaim - any warranty concerning suitability for a specific customer application or use. This Information is intended for use only by customers who have the requisite experience and capability to determine the correct products for their application. Any technical advice inferred from this Information or otherwise provided by us with reference to the use of our products is given gratis, and we assume no obligation or liability for the advice given or results obtained.