


客户图

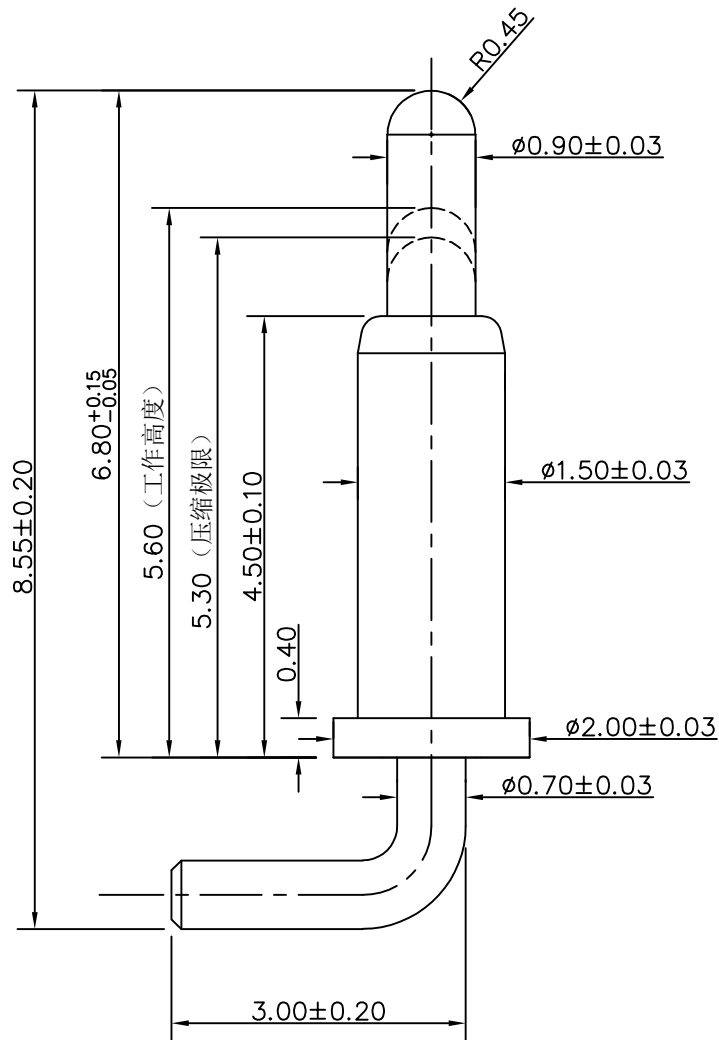

- Note:
- 1: Material(材料):
Barrel: Brass C3602 (针管: 黄铜 C3602)
Plunger: Brass C6801 (针头: 无铅铜 C6801)
Spring: SUS304 (弹簧: SUS304)
 - 2: Plating(电镀):
Barrel: 3u' Au over 50~100u' Cu over 60~120u' Ni
(针管: 镀金3u', 铜底50~100u', 镍底60~120u'.)
Plunger: 3u' Au over 50~100u' Cu over 60~120u' Ni
(针头: 镀金3u', 铜底50~100u', 镍底60~120u'.)
Spring: Gold plated (弹簧: 镀金)
 - 3: Electrical(电气特性):
Rated Current & Voltage: DC 12V;1A (额定电压&电流: 直流12V,1A)
Contact Resistance: 50 mohm Max. at working height.
接触电阻: 最大50毫欧 (在工作高度状态下)
 - 4: Mechanical(机械性能):
Force: 100g±20% at working height. (100g±20% 在工作高度)。
Durability: 10.000 cycles(min) (寿命: 10000次)
 - 5: WorkTemperture(工作环境):
Withstanding Higt Temperature: 280℃
Operational Temperature: -20℃~ +70℃

深圳市鑫扬泽电子有限公司

HTTP://WWW.XYZPOGOPIN.COM

TEL:0755-28773277 FAX:0755-28891353



SCALE:	N/A	UNIT	mm	THE UNMARKED TOLERANCE ARE AS BELOW :				DESIGNED BY:		DWG. NO.	YZB0093-20086-01
SHEET:	1 of 1	PROJECTION		LENGTH		ANGLE		CHECKED BY:		TITLE:	Pogo pin连接器
DATE:	2023.7.31	VER.	D.0	X.XX ±0.05mm	X.XX ±0.50°	X.X ±0.10mm	X.X ±1.00°	APPROVED BY:			
				X. ±0.20mm	X. ±2.00°						