

A

B

C

D

E





A

B

C

D

E

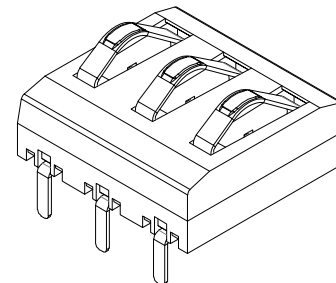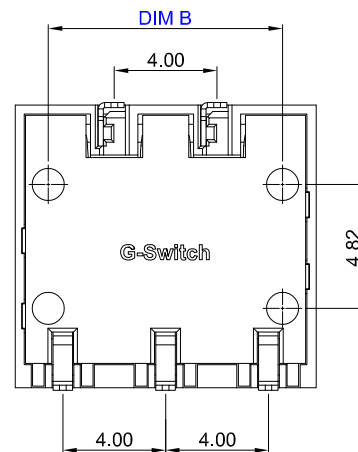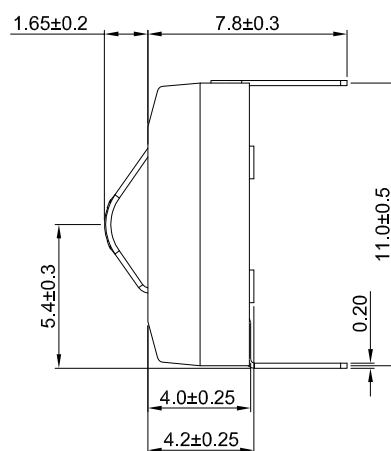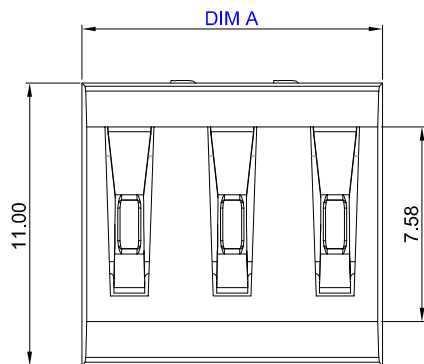

GT-BT P 400 XX - 0400 B - 038 C

G-Switch

Series
BT: Battery

Type
P: Plug

Pitch
400=4.00




Pin Q' PY
02~06Pin

Height
0400=4.00

Detail

Serial code

Detail
B:No column

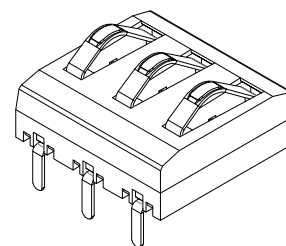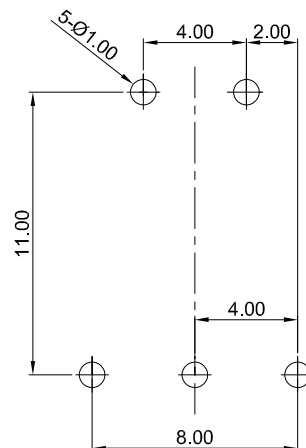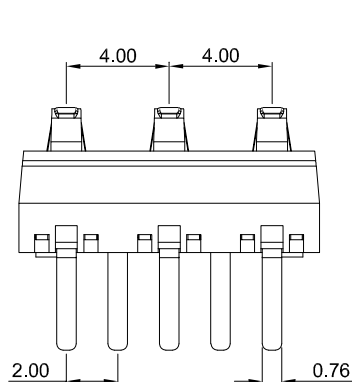

G-Switch Specification:

- 1.Current rating: 3A/Pin
- 2.Rated Voltage: 30V DC
- 3.Insulation resistance: 500MQ min
- 4.Contact resistance: 30mΩ max
- 5.Dielectric strength: 500V RMS
- 6.Durability: 5,000cycles
- 7.Operating temperature range: -55°C ~ +125°C

3	FIXED PIECE	COPPER ALLOY	Tin OVERALL
2	CONTACT	C5210	Au5u" ON CONTACT AREA
1	HOUSING	PA9T,94V-0	BLACK
NO.	PART NAME	MATERIAL	REMARK

Ordering Information:

Circuit	Dimensions(mm)	
	DIM A	DIM B
02P	7.70	5.11
03P	11.70	9.11
04P	15.70	13.11
05P	19.70	17.11
06P	23.70	21.11



SCALE: 1:1 UNIT: mm
SIZE: A4

Unless otherwise
General Tolerance:
X ±0.40
X.x ±0.30
X.xx ±0.20
X° ±5°
X.x° ±3°

Title: Vertical Pitch4.0 Battery Conn
DIP A×11×H4.0mm

Molde Code: GT-BTP400XX-0400B-038C

DRAWN	CHECKED	APPROVED	DATE
Xla	Chen	Chen	2023.12.28

品贊科技
b-Switch
www.dg-switch.com

REV: A0 SHEET: 1/1