
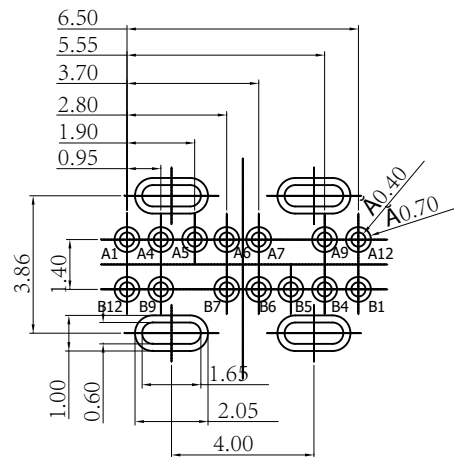
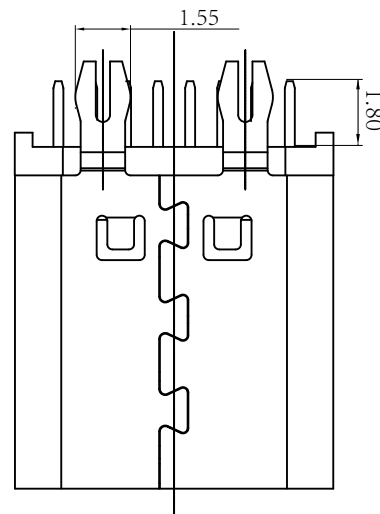
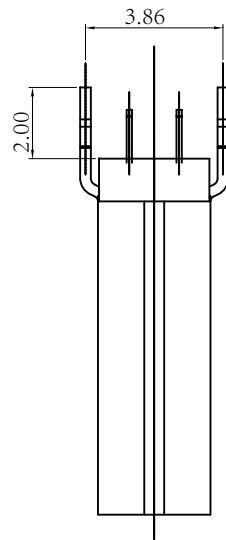
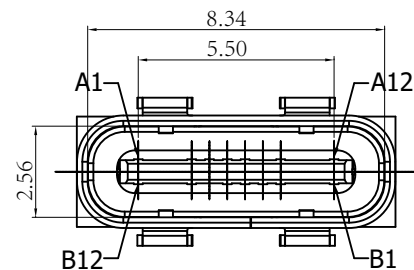
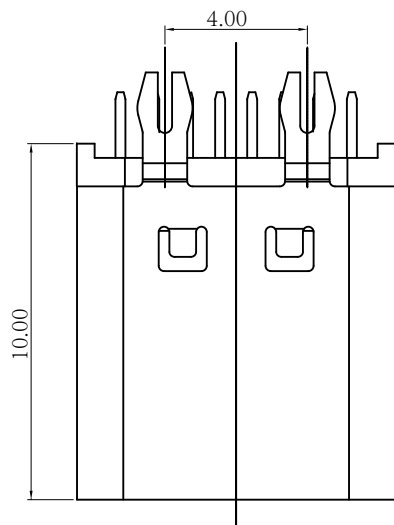


Kinghelm®

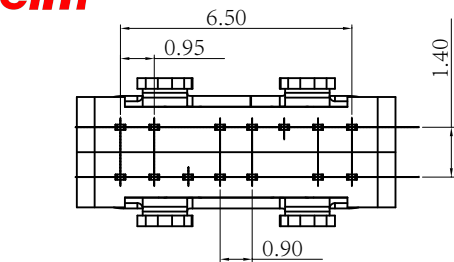

REV	DESCRIPTION	DATE	APPROVED
A/0	新版发行	2020.06.06	xiao

备注:

1. 材质:

1.1 胶芯: LCP+30%G.F UL94V-0

1.2 端子: 高导铜, T=0.15mm; 半金亮锡1 μ "

1.3 外壳: SUS304, T=0.30mm; 镀镍80 μ " MIN.

1.4 钢片: SUS301, T=0.15mm;

2. 主要特性:

2.1 额定电流: 5.0A

2.2 接触阻抗: 40MILLTOHMS MAX

2.3 绝缘阻抗: 150V DC/100 MEGA OHMS MIN

2.4 耐压测试: 100V AC/ 1MA MAX


2.5 沾锡性: 温度250±5℃, 时间5±0.5s

2.6 插入力: 5~20N 2. 拔出力: 8~20N

使用寿命: 10000次、拔出力 5N MIN

2.7 盐雾测试: 通过24H盐水盐雾无生锈现象

2.8 工作温度: -30℃~+80℃

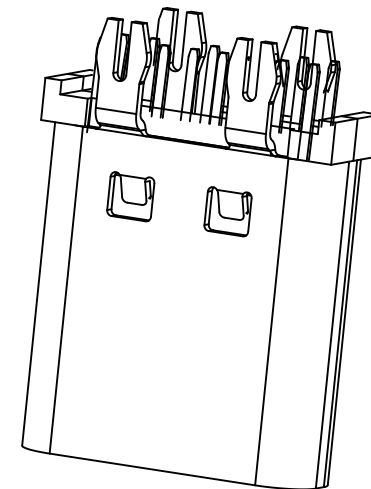

TOLERANCES		深圳市金航标电子有限公司		www.kinghelm.com.cn	
. X	±0. 30				
. XX	±0. 20	KH-TYPE-C-L10-14P		0755-28190160	
. XXX	±0. 10				
ANGLES ±2. 00°					
APPROVED: TZ120		TITLE: TYPE-C 14P 180度立插 L=10. 0			
CHECKED: TZ101		PART NO. :			PROJECTION: 
DRAWING: TZ125		REV. : A/0	SIZE: A4	UNIT: M M	SCALE: 1:1 SHEET: 1/1