

为 您 的 产 品 保 驾 护 航

PRODUCT DATASHEET

Blade Fuses

0891 Low Profile Mini Blade Fuse Devices



Description

The 0891 Low Profile Mini Blade Fuses standard applies to vehicle series fuses below 32V.

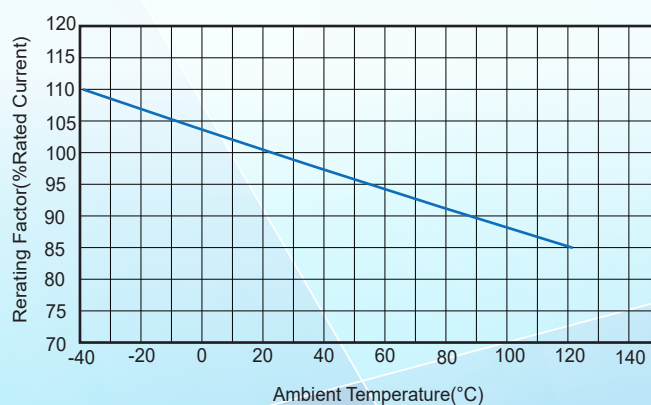
Performance Specification

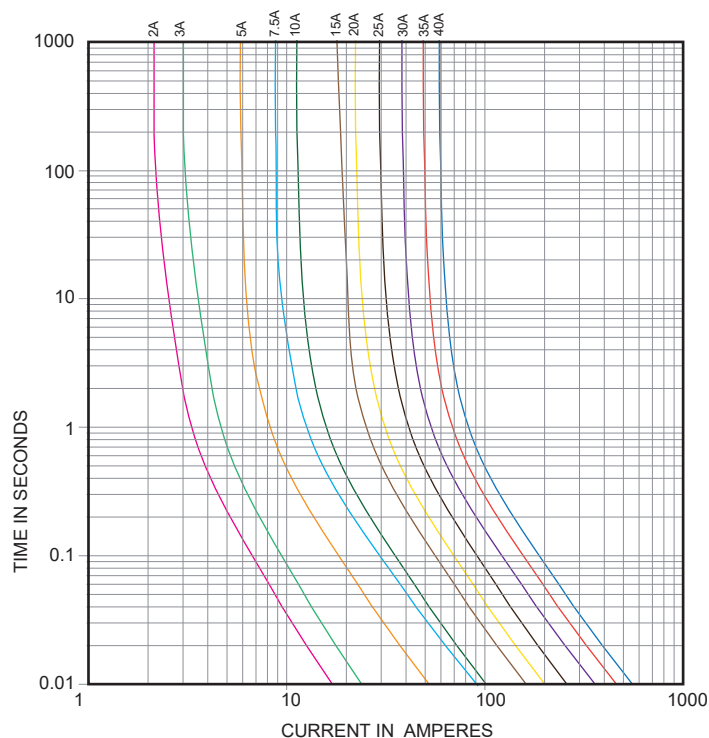
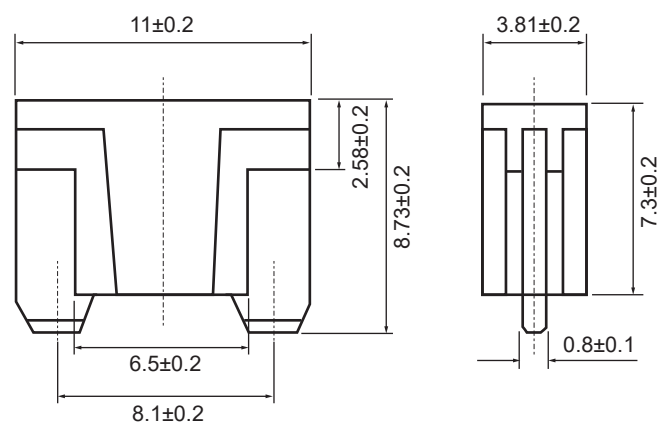
Model	Current Rating (A)	Interrupting Rating	Voltage Rating	Max.Voltage Drop(mV)	Cold Resistance (mΩ)	Housing Material Color
0891002.J	2.0	1000A @32VDC	32V DC	200	36.6	灰色
0891003.J	3.0			175	31.24	深紫色
0891005.J	5.0			175	17.0	橙色
089107.5J	7.5			150	11.3	褐色
0891010.J	10.0			125	8.60	红色
0891015.J	15.0			125	6.25	浅蓝色
0891020.J	20.0			125	4.50	黄色
0891025.J	25.0			110	3.67	透明色
0891030.J	30.0			100	3.10	浅绿色
0891035.J	35.0			90	2.75	紫色
0891040.J	40.0			85	2.43	酒红色

Time-Current Characteristics

% of Rating	Opening Time
110%	4h min
135%	0.75s~1800s
200%	0.15s~5s
350%	0.04s~0.5s
600%	0.02s~0.1s

Temperature Derating Curve



Time-Current Characteristic Curves

Dimensions (mm)

Specification

Operating Temperature	Terminals	Housing Material
$-40^{\circ}\text{C} \sim +105^{\circ}\text{C}$	zinc alloy	PC

Packaging Quantity

Model	QTY
0891 Series	1000 pcs/bag