
 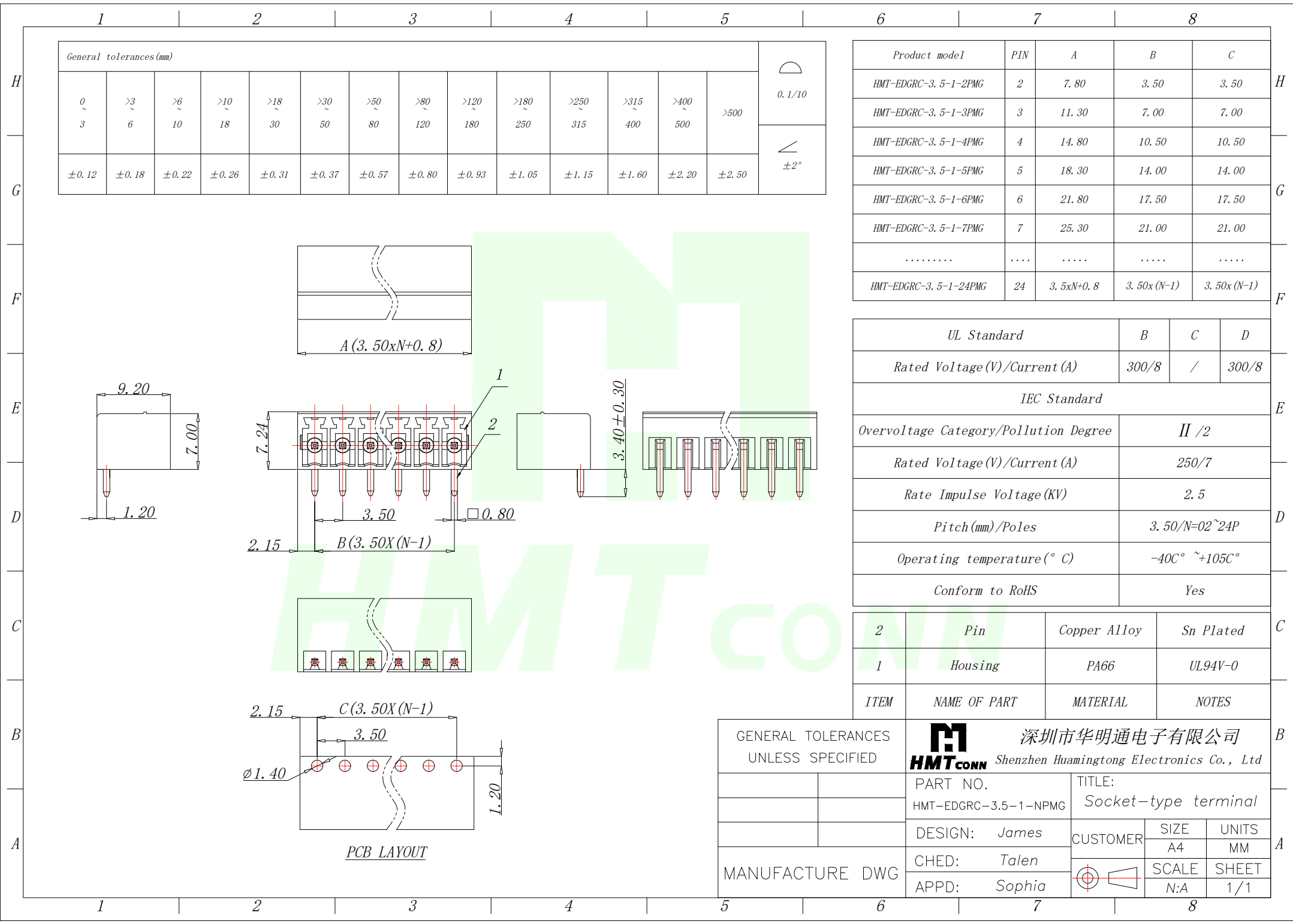




Product model	PIN	A	B	C
HMT-EDGRC-3.5-1-2PMG	2	7.80	3.50	3.50
HMT-EDGRC-3.5-1-3PMG	3	11.30	7.00	7.00
HMT-EDGRC-3.5-1-4PMG	4	14.80	10.50	10.50
HMT-EDGRC-3.5-1-5PMG	5	18.30	14.00	14.00
HMT-EDGRC-3.5-1-6PMG	6	21.80	17.50	17.50
HMT-EDGRC-3.5-1-7PMG	7	25.30	21.00	21.00
.....				
HMT-EDGRC-3.5-1-24PMG	24	3.5xN+0.8	3.50x(N-1)	3.50x(N-1)

UL Standard	B	C	D
Rated Voltage (V)/Current (A)	300/8	/	300/8
IEC Standard			
Overvoltage Category/Pollution Degree	II /2		
Rated Voltage (V)/Current (A)	250/7		
Rate Impulse Voltage (KV)	2.5		
Pitch (mm)/Poles	3.50/N=02~24P		
Operating temperature (° C)	-40C° ~+105C°		
Conform to RoHS	Yes		

2	Pin	Copper Alloy	Sn Plated
1	Housing	PA66	UL94V-0
ITEM	NAME OF PART	MATERIAL	NOTES

GENERAL TOLERANCES UNLESS SPECIFIED		 深圳市华明通电子有限公司 Shenzhen Huamingtong Electronics Co., Ltd	
	PART NO.	TITLE:	
	HMT-EDGRC-3.5-1-NPMG	Socket-type terminal	
	DESIGN: James	CUSTOMER	SIZE
	CHED: Talen		UNITS
MANUFACTURE DWG	APPD: Sophia		A4
			MM
		SCALE	SHEET
		N:A	1/1