


为 您 的 产 品 保 驾 护 航

PRODUCT DATASHEET

Blade Fuses

0327 Micro2 Blade Fuse Devices

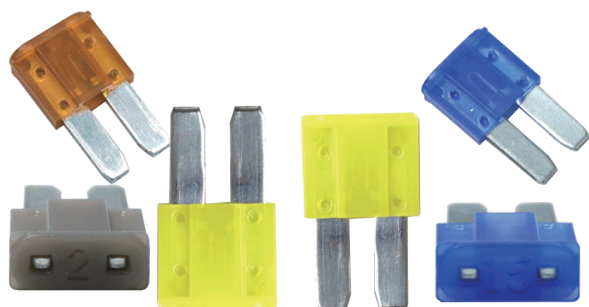

Description

The 0327 Micro2 Blade Fuses standard applies to vehicle series fuses below 32V.


Performance Specification

Model	Current Rating (A)	Interrupting Rating	Voltage Rating	Max.Voltage Drop(mV)	Cold Resistance (mΩ)	Housing Material Color
0327002.J	2.0	1000A @32VDC	32V DC	200	36.6	灰绿色
0327003.J	3.0			175	31.24	玫红色
0327005.J	5.0			175	17.0	黄褐色
032707.5J	7.5			150	11.3	茶色
0327010.J	10.0			125	8.60	红色
0327015.J	15.0			125	6.25	蓝色
0327020.J	20.0			125	4.50	黄色
0327025.J	25.0			110	3.67	透明色
0327030.J	30.0			100	3.10	绿色
0327035.J	35.0			90	2.75	紫色
0327040.J	40.0			85	2.43	粉红色

Time-Current Characteristics



% of Rating	Opening Time
110%	4h min
135%	0.75s~1800s
200%	0.15s~5s
350%	0.04s~0.5s
600%	0.02s~0.1s

Temperature Derating Curve

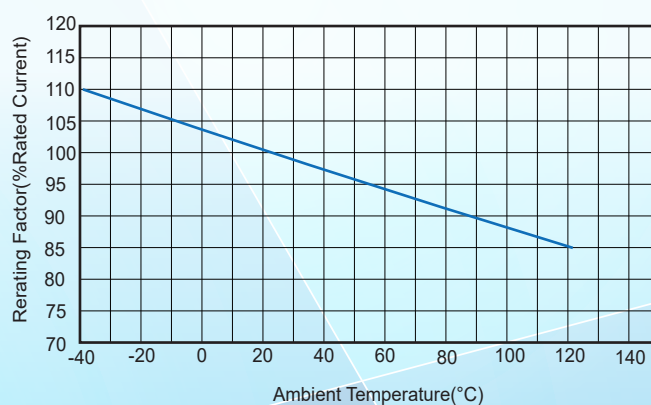

Time-Current Characteristic Curves

Dimensions (mm)

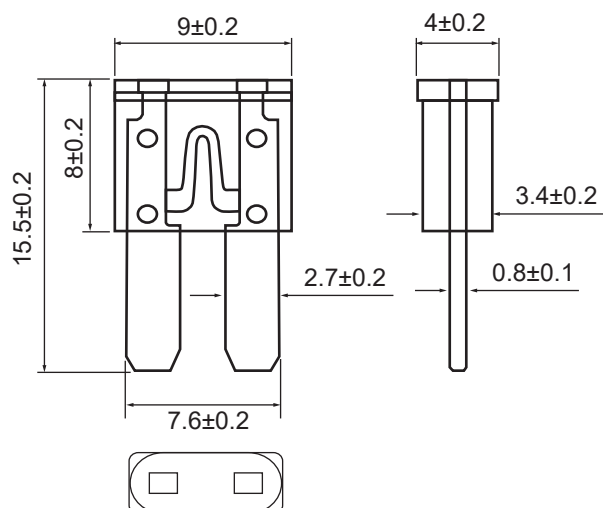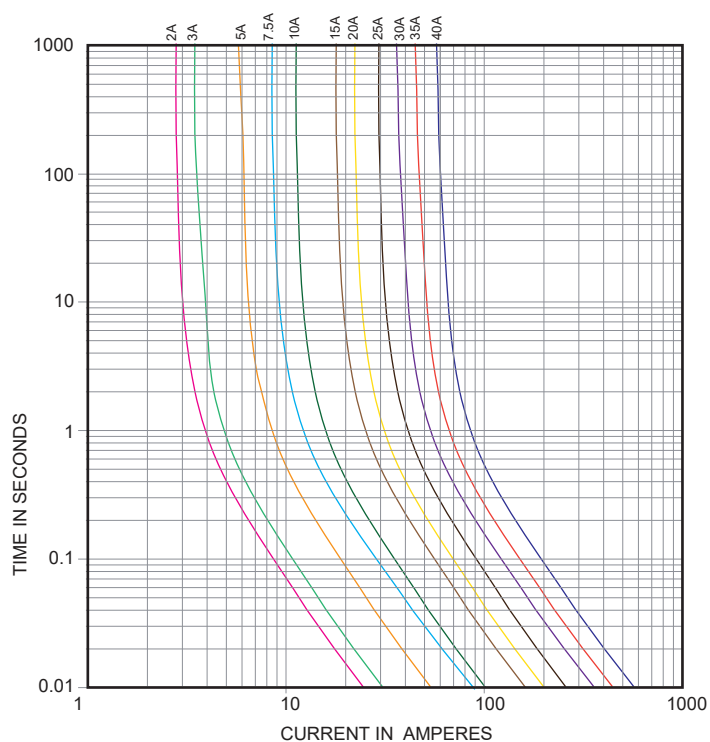

Specification

Operating Temperature	Terminals	Housing Material
$-40^{\circ}\text{C} \sim +105^{\circ}\text{C}$	zinc alloy	PC

Packaging Quantity

Model	QTY
0327 Series	1000 pcs/bag