
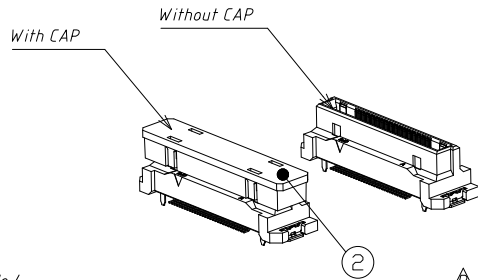


P/N	CKT	A	B	C	D	E
JME123043-602050-HF	20	4.50	9.50	15.95	17.60	17.36
JME123043-603050-HF	30	7.00	12.00	18.45	20.10	19.86
JME123043-604050-HF	40	9.50	14.50	20.95	22.60	22.36
JME123043-605050-HF	50	12.00	17.00	23.45	25.10	24.86
JME123043-606050-HF	60	14.50	19.50	25.95	27.60	27.36
JME123043-608050-HF	80	19.50	24.50	30.95	32.60	32.36
JME123043-600050-HF	100	24.50	29.50	35.95	37.60	37.36
JME123043-600250-HF	120	29.50	34.50	40.95	42.60	42.36



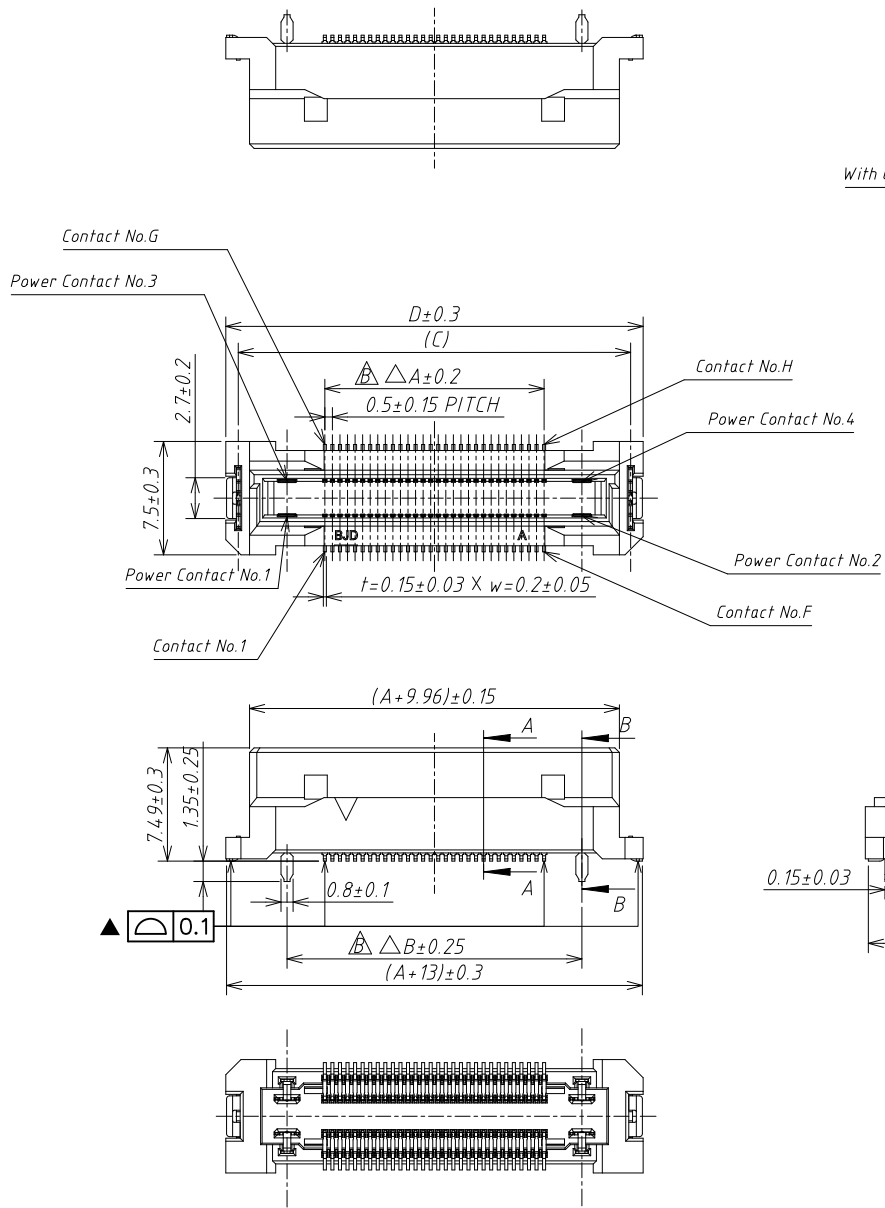


NOTES:

1. "▲" means Key dimensions, "△" means Important dimensions.

2. PART NO. Specifications : JME123043-60XX50-HF

XX: Quantity code of signal contacts.

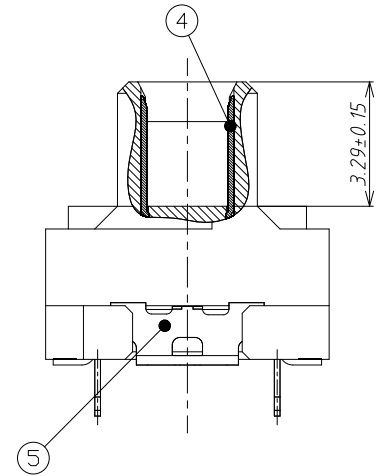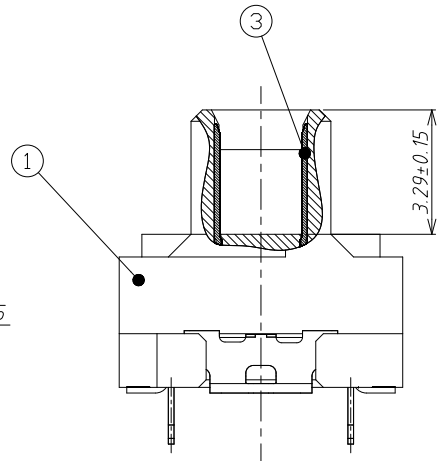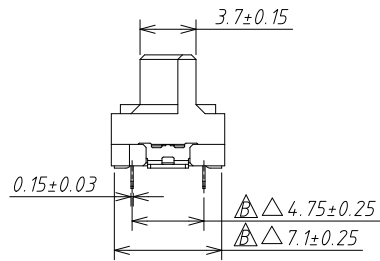

				UNLESS OTHERWISE SPECIFIED TOLERANCES ARE		客户图 Drawings		东莞市文章济美电子有限公司	
				X.		APPROVED		DATE	
				X.X		TS Chen		2022-08-01	
				X.XX		CHECKED		DATE	
				X.XXX		QF DONG		2022-08-01	
				ANG.		DRAWN		DATE	
				±0°30'		Kuan He		2022-08-01	
				UNIT		SIZE		SCALE	
				MM		A4		2:1	
				SER		REV		B	
				REVISIONS					
				CHK					
				DATE					

