

Operation: SMT/立贴式 小型常开单点型 检测开关[操作力可定制]



ITEM NO.: TC-CB02B (Series)





(L8.6mm×W4.8mm×H3.5mm DETECTOR-SWITCH)




Technical parameter

PROJECT		LEVEL	A[better product]	B[average product]
Electrical Properties	Contact Rating		0.1A, 12V DC	
	Initial Contact Resistance		50mΩ max.	
	Insulation Resistance		100MΩ min.500V DC Skey/PD: 100MΩ min.300V DC	
	Withstand Voltage		200V AC for 1 minute	100 V AC for 1 minut
	There No Load		115,000 Cycles	100,000 Cycles
Durable Performance	Rated Load		100,000 Cycles	850,000 Cycles
	Storage temp.		-15℃~+65℃(Operating Temp:)	
Operating Force			1. 0N. (1N. =100gram-force) ±0. 5N	
Heat Rrsistance			IR Reflow:235℃, 5sec. Manual :350℃, 3sec.	

Unit:mm

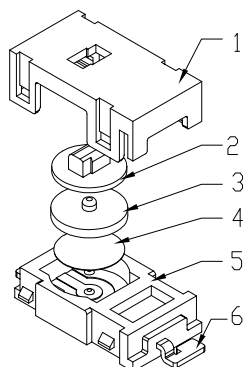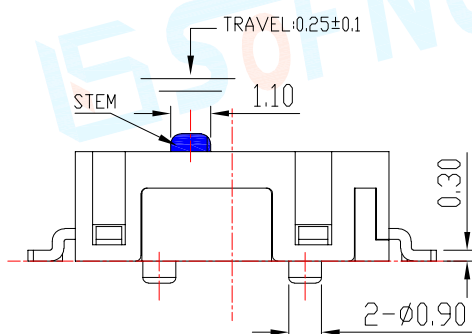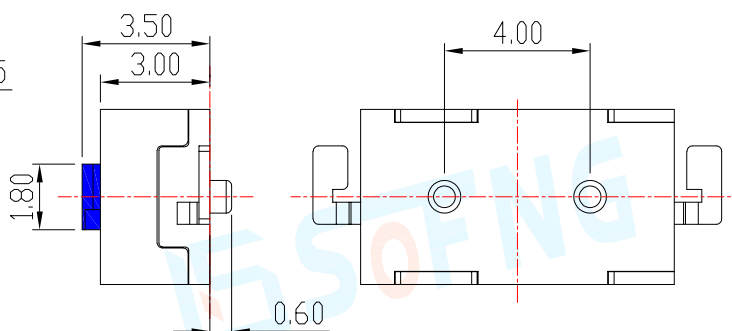
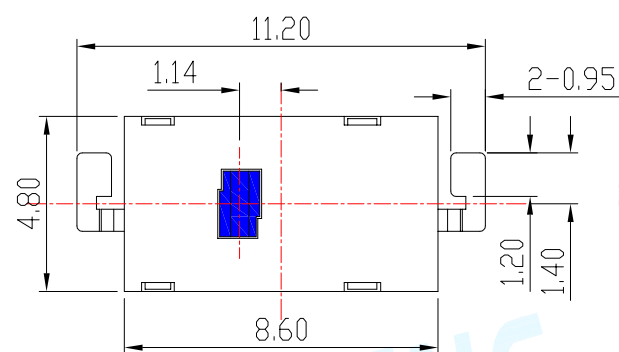


CIRCUIT DIAGRAM

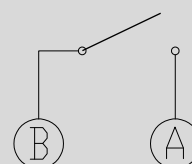

推荐锡膏厚度

 0.12mm

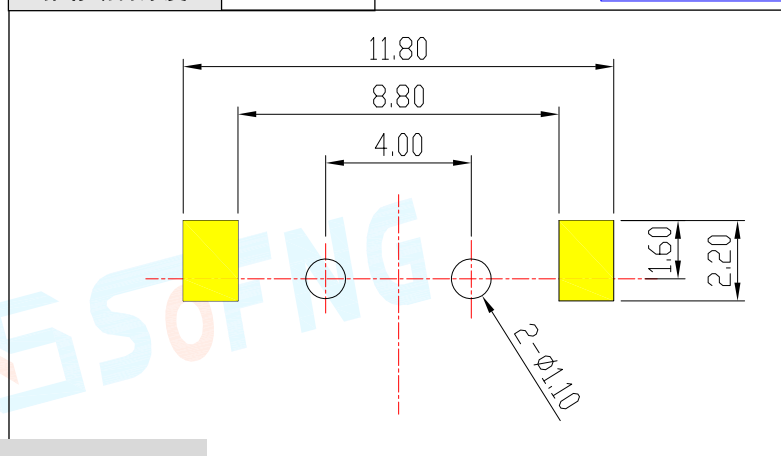

P.C.B LAYOUT