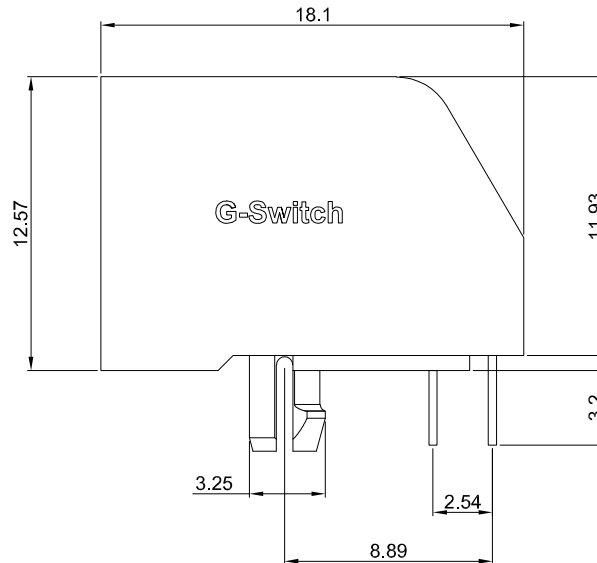
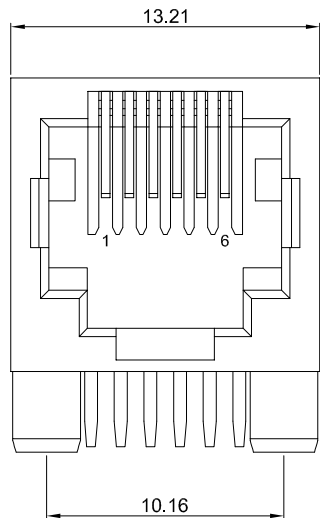


GT - RJ11 U N 00 - 001 A

G-Switch



Series
RJ11

Shield
U=UTP

Serial code

Contact Plated
00=Au G/F

Light
N=without led

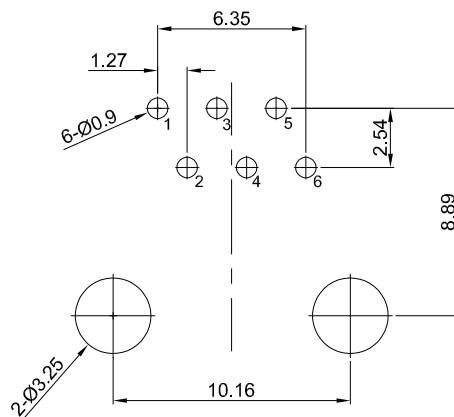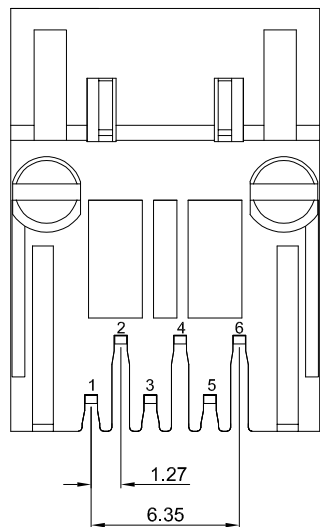

PCB REFERENCE DIAGRAM
TOLERANCE:±0.05

G-Switch Specification:

- 1.Current rating: 1.5A
- 2.Voltage rating: 125V AC RMS.
- 3.Insulation resistance: 500MΩ min
- 4.Contact resistance: 30mΩ max
- 5.Dielectric strength: 500 megohms min @ 100V DC
- 6.Durability: 750 cycles
- 7.Operating temperature range: -40°C ~ +85°C

1	HOUSING	PBT	BLACK UL 94V-0
2	TERMINALS	PHOSPHOR BRONZE	G/F PLATED ON CONTACT AREA TIn PLATED ON SOLDER AREA
NO.	PARTS	MATERIAL	REMARKS



SCALE: 1:1	UNIT: mm	Title: Horizontal RJ11 Conn 6P6C DIP 13.21×12.57×L18.10mm				品贊科技 b-Switch www.dg-switch.com	
SIZE: A4		Molde Code: GT-RJ11UN00-001A					
Unless otherwise General tolerance:							
X.	±0.40	DRAWN	CHECKED	APPROVED	DATE	REV: A0	SHEET: 1/1
X.x	±0.30						
X.xx	±0.20						
Angles	±3°						
		Xia	Chen	Chen	2025.05.29		