
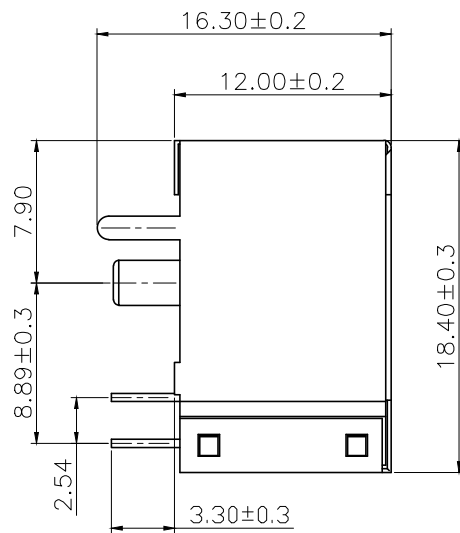
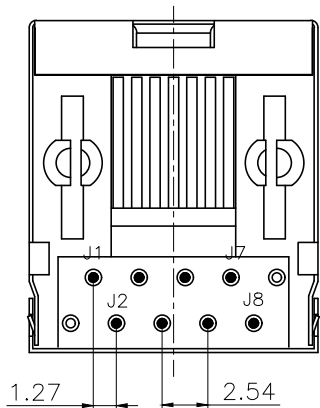
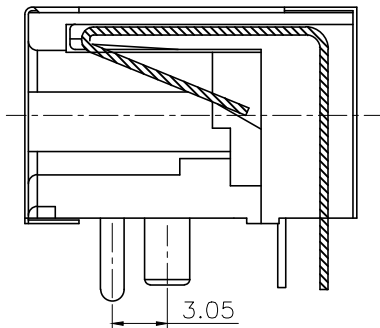


ROHS

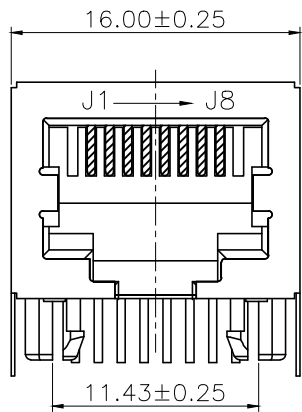

SPECIFICATION:

Electrical:

Current Rating:1.5Amp max @25℃

Voltage Rating:150VAC max

Insulation Resistance:500 megohms min

Contact Resistance:30 milliohms max

Withstanding Voltage:1000 VAC

Mechanical:

Durability:750 Cycles

Operating Temperature:-40℃~+70℃

Storage Temperature:-50℃~+75℃

Contact Normal Force:100g Minimum

Material:

Housing:PBT Black UL94V-0


Shield: 0.15mm Thickness SUS304 Ni Plated

Contact:0.45mm Dia Phosphor Bronze

Plated Gold Over Ni

Soldering Temperature: 260+/-5℃,5sec/95%Areabe covered

Withstand Temperature: 270+/-5℃,5sec No stick tin melting phenomenon

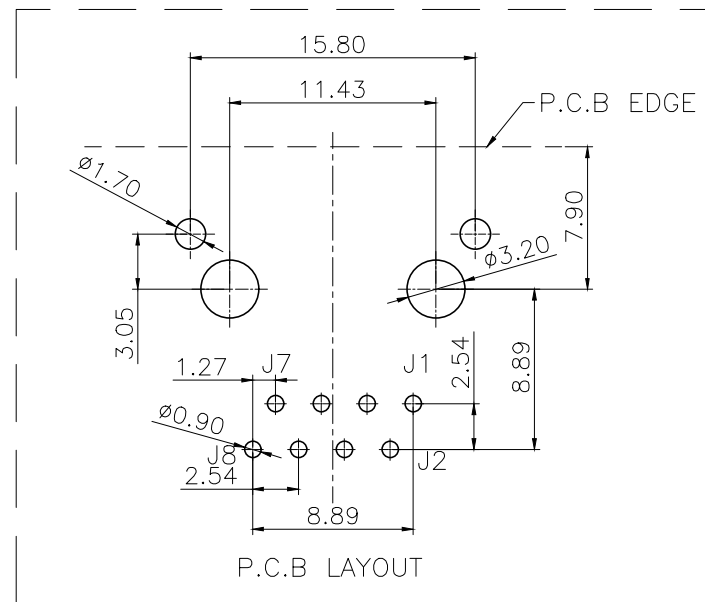

COSTOMER DRAWING		LAILIAN 深圳市莱联电子有限公司	
DRAWING		SHENZHEN LAILIAN ELECTRONICS CO.,LTD	
CHECKED			
APPROVED			
TOLERANCES ARE		TITLE	RJ45 8P8C带壳无弹无灯
30-150	±0.35	PART NO.	LAIL-RJ45-LED0-BY-01-WC
10-30	±0.2		
5-10	±0.15	DWG. NO.	
0-5	±0.1		
ANGLE		UNITS	mm
±3°		Projection	