


NO.	ECN NO.	DESCRIPTION	DATE

客户图

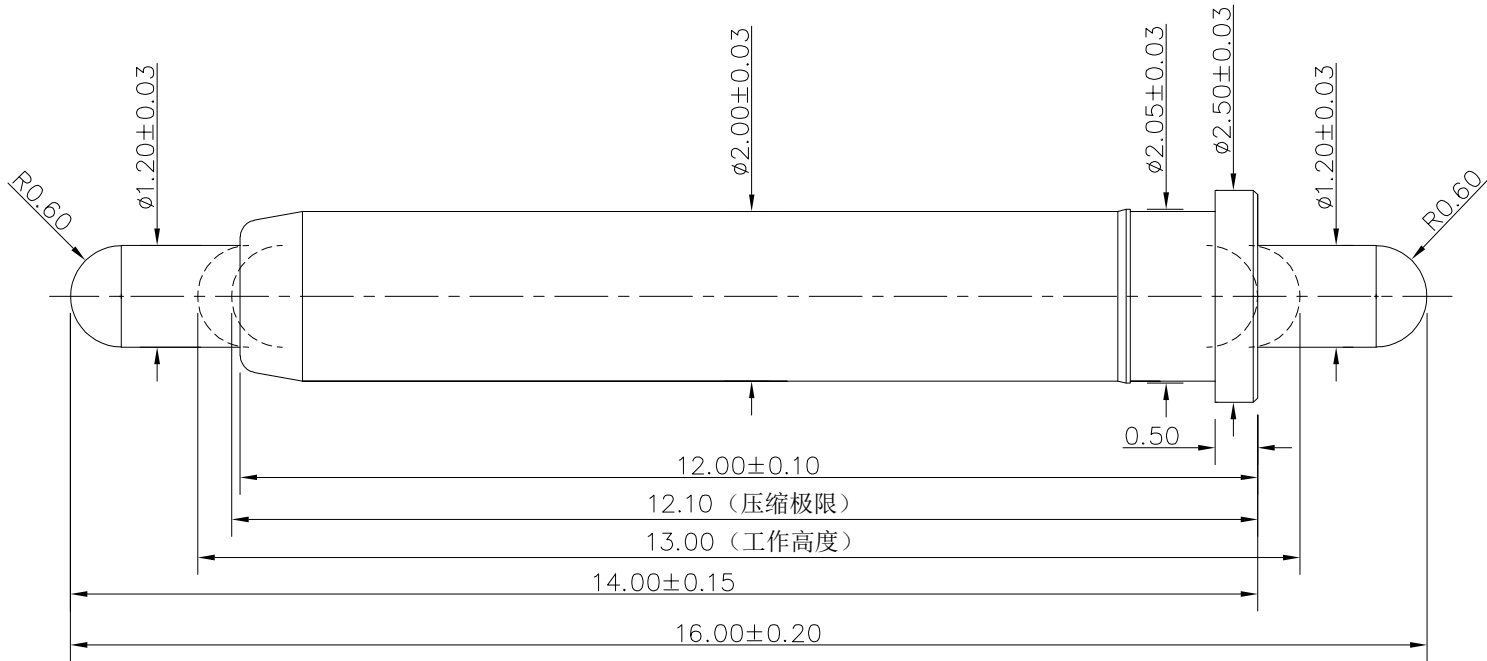

- Note:
- Material(材料):
Barrel: Brass C3604 (针管: 黄铜 C3604)
Plunger: Brass C3604 (针头: 黄铜 C3604)
Spring: SUS304 (弹簧: SUS304)
 - Plating(电镀):
Barrel: 3u' Au over 50~80u' Ni(针管: 镀金3u', 镍底50~80u'.)
Plunger: 3u' Au over 50~80u' Ni (针头: 镀金3u', 镍底50~80u'.)
Spring: Gold flash (弹簧: 镀金)
 - Electrical(电气特性):
Rated Current & Voltage: DC 12V;2A (额定电压&电流: 直流12V,2A)
Contact Resistance: 50 mohm Max. at working height.
接触电阻: 最大50毫欧 (在工作高度状态下)
 - Mechanical(机械性能):
Force: 100g±20% at working height. (100g±20% 在工作高度)。
Durability: 10.000 cycles(min) (寿命: 10000次)
 - WorkTemperture(工作环境):
Withstanding Higt Temperature: 280℃
Operational Temperature: -20℃~ +70℃

深圳市鑫探技术有限公司



HTTP://WWW.XYZPOGOPIN.COM
TEL:0755-28773277 FAX:0755-28891353

SCALE:	N/A	UNIT	mm	THE UNMARKED TOLERANCE ARE AS BELOW : LENGTHANGLE X.XX ±0.05mmX.X ±0.10mmX. ±0.20mmX.XX ±0.50°X.X ±1.00°X. ±2.00°				DESIGNED BY:		DWG. NO.	YZ67720160D-02
SHEET:	1 of 1	PROJECTION						CHECKED BY:		TITLE:	Pogo pin连接器
DATE:	2026.05.18	VER.	A.0					APPROVED BY:			