



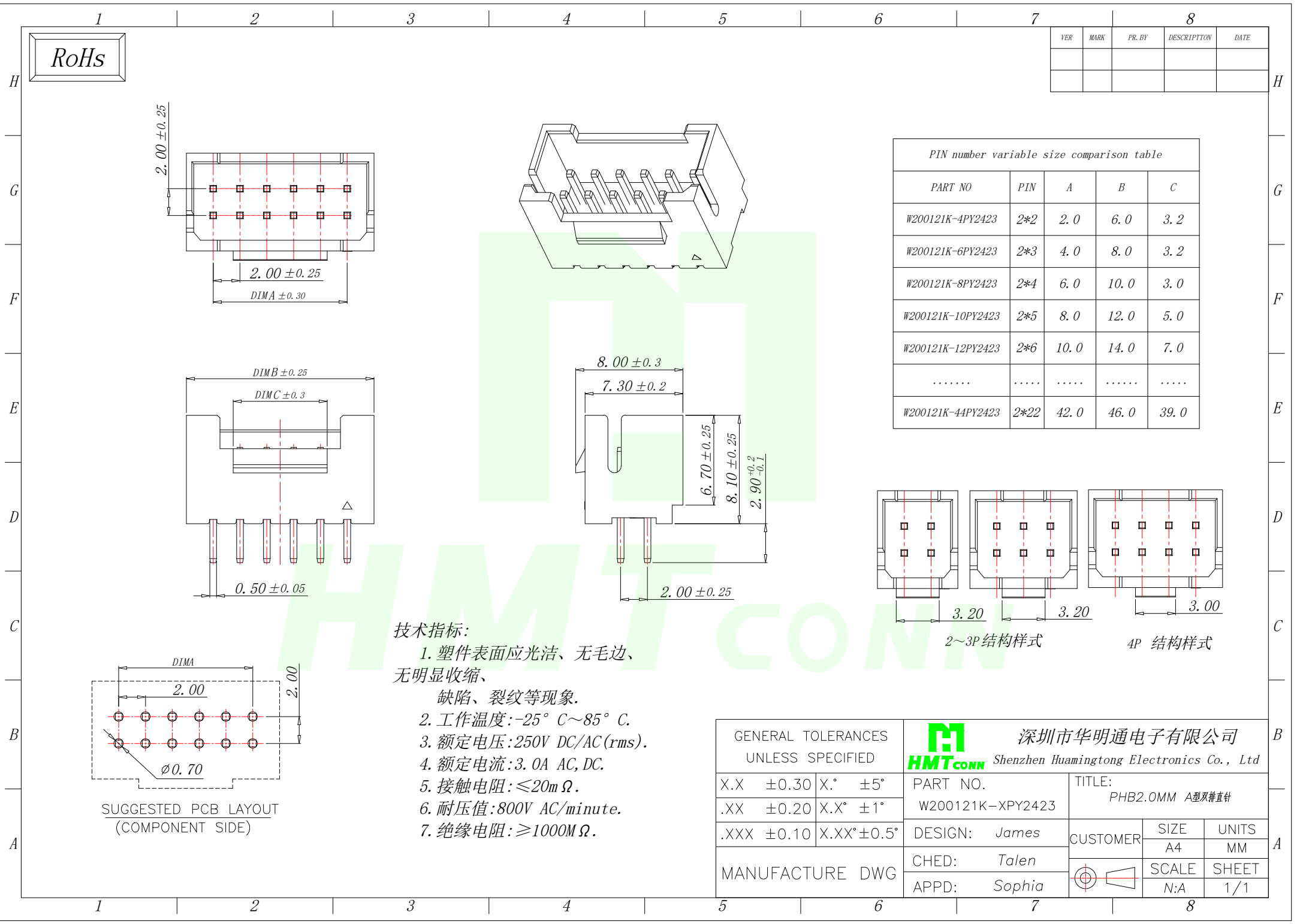

RoHS

VER	MARK	PR. BY	DESCRIPTION	DATE

PIN number variable size comparison table				
PART NO	PIN	A	B	C
W200121K-4PY2423	2*2	2.0	6.0	3.2
W200121K-6PY2423	2*3	4.0	8.0	3.2
W200121K-8PY2423	2*4	6.0	10.0	3.0
W200121K-10PY2423	2*5	8.0	12.0	5.0
W200121K-12PY2423	2*6	10.0	14.0	7.0
.....				
W200121K-44PY2423	2*22	42.0	46.0	39.0

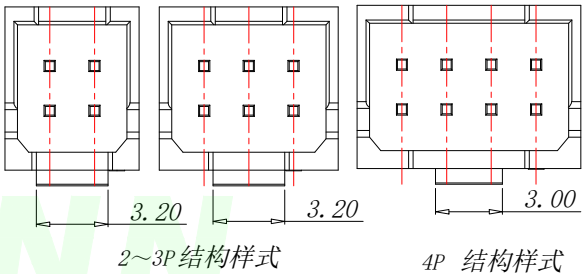

技术指标:

1. 塑件表面应光洁、无毛边、无明显收缩、缺陷、裂纹等现象。
2. 工作温度: $-25^{\circ}\text{C} \sim 85^{\circ}\text{C}$.
3. 额定电压: 250V DC/AC(rms).
4. 额定电流: 3.0A AC, DC.
5. 接触电阻: $\leq 20\text{m}\Omega$.
6. 耐压值: 800V AC/minute.
7. 绝缘电阻: $\geq 1000\text{M}\Omega$.

GENERAL TOLERANCES UNLESS SPECIFIED		 深圳市华明通电子有限公司 Shenzhen Huamingtong Electronics Co., Ltd	
X.X ±0.30	X.° ±5°	PART NO. W200121K-XPY2423	TITLE: PHB2.0MM A型双排直针
.XX ±0.20	X.X° ±1°	DESIGN: James	CUSTOMER
.XXX ±0.10	X.XX° ±0.5°	CHED: Talen	SIZE A4
MANUFACTURE DWG		APPD: Sophia	UNITS MM
			SCALE N:A
			SHEET 1/1