
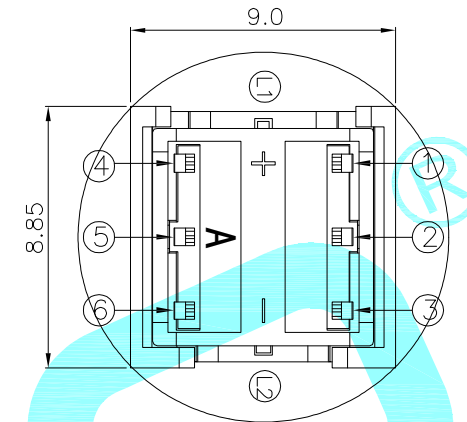


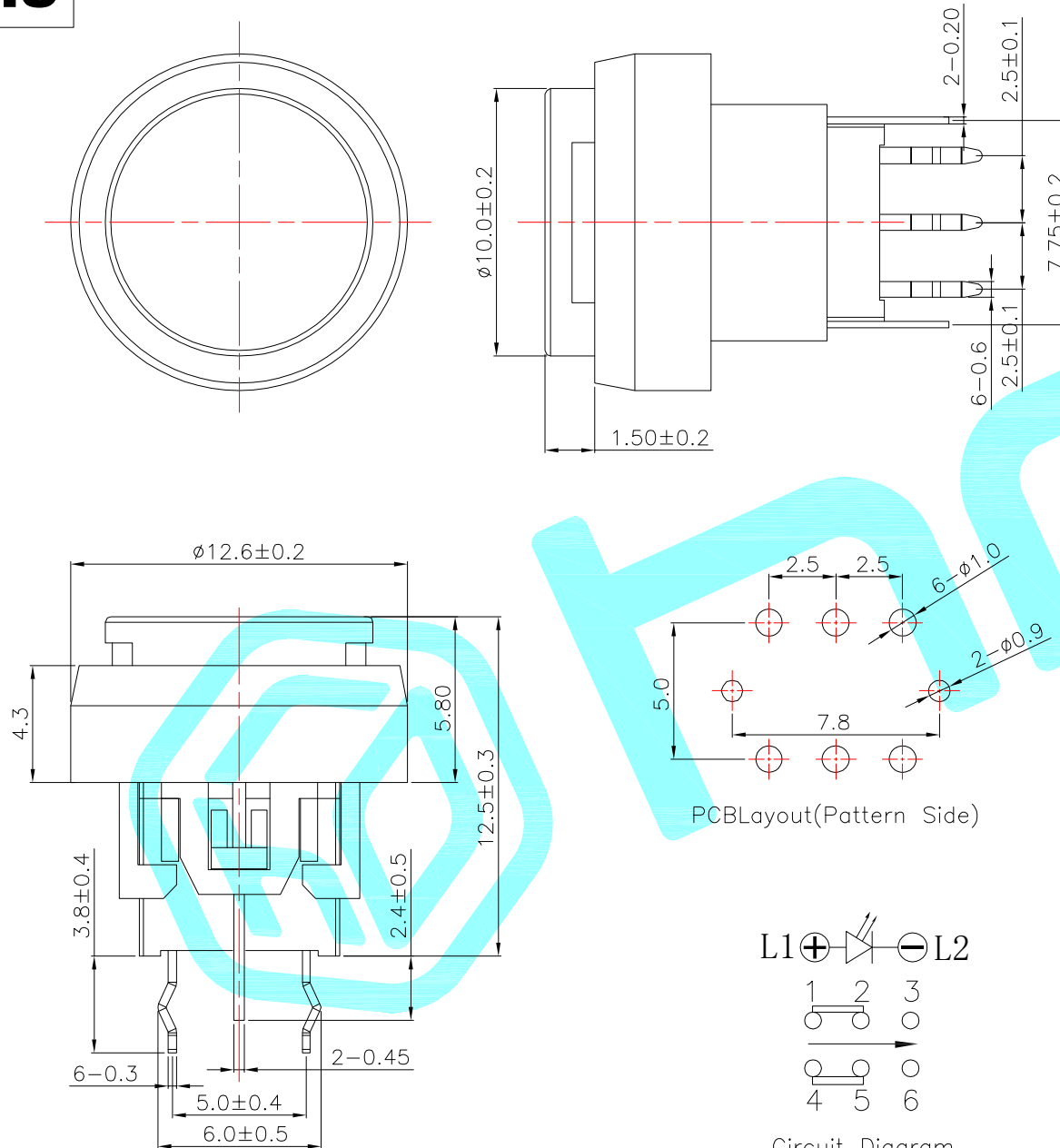

LED colour(LED颜色)	Part No. (料号)
Whiler(白色)	K6-6134D-01-□□
Red(红色)	K6-6134D-02-□□
Blue(蓝色)	K6-6134D-03-□□
Green(普绿)	K6-6134D-04-□□

NO.	Operating Type	Part No.
1	Push To Lock (自锁)	K6-6134D-□□-L1
2	Push No Lock (无锁)	K6-6134D-□□-N1

⑤	Cap	—	1	PC	Transparent	—
④	Fixed frame	—	1	POM	White	—
③	Contact	—	2	Phosphor bronze	Ag Plating	—
②	Terminal	—	—	Brass	Ag Plating	—
①	Housing	—	1	Nylon	Black	—
ITEM	PART NAME	TER'NO.	QTY.	MATERIAL	FINISHING	REMARK

APPROVALS			DATE					
DRAWN	LIUCAN	2021.10.28						
CHECKED				TITLE:		LED Tact Switch		
APPROVALS				PART NO.		K6-6134D-□□-□□		
D.	TOLERANCES ARE		30~以上	±0.30	ANGLE	UNIT: mm	SCALE: 1:1	PROJ: 
			10~30	±0.20				
			5~10	±0.15				
			~ 5	±0.10				
			±2'	DRAWING NO.		_____	SHEET 1 OF 1	

ECN NO.	REV.	DATE.	DESCRIPTION.	CHANGE.	CHECK.	APPRO.
	A		NEW			