

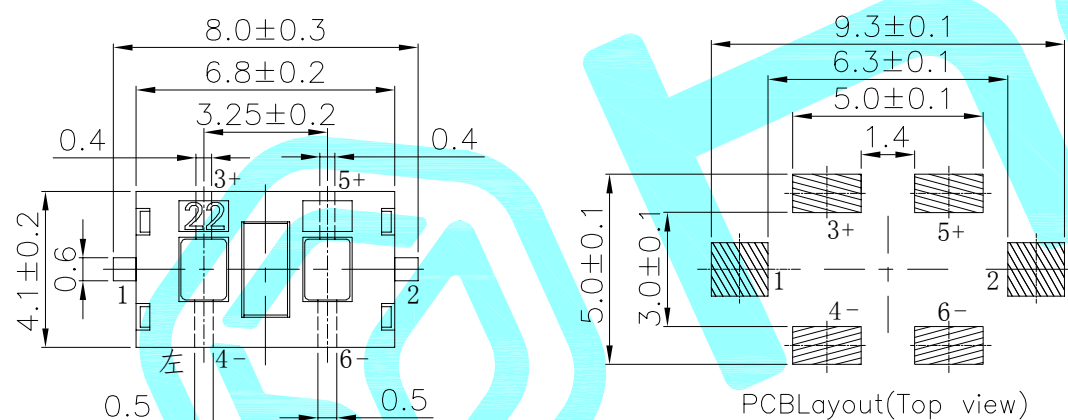


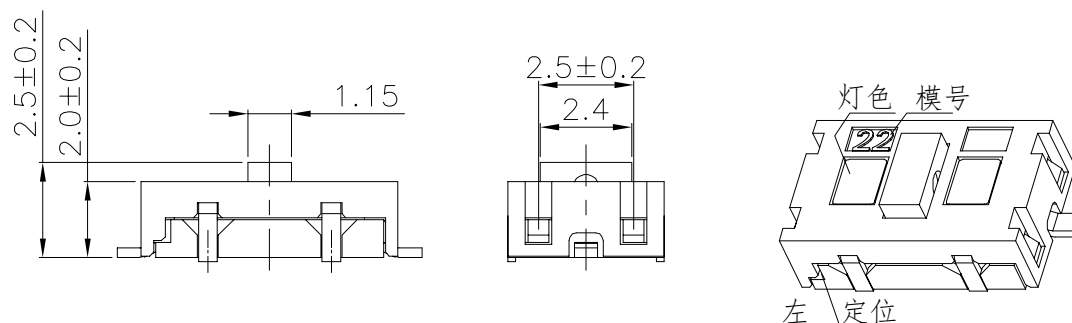


Typical Specifications

1. Rating : DC 30V 30mA
2. Insulation Resistance : 100MΩ MIN
3. Dielectric Strength : AC 250V for 1 minute
4. Operating Force : 260±50 gf
5. Contact Resistance : 100mΩ MAX
6. Life : 50,000 Cycles Min

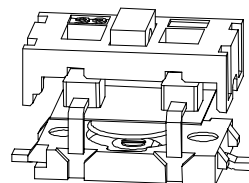

LED colour(LED颜色)		Part No. (料号)	Circuit Diagram
单色灯	White(白色)	K6-6841S-10	
	Red(红色)	K6-6841S-20	
	Blue(蓝色)	K6-6841S-30	
	Jade green(翠绿)	K6-6841S-70	
	White(白色)	K6-6841S-01	
	Red(红色)	K6-6841S-02	
	Blue(蓝色)	K6-6841S-03	
双色灯	Jade green(翠绿)	K6-6841S-07	
	White(左白)/Blue(右蓝)	K6-6841S-13	
	Red(左红)/Jade green(右翠绿)	K6-6841S-27	
	White(左白)/Red(右红)	K6-6841S-12	
	Blue(左蓝)/Blue(右蓝)	K6-6841S-33	

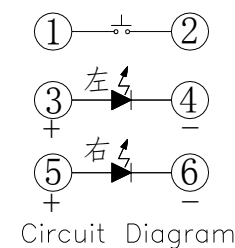

⑥	Contact	——	1	SUS	Ag Plating	——
⑤	Cover	——	1	PPA	White	——
④	LED	——	1	——	——	——
③	Terminal	——	8	Brass	Ag Plating	——
②	Base	——	1	LCP	Black	——
①	Button	——	1	LCP	White	——
ITEM	PART NAME	TER'NO.	QTY.	MATERIAL	FINISHING	REMARK

APPROVALS		DATE				
DRAWN	LIUCAN	2023.10.26				
CHECKED				TITLE:	LED Tact Switch	
APPROVALS				PART NO.	K6-6841S-□□	
TOLERANCES ARE	30~以上	±0.30	ANGLE	UNIT: mm	SCALE: 1:1	PROJ: 
	10~30	±0.20				
	5~10	±0.15				
	~ 5	±0.10				
		±2'	DRAWING NO.	_____		SHEET 1 OF 1

——	A	——	NEW	——	——	——
ECN NO.	REV.	DATE.	DESCRIPTION.	CHANGE.	CHECK.	APPRO.