



CHIP COMMON MODE CHOKE


High Common Mode Impedance at High Frequency.
Excellent Noise Suppression Performance.
Small Size and Low Profile, Surface Mount Type.
Operating Temperature Range: -40 °C to +85 °C.
RoHS Compliant.




Electrical Specifications @25°C

Part Number	Common mode Impedance (ohm $\pm 25\%$ @100M)	DCR		Rated Current A Max	Rated Volt (Vdc)Max	IR (MΩ Min)
		(mΩ typ.)	(mΩ Max)			
ACP3225-102-2P-T000 T-CND	1000	50	100	1.5	60	10
ACP3225-501-2P-T000 T-CND	500	40	100	2	60	10

MECHANICAL

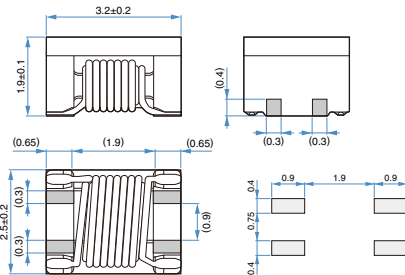


SCHEMATICS

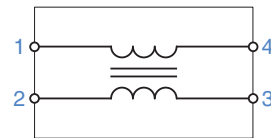


• No polarity

IMPEDEANCE FREQUENCY

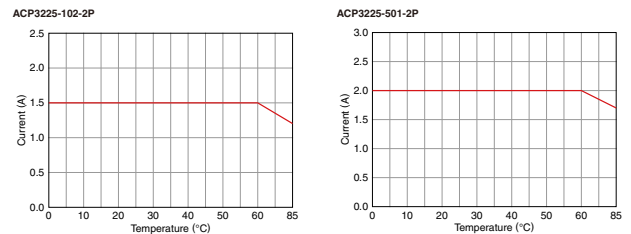

Unless otherwise specified all tolerances are:±0.25mm


TAPING AND PACKING

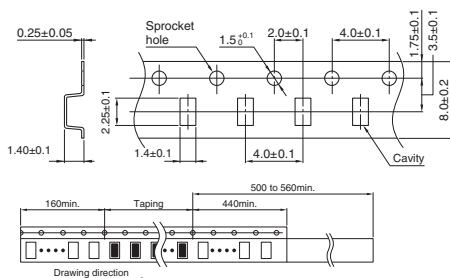

Quantity (pcs):
1000 PCS PER REEL
10 REELS PER CARTON
10000 PCS PER CARTON

Dimensions in mm

Reel

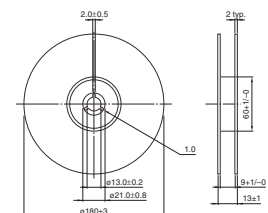

Dimensions in mm

Shenzhen magnetic Lianda Electronics Co., LTD

Address: 505, West Block, No. 221, Niucheng Road, Niucheng Village, Baiwang Community, Xili Street, Nanshan District, Shenzhen
Tel:0755-27652992 29016433 E-mail: sales1@cd-tek.com Website:www.cd-tek.com