

产品规格书

PRODUCT SPECIFICATION SHEET

物料名称

APPELLATION: A11 无线发射单线圈模组

MODE: YX-A11-R481226-G3248

客户料号

No.:

生产方	工艺审核 TECHNICAL	品质审核 QUALITY	项目审核 PROJECT	开发审核 DEVELOPING
	Jiuguijiang	wangxue	wangchunxia	Jiuguijiang


客户方	材料工程师 Materials Engineer	设计工程师 Engineer	主管审批 Approval	研发体系 R & D System



变更履历表

[illegible]

1. DIMENSIONS & MARKING:

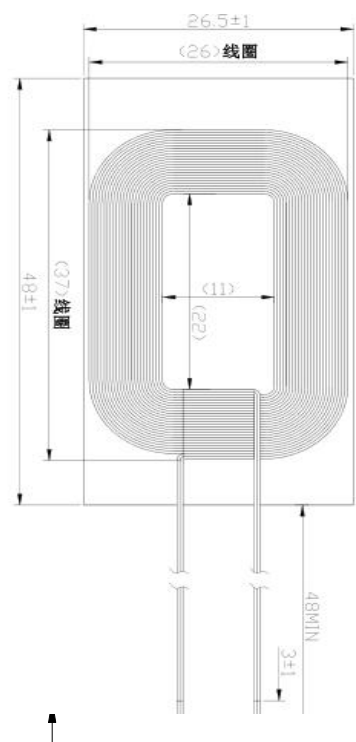

Symbol	A	B	C	D	E	F
Value(mm)	26.50max	48.00max	48.00	11.00	3.00±1.00	37.00max

2. ELECTRICAL SPECIFICATIONS @25℃


- 2.1 Operating Temperature range: -40℃~+85℃
- 2.2 Storage temperature range: -25℃ TO +125℃
- 2.3 The test frequency: 100 KHz, 100mV @ 25℃,65%
- 2.4 OCL : 8.20±10% μH .
- 2.5 Diameter : 0.3mm*2P
- 2.6 Turns Ratio: 12T

DRAWN BY:	CHECKED BY:	APPROVED BY:	CUSTOMER:
jiuguijiang	jiuguijiang	wangchunxia	PART NO. : YX-A11-R481226-G3248
CND-TEK 深圳磁联达电子有限公司			
REV. : A PAGE: 3 Of 4			

3、 Bill of materials:

序号	物料名称	物料规格	材料使用	备注
1	丝包线	0.3mm*2P	√	
2	软磁片	48*26.5mm	√	
3	锡条	Sn97.3-0.7Cu	√	

4、 Packaging:

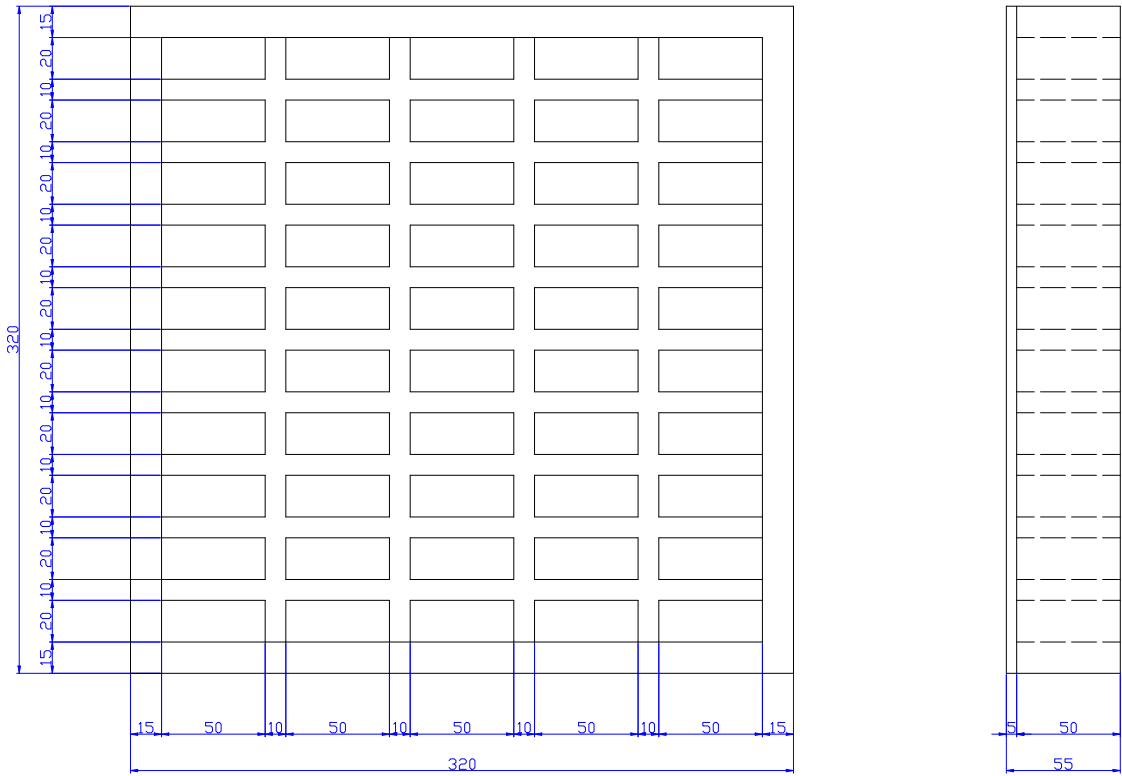

- 4.1 Quantity per grid: 20 PCS
- 4.2 Quantity per carton: 20*50 = 1000PCS
- 4.3 Quantity per carton: 1000*3 = 3000PCS
- 4.4 Carton size: 350*350*180mm.

DRAWN BY:	CHECKED BY:	APPROVED BY:	CUSTOMER:
jiuguijiang	jiuguijiang	wangchunxia	PART NO. : YX-A11-R481226-G3248
CND-TEK 深圳磁联达电子有限公司			REV. : A
			PAGE: 4 Of 4