

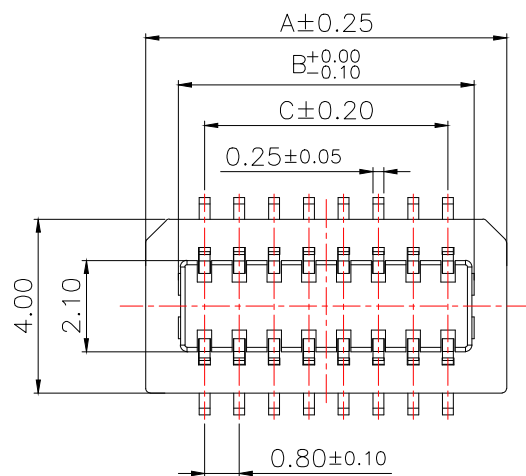
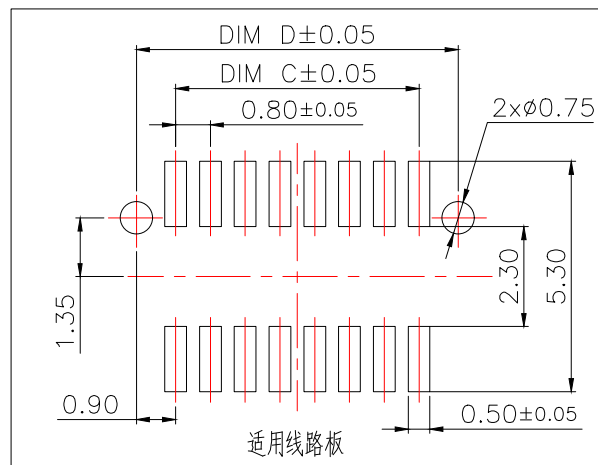
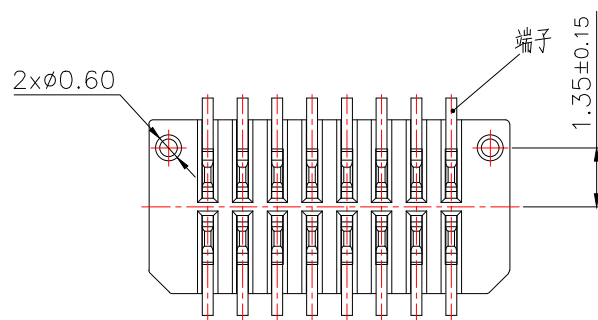
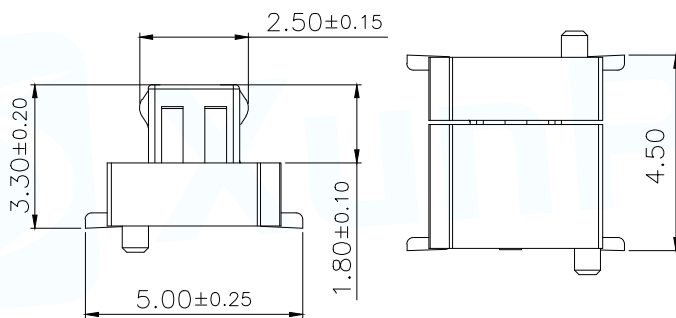


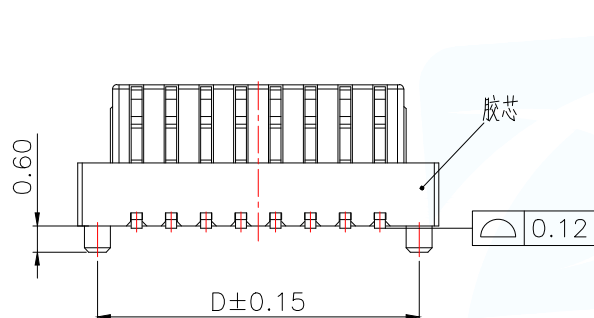

技术指标:

1. 塑件表面应光洁、无毛边、无明显收缩、缺陷、裂纹等现象。
2. 温度范围: $-40^{\circ}\text{C} \sim 105^{\circ}\text{C}$ 。
3. 额定电压: 50V, AC。
4. 接触电阻: $\leq 0.02\Omega$ 。
5. 绝缘电阻: $\geq 500\text{M}\Omega$ 。

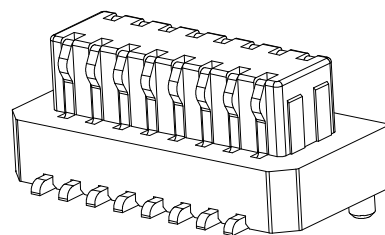

MAPX	MODIFICATION	DATE	DRAW	APPROVE
序号	品名	材质		
①	0.8 Pitch F型 单槽立式BTB公座胶芯	PA9T UL94 V-0, 颜色: 黑色		
②	0.8 Pitch F型 单槽立式公座端子	铜合金/表面点镀金		

总高(H)	公座单高(H)		母座单高(H)
	H	H1	
4.00	2.80	1.80	2.90
4.50	3.30		
5.00	3.80		
5.50	4.30	2.30	3.40
6.00	4.80		
6.50	5.30		
7.00			3.90

Part No	CKT	A	B	C	D
BTB0.833-6PLBDB6-GB42	2*3	4.30	2.80	1.60	3.40
BTB0.833-8PLBDB6-GB42	2*4	5.10	3.60	2.40	4.20
BTB0.833-10PLBDB6-GB42	2*5	5.90	4.40	3.20	5.00
BTB0.833-12PLBDB6-GB42	2*6	6.70	5.20	4.00	5.80
BTB0.833-14PLBDB6-GB42	2*7	7.50	6.00	4.80	6.60
BTB0.833-16PLBDB6-GB42	2*8	8.30	6.80	5.60	7.40
BTB0.833-18PLBDB6-GB42	2*9	9.10	7.60	6.40	8.20
BTB0.833-20PLBDB6-GB42	2*10	9.90	8.40	7.20	9.00
BTB0.833-30PLBDB6-GB42	2*15	13.90	12.40	11.20	13.00
BTB0.833-40PLBDB6-GB42	2*20	17.90	16.40	15.20	17.00
BTB0.833-50PLBDB6-GB42	2*25	21.90	20.40	19.20	21.00
BTB0.833-60PLBDB6-GB42	2*30	25.90	24.40	23.20	25.00
BTB0.833-70PLBDB6-GB42	2*35	29.90	28.40	27.20	29.00
BTB0.833-80PLBDB6-GB42	2*40	33.90	32.40	31.20	33.00
BTB0.833-90PLBDB6-GB42	2*45	37.90	36.40	35.20	37.00
BTB0.833-100PLBDB6-GB42	2*50	41.90	40.40	39.20	41.00

MANUFACTURE DWG		 东莞市讯普电子科技有限公司 DongGuan XunPu Electronics Co., Ltd		
UNLESS OTHERWISE SPECIFIED TOLERANCES		 TITLE: 0.8 Pitch F型单槽立式BTB公座业务图(单高3.3)		
DECIMALS:		PAR	BTB0.833-XPLBDB6-GB42	
X.: ±0.50		DWN	Lucas	
X.X: ±0.20		CHKD	Ethan	
X.XX: ±0.10		APVD	Jacob	
		SCALE: 1:1	UNIT: MM	
		CUSTOMER COPY	SIZE: A4	SHEET: 1F1
				REV: A