
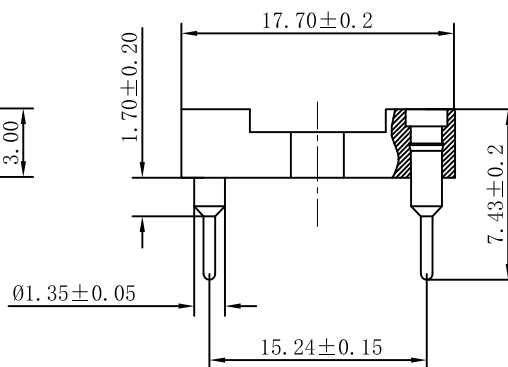
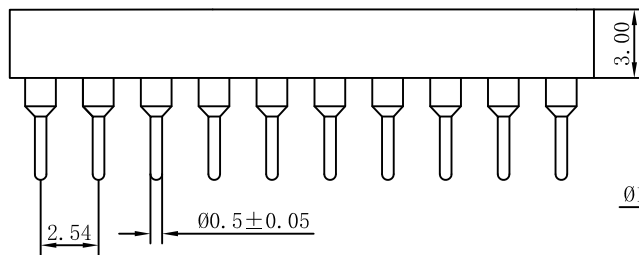


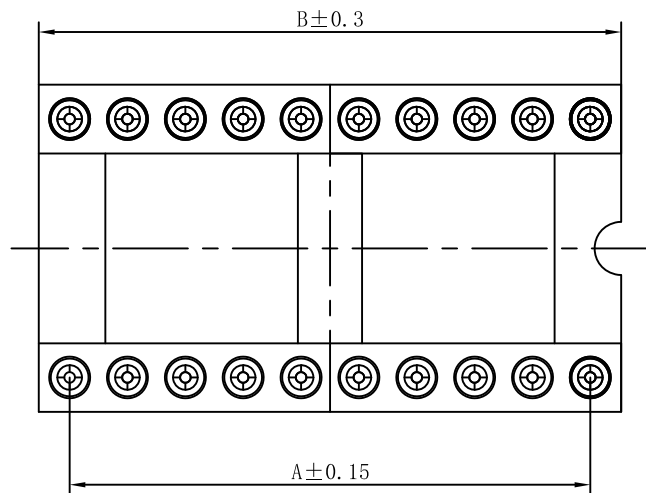

材料

针(外套管): 黄铜, CuZn38Pb2

线夹(触点4指): 铜钨合金, 经过热处理

镀层(外套管): 镀锡 或镀金

镀层(触点): 镀金 或镀锡

绝缘体(黑色): 玻璃充填热塑性聚酯 UL94-V0

电气参数

额定电流: 3A/触点, 最大值

接触电阻: <20mΩ/触点

绝缘电阻: 1000MΩ, 在DC100V下

操作电压: 60VAC/DC

机械参数

操械温度: 镀金: -55° C ~ +125° C

镀锡: -40° C ~ +105° C

Ø0.43mm/0.017英寸钢针的平均插进力: <250g

Ø0.43mm/0.017英寸钢针的平均拔力: <50g

机械寿命: 最小200

焊接温度: 260° C, 10秒, 最大值

Poles	PART NO.	A	B	备注
24	Z-6200S24P-W000	27.94	30.48	单杠
28	Z-6200S28P-N000	33.02	35.56	
32	Z-6200S32P-W000	38.1	40.64	
40	Z-6200S40P-W000	48.26	50.8	双杠
42	Z-6200S42P-W000	50.8	53.56	
48	Z-6200S48P-W000	58.42	61.24	

TOLERANCE TABLE	
.0	±0.30
.00	±0.20
.000	±0.05

APPROVED:	DATE:	Ckmtw 深圳市灿科盟实业有限公司 CANKEMENG INDUSTRIAL CO., LTD					
CHECKED:	DATE:	TITLE: 2.54圆孔IC座 6200S-XP 行距15.24mm					
DRAWN: YKX	DATE: 2024-6-25	PART. NO.	Z-6200SXXP-W000				
		UNIT	mm	SCALE	free	☉	☐
		FILE NO.	Ckmtw-6200-0002	REV.	A	AC00	