



Operation:DIP/沉板卧式 小型 镀金阻燃 DC 电源连接器

ITEM NO.:DC-018C-T13 (Series)

(L10.5×W6.5×H4.6 DC-CONNECTORS)

側向操作

精密部品 NICETY


可靠 STABILIZE

適合環保 RoHS

Technical parameter

LEVEL		A[better product]	B[average product]
PROJECT			
Electrical Properties	Contact Rating	1.0A, 24V DC	
	Initial Contact Resistance	50mΩ max.	
	Insulation Resistance	100MΩ min.500V DC	Skey/PD: 100MΩ min.300V DC
Durable Performance	Withstand Voltage	500V AC for 1 minute	350 V AC for 1 minute
	There No Load	6,000 Cycles	5,000 Cycles
	Rated Load	5,000 Cycles	4,000 Cycles
	Storage temp.	-35℃～+75℃(Operating Temp:)	
Operating Force		IF:5～15N MAX. (EF:10.0N MIN.)	
Heat Rrsistance		IR Reflow:255℃, 5sec. Manual :350℃, 3sec.	

CIRCUIT DIAGRAM

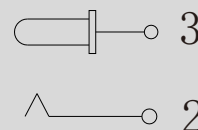

Unit:mm

