

Operation: 卧式/DIP 阻燃级 大电流 DC 电源连接器 (Type-A)

RoHS Compliant

LTEM NO.:DC-044D-□ (Series)

(L11.85×W10.0×H7.3 DC-CONNECTORS)



邀您使用(微信)小程序
碩方电子开关&连接器选型手册
手机扫码即可进入...

Technical parameter

LEVEL		A[better product]	B[average product]
PROJECT			
Electrical Properties	Contact Rating	3A, 12V DC	
	Initial Contact Resistance	50mΩ max.	
	Insulation Resistance	100MΩ min.500V DC Skey/PD: 100MΩ min.300V DC	
Durable Performance	Withstand Voltage	500V AC for 1 minute	350 V AC for 1 minut
	There No Load	6,000 Cycles	5,000 Cycles
	Rated Load	5,000 Cycles	4,000 Cycles
	Storage temp.	-35℃~+75℃(Operating Temp:)	
	Operating Force	IF:35N MAX. (EF:10.0N MIN.)	
	Heat Rrsistance	IR Reflow:235℃,5sec. Manual:350℃,3sec.	






PIN DIAM	2.0 mm	2.5 mm
----------	--------	--------

DC-044D - T**


产品型号

内芯直径
T20=2.0mm
T25=2.5mm


Unit:mm

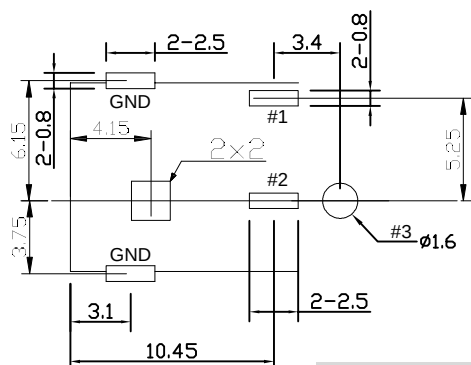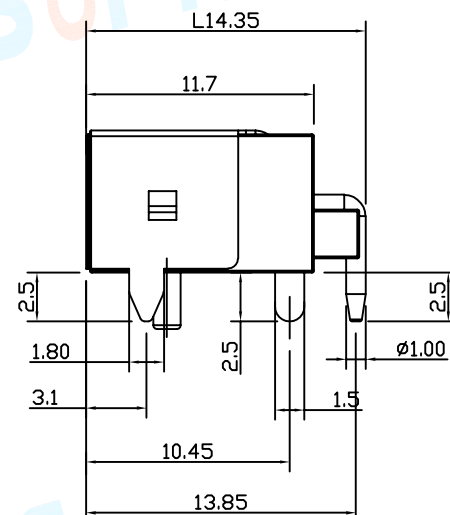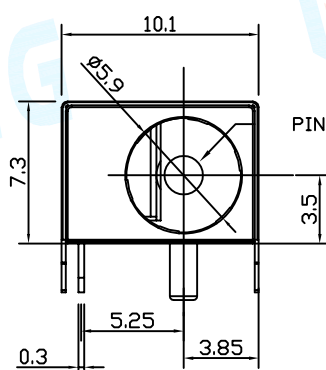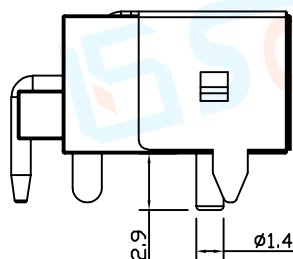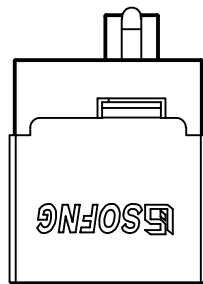

P.C.B LAYOUT

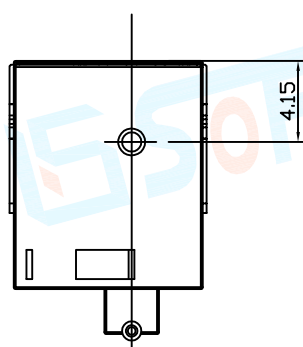

CIRCUIT DIAGRAM

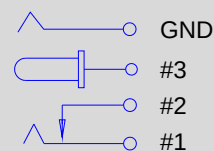

表面插装 DIP

側向操作

精密部品 NICETY

可靠 STABILIZE

適合環保 RoHS

