

CONNECTORS

Operation: DIP& 4PIN 侧入板式 1.0A/ 电源连接器



ITEM NO.: DC-033D-T13 (Series)

(L9.4×W8.0×H5.3 DC-POWER-SOCKETS)

DC-POWER-SOCKETS



Technical parameter

PROJECT	LEVEL	A[better product]	B[average product]
Electrical Properties	Contact Rating	0.5A, 30V DC	
	Initial Contact Resistance	50mΩ max.	100mΩ max.
	Insulation Resistance	100MΩ min.500V DC	Skey/PD: 100MΩ min.300V DC
	Withstand Voltage	500V AC for 1 minute	350 V AC for 1 minut
	There No Load	6,000 Cycles	5,000 Cycles
Durable Performance	Rated Load	5,000 Cycles	4,000 Cycles
	Storage temp.	-35℃~+75℃(Operating Temp:)	

插件封装 DIP



 
侧向导入 LATERAL

精密部品 NICETY

可靠 STABILIZE

適合環保 RoHS


Unit:mm

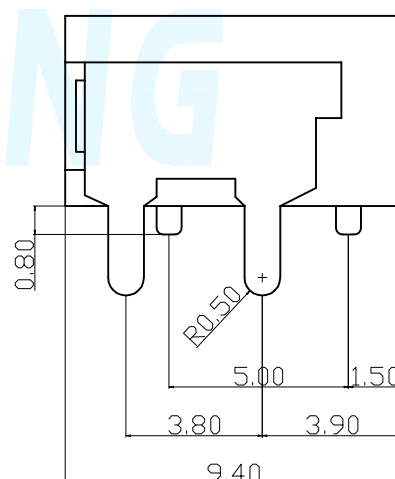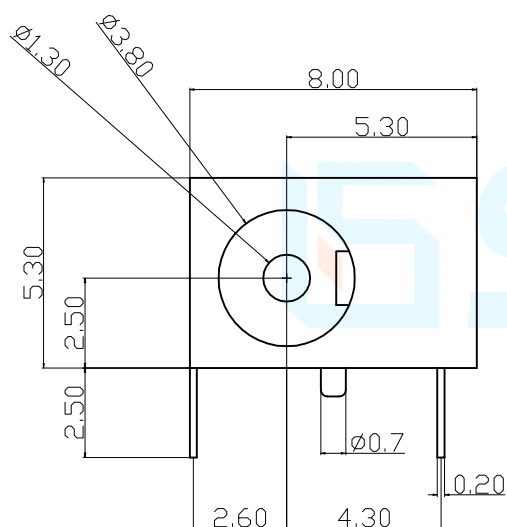

邀您使用(微信)小程序

硕方电子开关&连接器选型手册

手机扫码即可进入...

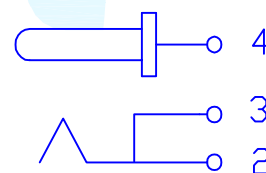

Operating Force

Inward
Exiting


5.0~8.0N. (1N.=100gram-force)

5.0~8.0N. (1N.=100gram-force)

Solder-ability (Max.)

IR Reflow:245°C, 5sec.

Manual:330°C, 3sec.

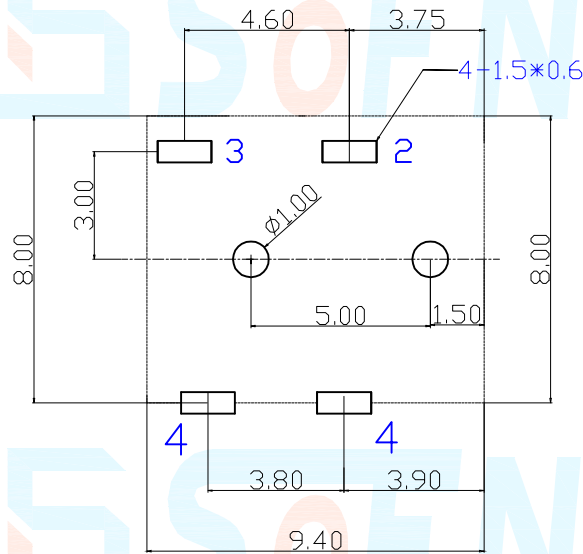

DECIMALS	ANGLES
.X :±0.25	X.° :±1.5°
.XX :±0.15	X.X° :±1.0°
.XXX :±0.05	.XXX° :±0.5°


Pin Definition

Material declaration

No.	NAME	Type	Description
① A	基座 HOUSING	1	耐热尼龙 PPA[Black]
② B	下垫 UP&DOWN COVER	1	耐热尼龙 PPA[Black]
③ C	芯针 AXIS SUPPORT	1	H62 黄铜棒 BRASS[镀锡]
④ D	簧片 Ccontact	1	QSn6.5-0.1 锡青铜带[镀银]t=0.40mm
⑤ E	动态端子 Moving Ccontact	1	H62 黄铜带 BRASS[镀银]t=0.40mm
⑥ F	静态端子 Moving Ccontact	1	H62 黄铜带 BRASS[镀银]t=0.40mm

■ 手焊接时

项目	条件
焊接温度	350°C max.
连续焊接时间	3s max.
焊剂斗容量	60W max.

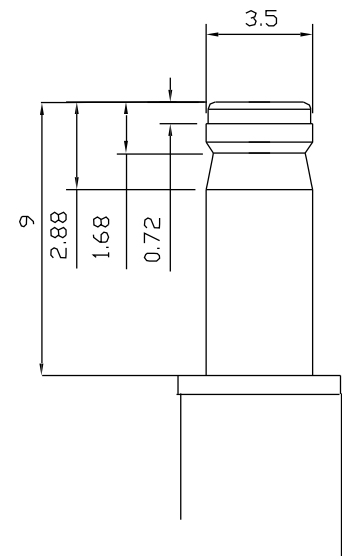

本品不屬於危害性廢棄物,須丟棄時可以委託
回收商予以回收再生處理。
Products do not belong to •

注記 NOTICE

1. 碩方公司擁有最終解釋權; The company reserves the right of final interpretation;
2. 文件禁止外洩、轉載; Leaked and reproduced prohibited;
3. 未經授權修改無效。Modify is invalid.

運送時本產品不要直接與水、酸鹼性化學物質接觸,或放置於含有以上氣體環境中,並且需要注意會有滑落、側翻的危險發生; 運輸過程中不能有碰撞或者擠壓,須保證溫度與濕度適中 [常溫 25°C, 濕度在 50°C 以內], 不可導致材料變形或氧化。