

CONNECTORS

Operation: DIP& 侧插板式 3.0A 大电流/电源连接器



ITEM NO.: DC-036

(L11.5×W7.0×H9.6 DC-POWER-SOCKETS)



Technical parameter

PROJECT		LEVEL	A[better product]	B[average product]
Electrical Properties	Contact Rating		3.0A, 24V DC	
	Initial Contact Resistance		30mΩ max.	50mΩ max.
	Insulation Resistance		100MΩ min.500V DC	Skey/PD: 100MΩ min.300V DC
	Withstand Voltage		500V AC for 1 minute	350 V AC for 1 minut
	There No Load		6,000 Cycles	5,000 Cycles
Durable Performance	Rated Load		5,000 Cycles	4,000 Cycles
	Storage temp.		-25℃~+75℃(Operating Temp:)	

插件封装 DIP

 

侧向导入 LATERAL

精密部品 NICETY

可靠 STABILIZE

適合環保 RoHS

Unit:mm

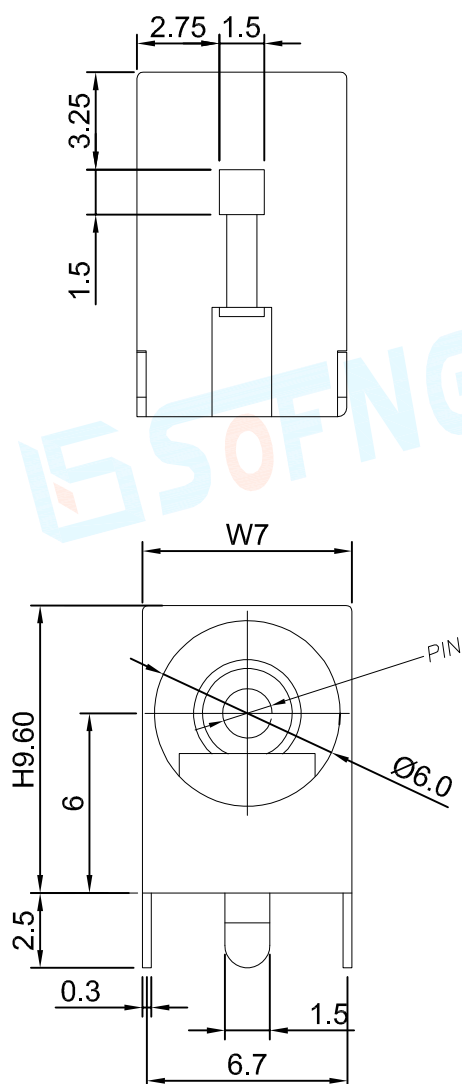


PIN	Ø 1.65	Ø 2.0	Ø 2.5
APPO			

DC - 036 - T20

产品型号
内芯直径
T16=1.65mm
T20=2.0mm
T25=2.5mm

SOFTNG

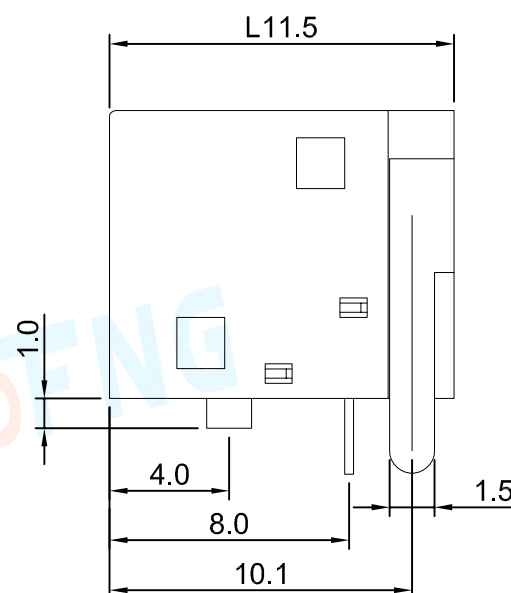

Operating Force

Inward

5.0~10.0N. (1N.=100gram-force)


Exiting

5.0~10.0N. (1N.=100gram-force)

Solder-ability (Max.)

IR Reflow: 255°C, 5sec.



Manual: 350°C, 3sec.

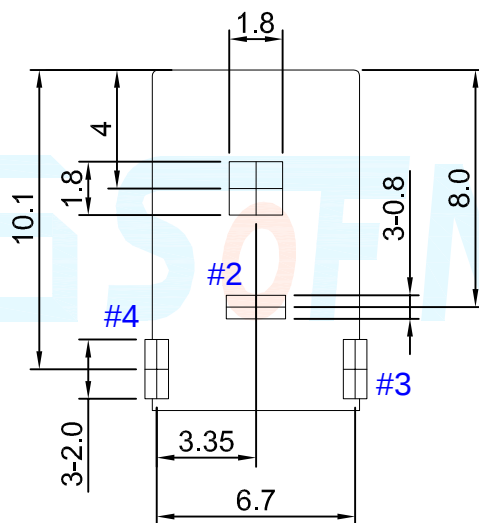

Pin Definition

Material declaration

No.	NAME	Type	Description
① A	基座 CASE	1	耐热尼龙 PPA
② B	动态端子 Moving Ccontact	1	H65 磷铜[镀银]t=0.3mm
③ C	平片 FLAT PIECE	1	H62 黄铜带 BRASS[镀银]t=0.3mm
④ D	静态端子 Moving Ccontact	1	H62 黄铜带 BRASS[镀银]t=0.3mm
⑤ E	盖板 Cover	1	H62 黄铜带 BRASS[镀银]t=0.3mm
⑥ F	芯针 AXIS SUPPORT	1	H62 黄铜棒 BRASS[镀银]

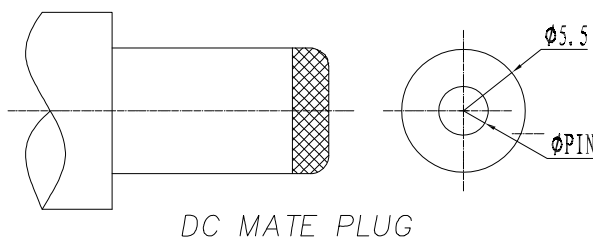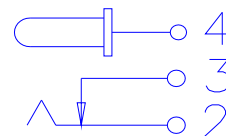

邀您使用(微信)小程序

硕方电子开关&连接器选型手册

手机扫码即可进入...



本品不屬於危害性廢棄物,須丟棄時可以委託
回收商予以回收再生處理。
Products do not belong to •

注記 NOTICE

1. 碩方公司擁有最終解釋權; The company reserves the right of final interpretation;
2. 文件禁止外洩、轉載; Leaked and reproduced prohibited;
3. 未經授權修改無效。Modify is invalid.

運送時本產品不要直接與水、酸鹼性化學物質
接觸,或放置於含有以上氣體環境中,並且需要
注意會有滑落、側翻的危險發生; 運輸過程中
不能有碰撞或者擠壓,須保證溫度與濕度適中
[常溫 25°C, 濕度在 50°C 以內], 不可導致材料變
形或氧化。