

Operation: DIP/卧式 阻燃 中型 DC 电源连接器 (Type-A)



LTEM NO.: DC-002 -165 (Series)

(L11.2×W5.0×H7.2 DC-CONNECTORS)


表面插装 DIP

側向操作 LATERAL

精密部品 NICETY

可靠 STABILIZE

適合環保 RoHS

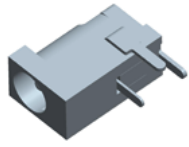


Technical parameter




LEVEL		PROJECT	
		A[better product]	B[average product]
Electrical Properties	Contact Rating	1A, 24V DC	
	Initial Contact Resistance	50mΩ max.	
	Insulation Resistance	100MΩ min.500V DC Skey/PD: 100MΩ min.300V DC	
Durable Performance	Withstand Voltage	500V AC for 1 minute	350 V AC for 1 minute
	There No Load	6,000 Cycles	5,000 Cycles
	Rated Load	5,000 Cycles	4,000 Cycles
Storage temp.		-35℃~+75℃(Operating Temp:)	
Operating Force		IF:35N MAX. (EF:10.0N MIN.)	
Heat Rrsistance		IR Reflow:235℃,5sec. Manual:350℃,3sec.	

Unit:mm

CIRCUIT DIAGRAM

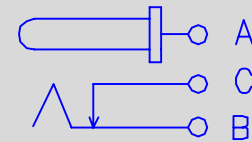

PIN DIM A	1.0mm	1.3mm	1.65mm
-----------	-------	-------	--------

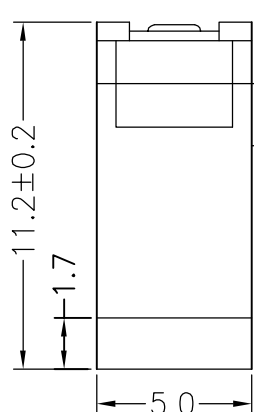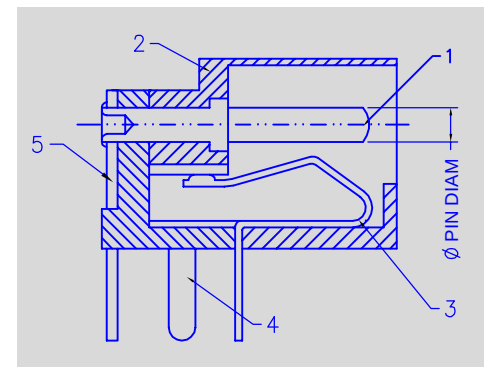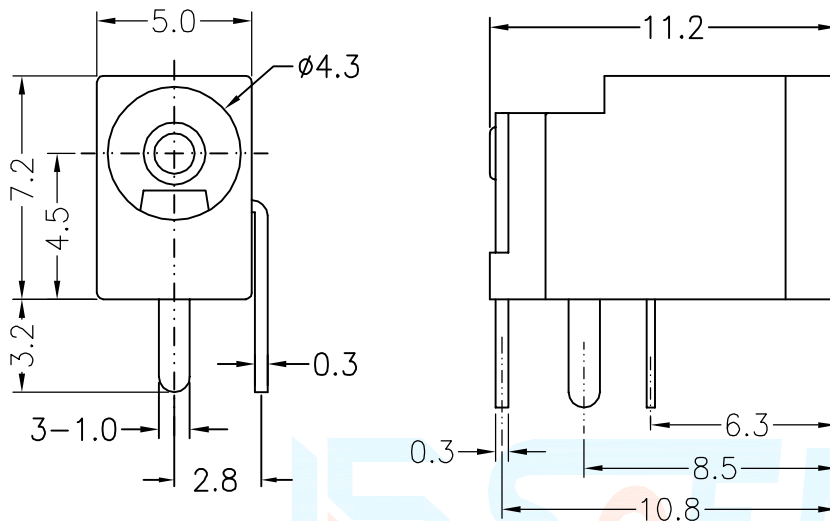

P.C.B LAYOUT



邀您使用(微信)小程序
碩方电子开关&连接器选型手册
手机扫码即可进入...

