

Operation: DIP/直立式 阻燃 DC 电源连接器 (Type-A)



ITEM NO.: DC-013-X20 (Series)

(L15.0×W9.0×H11.0 DC-CONNECTORS)

表面插装 DIP

正向操作

精密部品 NICETY

可靠 STABILIZE

適合環保 RoHS


Technical parameter

PROJECT		LEVEL	A[better product]	B[average product]
Electrical Properties	Contact Rating		25mA, 24V DC	
	Initial Contact Resistance		50mΩ max.	
	Insulation Resistance		100MΩ min.500V DC Skey/PD: 100MΩ min.300V DC	
Durable Performance	Withstand Voltage		500V AC for 1 minute	350 V AC for 1 minut
	There No Load		6,000 Cycles	5,000 Cycles
	Rated Load		5,000 Cycles	4,000 Cycles
	Storage temp.		-35℃~+75℃(Operating Temp:)	
	Operating Force		IF:35N MAX. (EF:10.0N MIN.)	
	Heat Rrsistance		IR Reflow:235℃,5sec. Manual:350℃,3sec.	





Material declaration

No.	NAME	Description
① A	基座	PA66 热塑性塑胶[黑色]
② B	后盖	酚醛胶板[黄色]
③ C	内芯针	锰钢[镀锡 50u" min]
④ D	连接片	黄铜 C2680/SPCC[镀锡 50u" min]
⑤ E	动态端子	磷铜 C5191[镀银]
⑥ F	静态端子	黄铜 C2680/SPCC[镀锡 50u" min]

CIRCUIT DIAGRAM

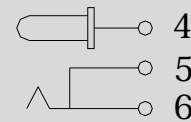

Unit:mm

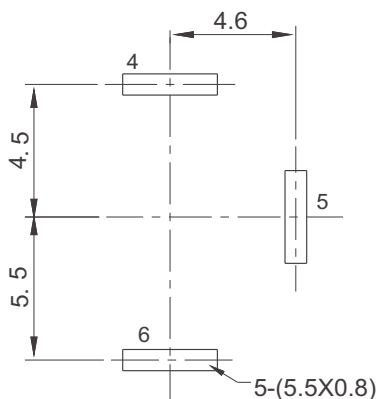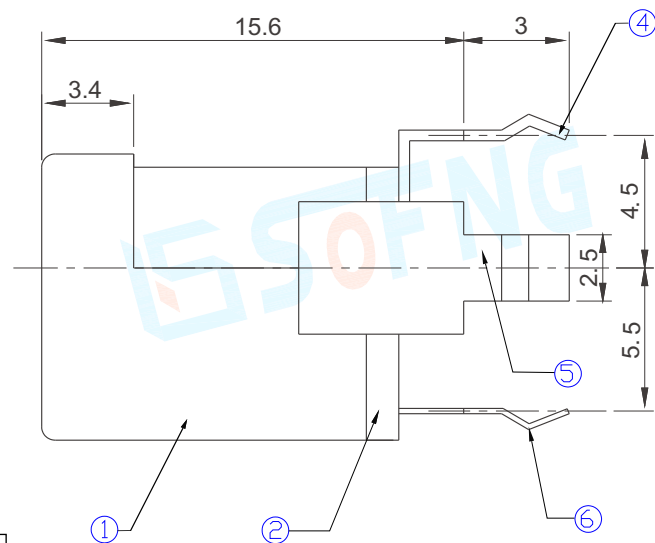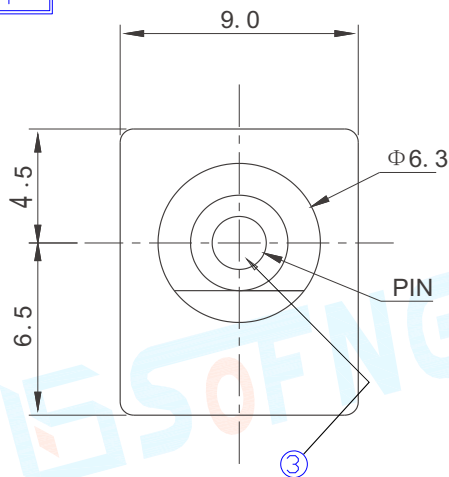 

P.C.B LAYOUT



邀您使用(微信)小程序
碩方电子开关&连接器选型手册
手机扫码即可进入...

PIN DIAM

1. 65mm

2. 00mm

2. 50mm

