



Technical parameter

LEVEL		A[better product]		B[average product]	
PROJECT					
Electrical Properties	Contact Rating	3A, 12V DC			
	Initial Contact Resistance	50mΩ max.			
	Insulation Resistance	100MΩ min.500V DC	Skey/PD: 100MΩ min.300V DC		
	Withstand Voltage	500V AC for 1 minute	350 V AC for 1 minut		
	There No Load	6,000 Cycles	5,000 Cycles		
Durable Performance	Rated Load	5,000 Cycles	4,000 Cycles		
	Storage temp.	-35℃～+75℃(Operating Temp:)			
Operating Force		1F:35N MAX. (EF:10.ON MIN.)			
Heat Rrsistance		IR Reflow:235℃, 5sec. Manual:350℃, 3sec.			

DC-028S - XXX

一 产品型号

—芯材质/直径
T20=铜2.0mm
T25=铜2.5mm

LTEM NO.:DC-028S (Series)

(L11.8×W10.0×H9.1 DC-CONNECTORS)

No.	NAME	Description
① A	基座	PPA 热塑性塑胶 [黑色]
② B	卡件	PPA 热塑性塑胶 [黑色]
③ C	静态端子	黄铜 H62 [镀银/锡基 50u" min]
④ D	动态端子	磷铜 H65 [镀银/锡基 50u" min]
⑤ E	前盖	不锈钢 SUS304
⑥ F	外壳	黄铜 H62 [镀银/锡基 50u" min]
⑦ G	内芯针	H62 黄铜 Φ 2/2.5 [镀银]

沉板插装 DIP

 
側向操作

精密部品 NICETY


可靠 STABILIZE

適合環保 RoHS


CIRCUIT DIAGRAM




Unit:mm

 

MATING PLUG
Jack Insertion Depth: 8.2 mm

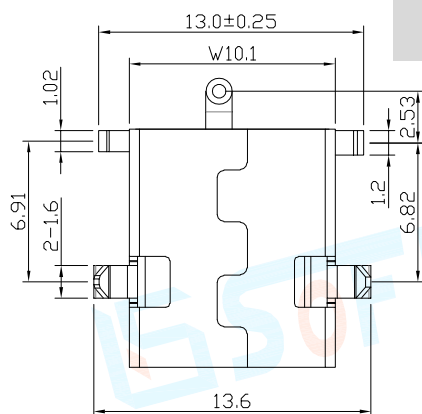

邀您使用(微信)小程序
硕方电子开关&连接器选型手册
手机扫码即可进入...

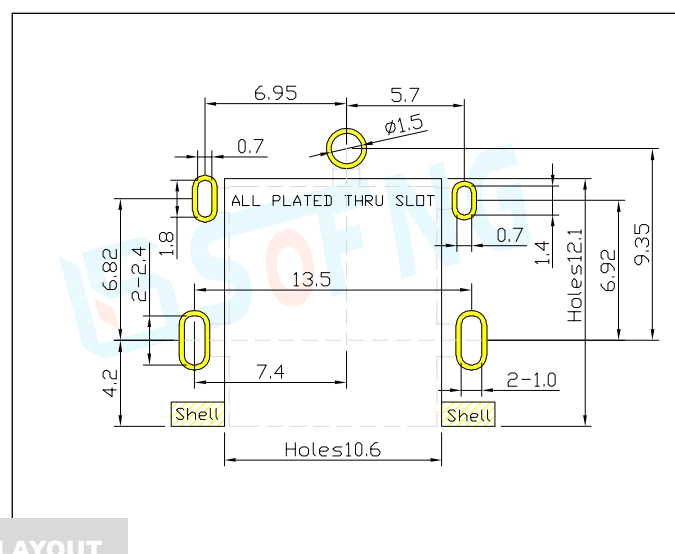

3 LAYOUT

