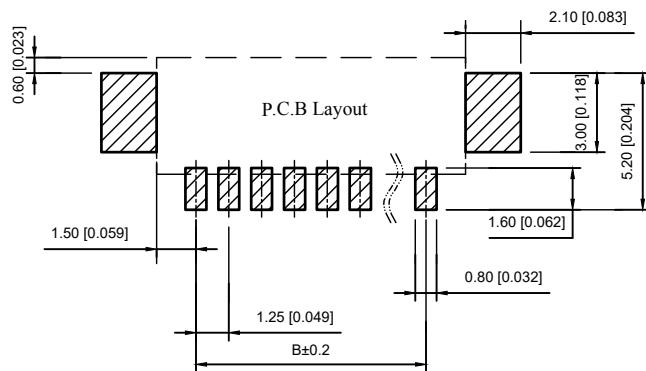
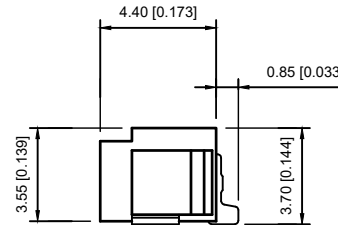
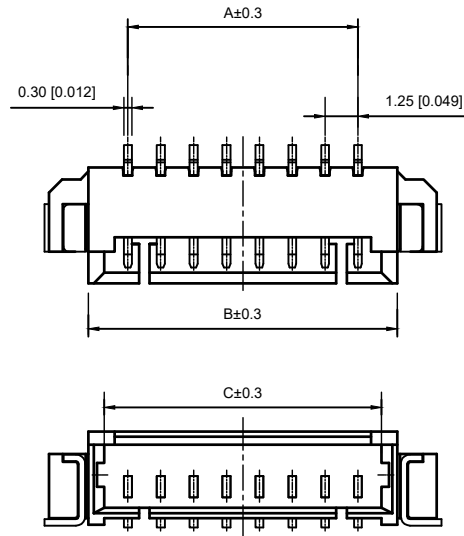


■ Specifications :

- Voltage rating: 125V AC / DC
- Current rating: 1A AC / DC
- Withstanding voltage: 250V AC/minute
- Temperature range: -25°C~+85°C
- Insulation resistance: $\geq 100M\Omega$
- Contact resistance: $\leq 20m\Omega$
- After environmental testing : $\leq 40m\Omega$

X9821 W R S-11-9T SN

- ① Series No.
- ② Category : W-WAFER
- ③ Welding Board Angle : R-Straight 90°
- ④ Welding Way:S-SMT
- ⑤ Row No.-Pin No.: XX-02P~16P
- ⑥ Material : 9T-PA9T 94V-0
- ⑦ Plating Category: Sn-Bright Tin Plating

Poles	Dimensions(mm)			Poles	Dimensions(mm)		
	A	B	G		A	B	G
02	1.25	4.25	3.05	12	13.75	16.75	16.65
03	2.50	5.50	4.30	13	15.00	18.00	18.80
04	3.75	6.75	5.55	14	16.25	19.25	19.05
05	5.00	8.00	6.80	15	17.50	20.50	19.30
06	6.25	9.25	8.05	16	18.75	21.75	20.55
07	7.50	10.50	9.30				
08	8.75	11.75	10.55				
09	10.00	13.00	11.80				
10	11.25	14.25	13.05				
11	12.50	15.50	14.30				

X9821WRS-11-9TSN	PA9T UL 94V-0	Brass	Tin-Plated	X9821H
PART NO	Material	Material(pin)	Finish(pin)	Suitable XKB Housing

							DSND		DATE		SCALE: N/A	MODEL TYPE: 1.25mm Crimp Style Connectors		
					ANGLAR	±5°	DWN		DATE		VIEW: 	PART NO.: X9821WRS-11-9TSN		
ΔX					L ≤ 4	±0.2	CHKD		DATE		UNIT: mm/in	DWG NO.: X-X9821WRS-11-9TSN		
ΔX					4<L ≤ 16	±0.3								
ΔX					16<L ≤ 63	±0.4								
MARK	DESCRIPTION			DATE	REVISED	APPROVED			DATE		SIZE: A4			
REVISIONS						UNSPECIFIED TOLERANCES		XKB INDUSTRIAL PRECISION CO.,LIMITED				WEIGHT	SHEET	REVISION
www.xk-dg.cn www.helloxkb.com www.helloxkb.cn												1.0g	1/1	A0