

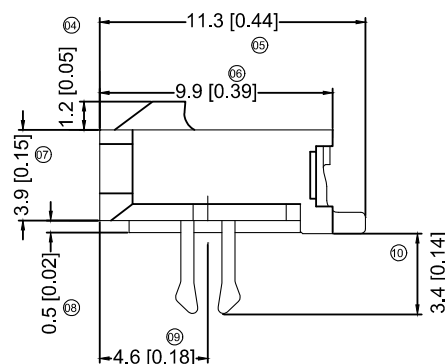


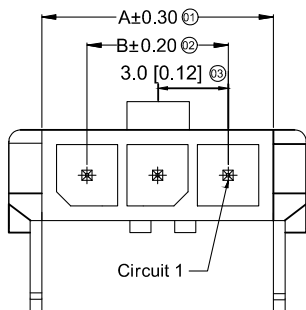

■ Specifications :

- Voltage rating: 250V AC / DC
- Current rating: 5A AC / DC
- Withstanding voltage: 1000V AC/minute
- Temperature range: -25°C~+85°C
- Insulation resistance: $\geq 1000\text{M}\Omega$
- Contact resistance: $\leq 10\text{m}\Omega$
- After environmental testing : $\leq 20\text{m}\Omega$

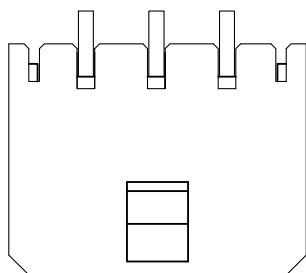

X3025 W R S- 06 C-LPSW

- | | | | | | | | | |
|----|--------------------------------------|----|----|----|----|----|----|----|
| 01 | 02 | 03 | 04 | 05 | 06 | 07 | 08 | 09 |
| 01 | Series No. | | | | | | | |
| 02 | Category : W-wafer | | | | | | | |
| 03 | Welding Board Angle: R-90° | | | | | | | |
| 04 | Welding Way: S-SMT | | | | | | | |
| 05 | Row No.-Pin No. : XX-Single row | | | | | | | |
| 06 | Special NO.: C- The harpoon | | | | | | | |
| 07 | Material: LP-LCP 94V-0 66-PA66 94V-0 | | | | | | | |
| 08 | Planting Category: | | | | | | | |
| | SN-Bright tin plating 70U" | | | | | | | |
| | SW-Fog Tin plating | | | | | | | |
| 09 | Color : Blank-natural color | | | | | | | |

3025WRS-06C-LPSW	LCP UL 94V-0	Brass	Tin Plating Fog	Brass	Tin-Plated	X3025H
3025 WRS --06C-LPSN	LCP UL 94V-0		Tin-Plated			
3025 WRS-06C-66SN	PA66 UL 94 V-0					
PART NO	Material	Material(Pin)	Finish(Pin)	Material (Solder Tabs)	Finish (Solder Tabs)	Mates With XKB Housing

							DSND		DATE		SCALE: N/A	MODEL TYPE: 3.00mm Crimp Style Connectors		
Δx				XKB	ANGLAR	$\pm 5^{\circ}$	DWN		DATE		VIEW: 	PART NO.: X3025WRS-06C-LPSW		
Δx					$L \leq 4$	± 0.2	CHKD		DATE		UNIT: mm/in	DWG NO.: X3025WRS-06C-LPSW		
Δx					$4 < L \leq 16$	± 0.3	APPD		DATE		SIZE: A4			
Δx					$16 < L \leq 63$	± 0.4								
MARK	DESCRIPTION			DATE	REVISED	APPROVED								
REVISIONS						UNSPECIFIED TOLERANCES								
www.helloxkb.com						XKB INDUSTRIAL PRECISION CO.,LIMITED						WEIGHT 1.0g	SHEET 1/1	REVISION A0