
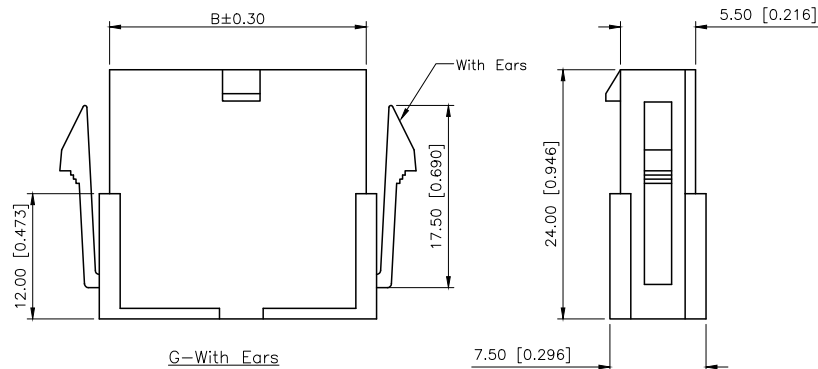


A

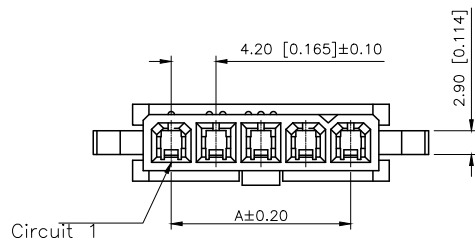

| REVISIONS |         |          |                 |            |        |
|-----------|---------|----------|-----------------|------------|--------|
| REV.      | ECN NO. | LOCATION | DESCRIPTION     | DATE       | DESIGN |
| A0        | N/A     |          | INITIAL RELEASE | /          | /      |
| A1        | N/A     |          | 图面升级整理图面        | 2024.07.27 | 阿树     |

PART NO.:

X9357 H F-02 G N2 XX  
① ② ③ ④ ⑤ ⑥ ⑦

Specifications:

Voltage rating:600V AC/DC

Current rating:9A AC/DC

Withstanding voltage:1500V AC/minute

Temperature range:-45℃-+125℃

Insulation resistance:≥1000MΩ



Contact resistance:≤10mΩ

After environmental testing:≤20mΩ

- ① Series No  
② Category:H-HSG  
③ Welding Board Angle:F-Female  
④ Row No-Pin No: XX-02P~12P  
⑤ Plug the Pin & special No:  
I-Without the Wing; G-With Ears  
⑥ Material:N0-PA66 UL94V-0;N2-PA66 94V-2  
⑦ Color: Blank-Natural Color

B

C

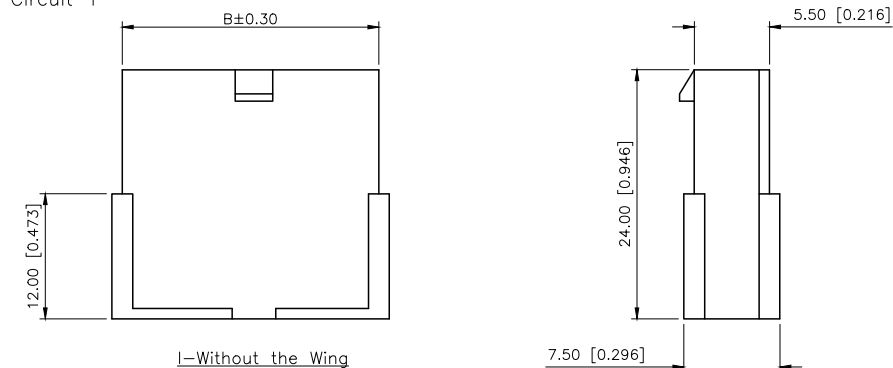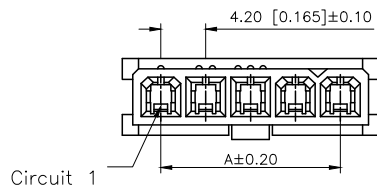

| Poles | Dimensions(mm) |       | Poles | Dimensions(mm) |       |
|-------|----------------|-------|-------|----------------|-------|
|       | A              | B     |       | A              | B     |
| 02    | 4.20           | 9.80  | 08    | 29.40          | 35.00 |
| 03    | 8.40           | 14.00 | 09    | 33.60          | 39.20 |
| 04    | 12.60          | 18.20 | 10    | 37.80          | 43.40 |
| 05    | 16.80          | 22.40 | 11    | 42.00          | 47.60 |
| 06    | 21.00          | 26.60 | 12    | 46.20          | 51.80 |
| 07    | 25.20          | 30.80 |       |                |       |

|                |                |                          |                          |              |
|----------------|----------------|--------------------------|--------------------------|--------------|
| X9357HF-02G-N2 | Nylon 66 94v-2 | X9357TM                  | X9357M Or<br>X9357H      | With Ears    |
| X9357HF-02I-N2 |                |                          |                          | Without Ears |
| X9357HF-02G-N0 | Nylon 66 94v-0 |                          |                          | With Ears    |
| X9357HF-02I-N0 |                |                          |                          | Without Ears |
| PART NO        | Material       | Suitable XKB<br>Terminal | Suitable XKB<br>Terminal | Note         |

|                        |       |
|------------------------|-------|
| AuGLAR                 | ±5°   |
| X.                     | ±0.40 |
| X.x                    | ±0.30 |
| X.xx                   | ±0.20 |
| X.xxx                  | ±0.15 |
| UNSPECIFIED TOLERANCES |       |



|          |    |             |                                               |
|----------|----|-------------|-----------------------------------------------|
| DESIGN   | 阿树 | VIEW:       | MODEL TYPE:<br>4.20 mm Crimp Style Connectors |
| CHECKED  |    | UNIT: mm/in | PART NO.:<br>X9357HF-02G-N2                   |
| APPROVED |    | SIZE: A4    | DWG NO.:<br>X-X9357HF-02G-N2                  |

D

D