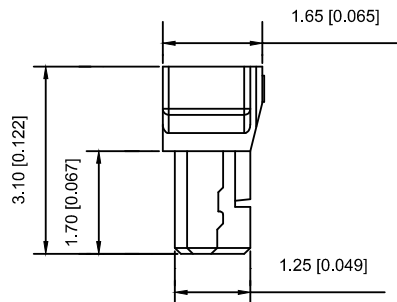
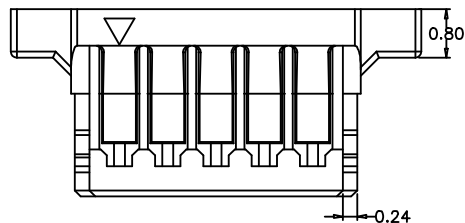
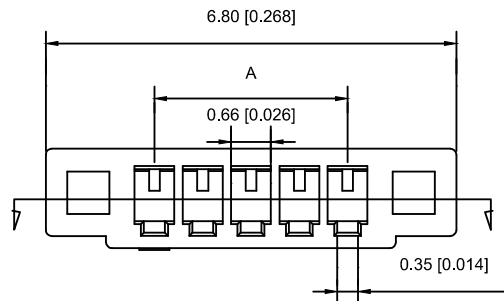
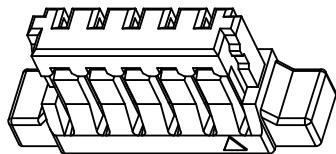


Specifications :

- Voltage rating: 30 V AC / DC
- Current rating: 0.5A AC / DC
- Withstanding voltage: 200V AC/minute
- Temperature range: -25°C~+85°C
- Insulation resistance: $\geq 100M\Omega$
- Contact resistance: $\leq 20m\Omega$
- After environmental testing: $\leq 40m\Omega$

X0800 H-06 -46 HF
① ② ③ ④ ⑤

- ① Series No.
② Category : H-HSG
③ Row No.Pin No.XX-02P~20P
④ Material: 46-PA46 94V-0
⑤ HF-Halogen Free

Poles	Dimensions(mm)			Poles	Dimensions(mm)		
	A	B	C		A	B	C
02	0.80	1.80	4.40	12	8.80	9.80	12.40
03	1.60	2.60	5.20	13	9.60	10.6	13.2
04	2.40	3.40	6.00	14	10.4	11.4	14.0
05	3.20	4.20	6.80	15	11.2	12.2	14.8
06	4.00	5.00	7.60	16	12.0	13.0	15.6
07	4.80	5.80	8.40	17	12.8	13.8	16.4
08	5.60	6.60	9.20	18	13.6	14.6	17.2
09	6.40	7.40	10.0	19	14.4	15.4	18.0
10	7.20	8.20	10.8	20	15.2	16.2	18.8
11	8.00	9.00	11.6				

X0800H-02-46HF	PA46 UL 94V-0 Halogen Free	X0800T	X0800W
PART NO	Material(Wafer)	Suitable XKB Terminal	Suitable XKB Terminal

							DSND		DATE		SCALE: N/A	MODEL TYPE: 0.8mm Crimp Style Connectors			
Δ x					ANGLAR	$\pm 5^{\circ}$	DWN		DATE		VIEW: 	PART NO.: X0800H-06-46HF			
Δ x					$L \leq 4$	± 0.2	CHKD		DATE		UNIT: mm/in	DWG NO.: X-X0800H-06-46HF			
Δ x					$4 < L \leq 16$	± 0.3	APPD		DATE		SIZE: A4				
Δ x					$16 < L \leq 63$	± 0.4									
MARK	DESCRIPTION			DATE	REVISED	APPROVED	$L > 63$	± 0.5							
REVISIONS							UNSPECIFIED TOLERANCES								
www.xk-dg.cn www.helloxkb.com www.helloxkb.cn							XKB INDUSTRIAL PRECISION CO.,LIMITED						WEIGHT 1.0g	SHEET 1/1	REVISION A0