

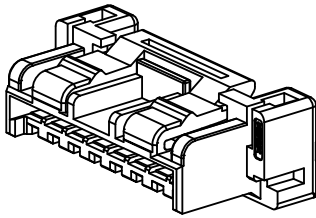
 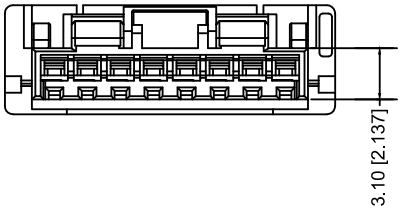
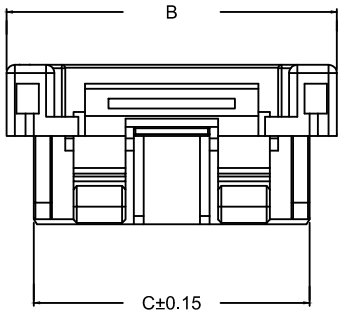


XKB



Specifications:
规格:
Voltage rating:250V
AC/DC XKB
额定电压: 250V AC/DC
Current rating:3A AC/DC
额定电流: 3A AC/DC
Withstanding
voltage:800V AC/minute
耐受电压: 800V AC/分钟
Temperature
range:-40℃-+105℃
温度范围: -40℃-+105℃
Insulation
resistance:≥1000MΩ
绝缘电阻: ≥1000MΩ
Contact resistance:≤20mΩ
接触电阻: ≤20mΩ
After environmental XKB
testing:≤40mΩ
环境测试后: ≤40兆欧

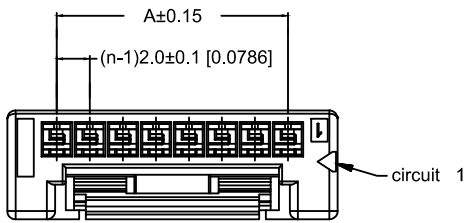

 
2P-7P



5P-7P外观形状

X2023 H -08 -N0
① ② ③ ④


- ①Series No.
- ②Category:H-HSG
- ③Row No.Pin No.: XX-02P-15P;
- ④Material:N0 -PA66 94V-0



11P-15P外观形状




 8P-15P外观形状




2P-4P外观形状

Poles	Dimension mm			Poles	Dimension mm		
	A	B	C		A	B	C
2	2.00	8.00	4.70	09	16.00	22.00	18.70
3	4.00	10.00	6.70	10	18.00	24.00	20.70
4	6.00	12.00	8.70	11	20.00	26.00	22.70
5	8.00	14.00	10.70	12	22.00	28.00	24.70
6	10.00	16.00	12.70	13	24.00	30.00	26.70
7	12.00	18.00	14.70	14	26.00	32.00	28.70
8	14.00	20.00	16.70	15	28.00	34.00	30.70

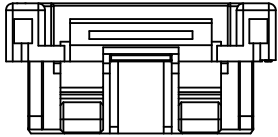

5P-15P 锁扣形状

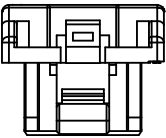

锁扣形状

X2023H-08 -N0	PA66 UL 94V-0	X2023T	X2023W
PART N0	Material	Suitale XKB Teminal	Suitale XKB Wafer

					ANGLAR	±5°
ΔX					L≤ 4	±0.2
ΔX					4<L≤ 16	±0.3
ΔX					16<L≤ 63	±0.4
MARK					L> 63	±0.5
DESCRIPTION					DATE	REVISED
REVISIONS					APPROVED	
					UNSPECIFIED TOLERANCES	

www.helloxkb.com www.helloxkb.cn www.xk-dg.cn

由 AUTODESK 学生版生成

XKB

XKB INDUSTRIAL PRECISION CO.,LIMITED

DSND		SCALE: N/A	MODEL TYPE: 2.0 mm Crimp Style Connectors		
DWN		VIEW: 	PART NO.: X2023H-08-N0		
CHKD		UNIT: mm/in	DWG NO.: X-X2023H-08-N0		
APPD		SIZE: A4			
PRECISION CO.,LIMITED			WEIGHT	SHEET	REVISION
				1/1	A0