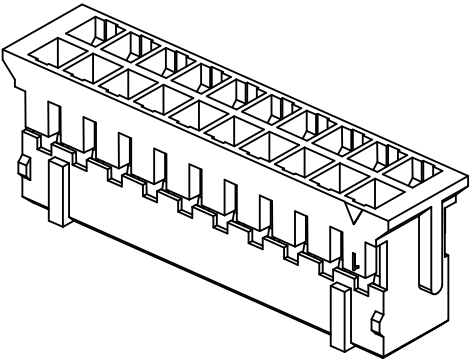
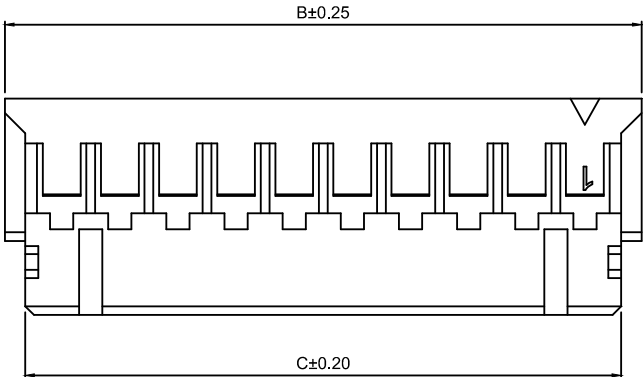
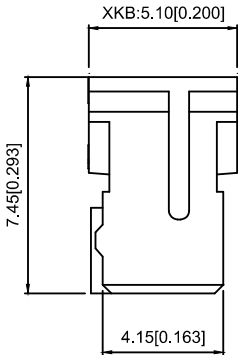
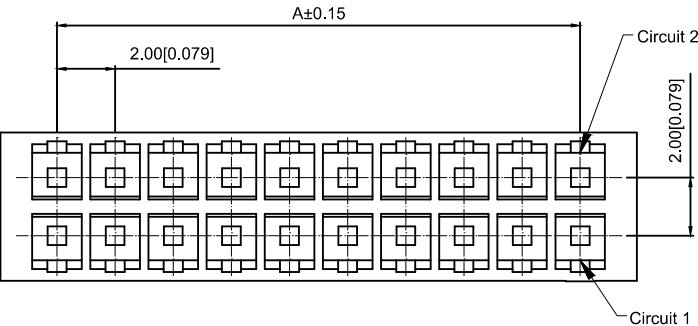


Specifications:
规格:
Voltage rating:250V AC/DC
额定电压: 250V AC/DC
Current rating:3A AC/DC
额定电流: 3A AC/DC
Withstanding voltage:800V AC/minute
耐受电压: 800V AC/分钟
Temperature range:-25℃-+85℃
温度范围: -25℃-+85℃
Insulation resistance:≥1000MΩ
绝缘电阻: ≥1000MΩ
Contact resistance:≤10mΩ
接触电阻: ≤10mΩ
After environmental testing:≤20mΩ
环境测试后: ≤20兆欧

X2026 H - 2x09 HF-N0

① ②③ ④ ⑤ ⑥ ⑦

- 1.Series No
- 2.Category:H-HSG
- 3.Appearance type:Blank-Ordinary
- 4.Row No-Pin No:2xXX-2x02P~2x22P
- 5.Plug the Pin&special No:
HF-Halogen Free
- 6.Material:NO-PA66 94V-0
- 7.Color:Blank-Natural Color
BK-Black

poles	Dimensions(mm)			poles	Dimensions(mm)			Poles	Dimensions(mm)		
	A	B	C		A	B	C		A	B	C
2x02	2.00	5.90	4.50	2x09	16.00	19.90	18.50	2x16	30.00	33.90	32.50
2x03	4.00	7.90	6.50	2x10	18.00	21.90	20.50	2x17	32.00	35.90	34.50
2x04	6.00	9.90	8.50	2x11	20.00	23.90	22.50	2x18	34.00	37.90	36.50
2x05	8.00	11.90	10.50	2x12	22.00	25.90	24.50	2x19	36.00	39.90	38.50
2x06	10.00	13.90	12.50	2x13	24.00	27.90	26.50	2x20	38.00	41.90	40.50
2x07	12.00	15.90	14.50	2x14	26.00	29.90	28.50	2x21	40.00	43.90	42.50
2x08	14.00	17.90	16.50	2x15	28.00	31.90	30.50	2x22	42.00	45.90	44.50

X2026H-2x09-N0BK	Nylon 66 UL 94V-0 Black	X2026T	X2026W
X2026H-2x09HF-N0	Nylon 66 UL 94V-0 Halogen Free		
X2026H-2x09-N0	Nylon 66 UL 94V-0		
PART NO	Material	Suitable XKB Terminal	Suitable XKB Wafer

Wire to board connector

						DSND		DATE		SCALE: N/A	MODEL TYPE:			
						DWN		DATE		VIEW: 	2.00mm Crimp Style Connectors			
Δx					units: mm	CHKD		DATE		UNIT: mm/in	PART NO.: X2026H-2x09HF-N0			
Δx					tolerance:									
Δx					X.X ±0.2mm									
Δx					X.XX ±0.1mm	APPD		DATE		SIZE: A4	DWG NO.: X-X2026H-2x09HF-N0			
MARK	DESCRIPTION	DATE	REVISED	APPROVED	X.XXX ±0.05mm									
REVISIONS						UNSPECIFIED TOLERANCES						XKB INDUSTRIAL PRECISION CO.,LIMITED		
www.xk-dg.cn www.helloxkb.com www.helloxkb.cn														
												WEIGHT	SHEET	REVISION
												1.0g	1/1	A0