

1



2

3

4

A

A

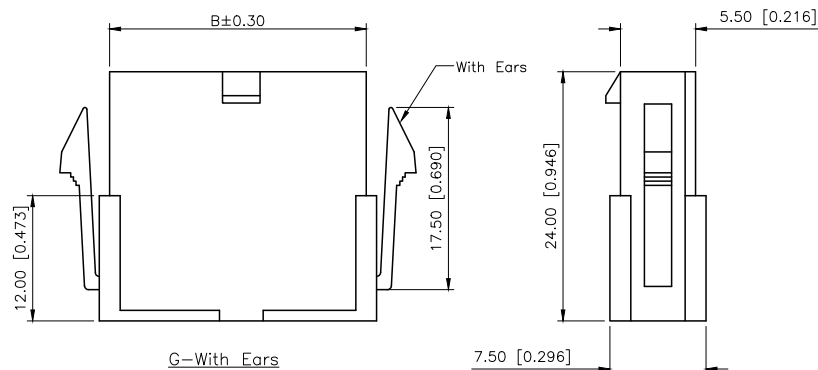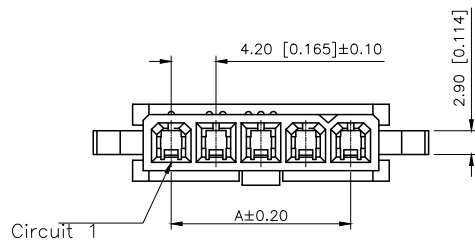

| REVISIONS |         |          |                 |            |        |
|-----------|---------|----------|-----------------|------------|--------|
| REV.      | ECN NO. | LOCATION | DESCRIPTION     | DATE       | DESIGN |
| A0        | N/A     |          | INITIAL RELEASE | /          | /      |
| A1        | N/A     |          | 图面升级整理图面        | 2024.07.27 | 阿树     |

PART NO.:



X9357 H F-02 I N2 XX  
① ② ③ ④ ⑤ ⑥ ⑦

Specifications:  
Voltage rating:600V AC/DC  
Current rating:9A AC/DC  
Withstanding voltage:1500V AC/minute  
Temperature range:-45℃-+125℃  
Insulation resistance:≥1000MΩ  
Contact resistance:≤10mΩ  
After environmental testing:≤20mΩ

- ① Series No
- ② Category:H-HSG
- ③ Welding Board Angle:F-Female
- ④ Row No-Pin No: XX-02P~12P
- ⑤ Plug the Pin & special No:  
I-Without the Wing; G-With Ears
- ⑥ Material:N0-PA66 UL94V-0;N2-PA66 94V-2
- ⑦ Color: Blank-Natural Color

B

B

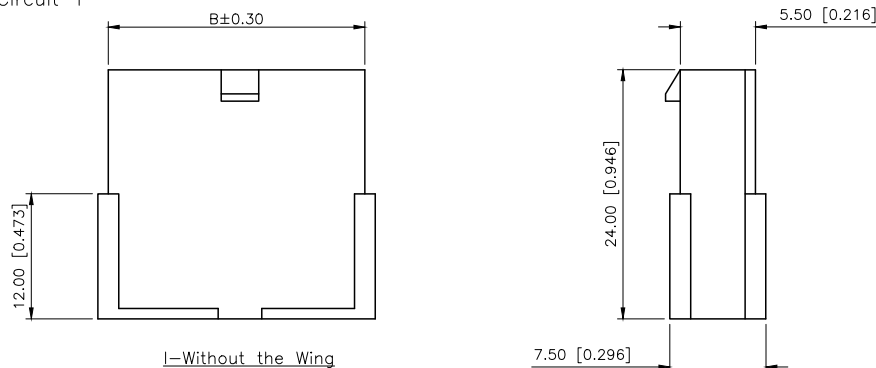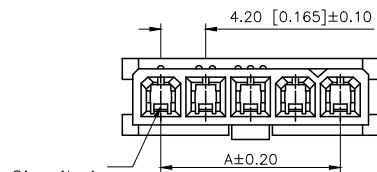

| Poles | Dimensions(mm) |       | Poles | Dimensions(mm) |       |
|-------|----------------|-------|-------|----------------|-------|
|       | A              | B     |       | A              | B     |
| 02    | 4.20           | 9.80  | 08    | 29.40          | 35.00 |
| 03    | 8.40           | 14.00 | 09    | 33.60          | 39.20 |
| 04    | 12.60          | 18.20 | 10    | 37.80          | 43.40 |
| 05    | 16.80          | 22.40 | 11    | 42.00          | 47.60 |
| 06    | 21.00          | 26.60 | 12    | 46.20          | 51.80 |
| 07    | 25.20          | 30.80 |       |                |       |

C

C

|                |                |                          |                          |              |
|----------------|----------------|--------------------------|--------------------------|--------------|
| X9357HF-02G-N2 | Nylon 66 94v-2 | X9357TM                  | X9357M Or<br>X9357H      | With Ears    |
| X9357HF-02I-N2 |                |                          |                          | Without Ears |
| X9357HF-02G-N0 | Nylon 66 94v-0 |                          |                          | With Ears    |
| X9357HF-02I-N0 |                |                          |                          | Without Ears |
| PART NO        | Material       | Suitable XKB<br>Terminal | Suitable XKB<br>Terminal | Note         |

D

D

|                        |       |
|------------------------|-------|
| AuGLAR                 | ±5°   |
| X.                     | ±0.40 |
| X.x                    | ±0.30 |
| X.xx                   | ±0.20 |
| X.xxx                  | ±0.15 |
| UNSPECIFIED TOLERANCES |       |



|          |    |       |       |             |                                |
|----------|----|-------|-------|-------------|--------------------------------|
| DESIGN   | 阿树 | VIEW: |       | MODEL TYPE: | 4.20 mm Crimp Style Connectors |
| CHECKED  |    | UNIT: | mm/in | PART NO.:   | X9357HF-02I-N2                 |
| APPROVED |    | SIZE: | A4    | DWG NO.:    | X-X9357HF-02I-N2               |

1

2

3

4