
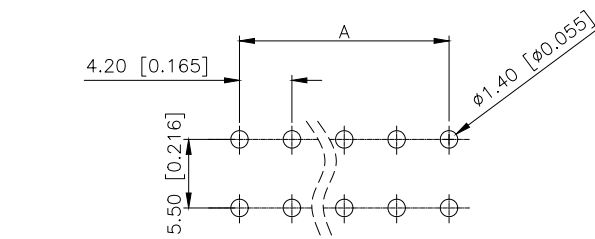
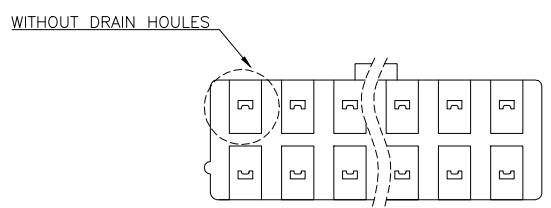




| REVISIONS |         |          |             |            |        |
|-----------|---------|----------|-------------|------------|--------|
| REV.      | ECN NO. | LOCATION | DESCRIPTION | DATE       | DESIGN |
| A1        | N/A     |          | 图面升级整理图面    | 2025.1.4   | 阿树     |
| A2        | N/A     | Ⓐ2 X2    | 产品尺寸及电气性能变更 | 2025.09.10 | 阿树     |

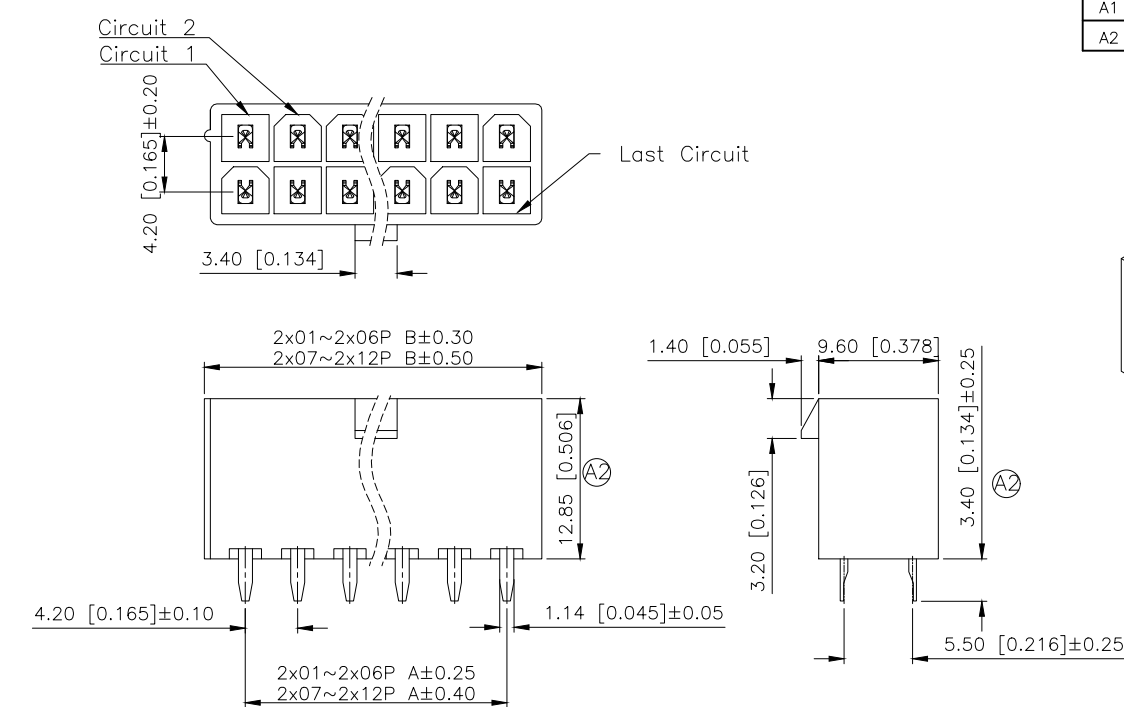

P.C.B. LAYOUT

PART NO.:  
X9357 W V-2x03 HN-N2 SN XX  
① ② ③ ④ ⑤ ⑥ ⑦ ⑧

- ①Series No
- ②Category:W-Wafer
- ③Welding Board Angle:V-Stright 180°
- ④Row No.Pin No:2xXX-2x01P~2x12P
- ⑤Plug the Pln&Specal NO.:HN-The hollow needle
- ⑥Material:N0-PA66 94V-0;  
N2-PA66 94V-2
- ⑦Planting: SN-Bright tin plating
- ⑧Color:Blank-natural color;;B-Black

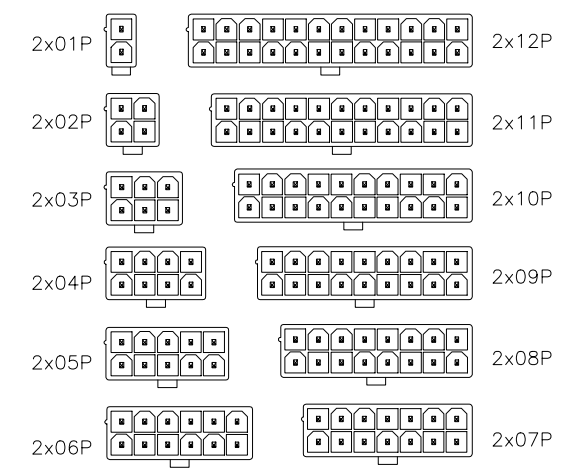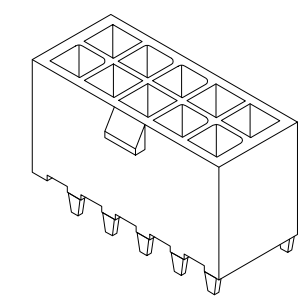

- SPECIFICATIONS
- Voltage rating:600V AC/DC
  - Current rating:7A AC/DC
  - Withstanding Voltage:1500V AC/minute
  - Temperature range:-40°C+125°C
  - Insulation resistance:≥1000MΩ
  - Contact resistance:≤20mΩ

| Poles | Dimensions(mm) |       |
|-------|----------------|-------|
|       | A              | B     |
| 2x01  | —              | 5.60  |
| 2x02  | 4.20           | 9.80  |
| 2x03  | 8.40           | 14.00 |
| 2x04  | 12.60          | 18.20 |
| 2x05  | 16.80          | 22.40 |
| 2x06  | 21.00          | 26.60 |
| 2x07  | 25.20          | 30.80 |
| 2x08  | 29.40          | 35.00 |
| 2x09  | 33.60          | 39.20 |
| 2x10  | 37.80          | 43.40 |
| 2x11  | 42.00          | 47.60 |
| 2x12  | 46.20          | 51.80 |

|                      |                            |               |             |                       |
|----------------------|----------------------------|---------------|-------------|-----------------------|
| X9357WV-2x03HN-N2SN1 | Nylon 66 UL 94V-2          | Brass         | Tin-Plated  | X9357H                |
| X9357WV-2x03HN-N2SNB | Nylon 66 UL 94V-2<br>Black |               |             |                       |
| X9357WV-2x03HN-N2SN  | Nylon 66 UL 94V-2          |               |             |                       |
| X9357WV-2x03HN-N0SN  | Nylon 66 UL 94V-0          |               |             |                       |
| PARE NO              | Material                   | Material(Pin) | Finish(Pin) | Suitable XKB Terminal |

|                        |       |
|------------------------|-------|
| AuGLAR                 | ±5°   |
| X.                     | ±0.40 |
| X.x                    | ±0.30 |
| X.xx                   | ±0.20 |
| X.xxx                  | ±0.15 |
| UNSPECIFIED TOLERAUCES |       |



|          |    |             |                                               |
|----------|----|-------------|-----------------------------------------------|
| DESIGN   | 阿树 | VIEW:       | MODEL TYPE:<br>4.20 mm Crimp Style Connectors |
| CHECKED  |    | UNIT: mm/in | PART NO.:<br>X9357WV-2x03HN-N2SN              |
| APPROVED |    | SIZE: A4    | DWG NO.:<br>X-X9357WV-2x03HN-N2SN             |

XKB INDUSTRIAL PRECISION CO.,LIMITED

|       |      |          |
|-------|------|----------|
| SCALE | PAGE | REVISION |
| N/A   | 1/1  | A2       |