
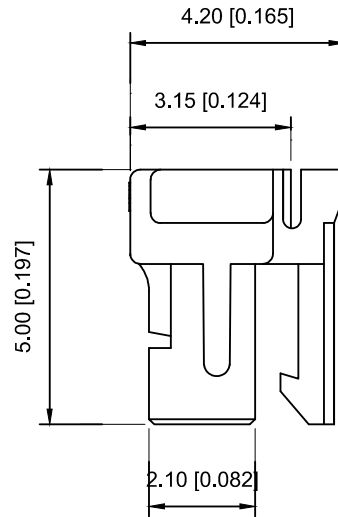
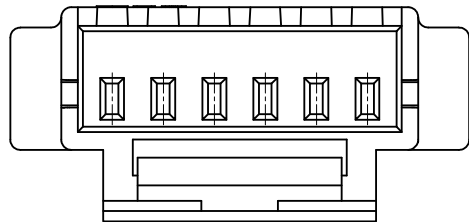
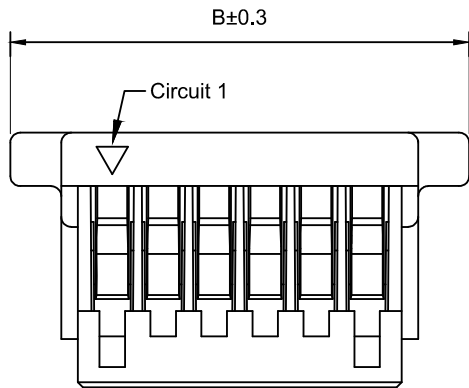


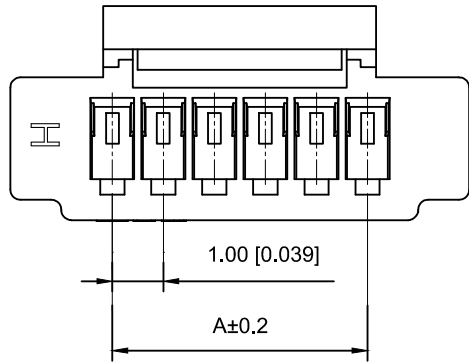

Specifications :

- Voltage rating: 50 V AC / DC
- Current rating: 1A AC / DC
- Withstanding voltage: 500V AC/minute
- Temperature range: -25°C~+85°C
- Insulation resistance: $\geq 100M\Omega$
- Contact resistance: $\leq 20m\Omega$
- After environmental testing: $\leq 40m\Omega$

X1002 H-08 L-N0 HF
① ② ③ ④ ⑤ ⑥

- ① Series No.
- ② Category : H-HSG
- ③ Row No.Pin No.XX-02P-20P
- ④ Special No:L-With Lock
- ⑤ Material:N0-PA66 94V-0
- ⑥ HF-Halogen Free

Poles	Dimensions(mm)		Poles	Dimensions(mm)	
	A	B		A	B
02	1.00	5.00	13	12.00	16.00
03	2.00	6.00	14	13.00	17.00
04	3.00	7.00	15	14.00	18.00
05	4.00	8.00	16	15.00	19.00
06	5.00	9.00	17	16.00	20.00
07	6.00	10.00	18	17.00	21.00
08	7.00	11.00	19	18.00	22.00
09	8.00	12.00	20	19.00	23.00
10	9.00	13.00			
11	10.00	14.00			
12	11.00	15.00			

X1002H-08L-N0HF	PA66 UL 94V-0 Halogen Free	X1002T	X1002W-L
PART NO	Material	Suitable XKB Terminal	Suitable XKB Terminal

							DSND		DATE		SCALE: N/A	MODEL TYPE: 1.0mm Crimp Style Connectors				
Δ X					ANGULAR	$\pm 5^{\circ}$	DWN		DATE		VIEW: 	PART NO.: X1002H-08L-N0HF				
Δ X					$4 < L \leq 16$	± 0.3	CHKD		DATE		UNIT: mm/in	DWG NO.: X-X1002H-08L-N0HF				
Δ X					$16 < L \leq 63$	± 0.4	APPD		DATE		SIZE: A4					
MARK	DESCRIPTION			DATE	REVISED	APPROVED						$L > 63$	± 0.5			
REVISIONS												UNSPECIFIED TOLERANCES				
www.xk-dg.cn www.helloxkb.com www.helloxkb.cn							XKB INDUSTRIAL PRECISION CO.,LIMITED					WEIGHT 1.0g	SHEET 1/1	REVISION A0		