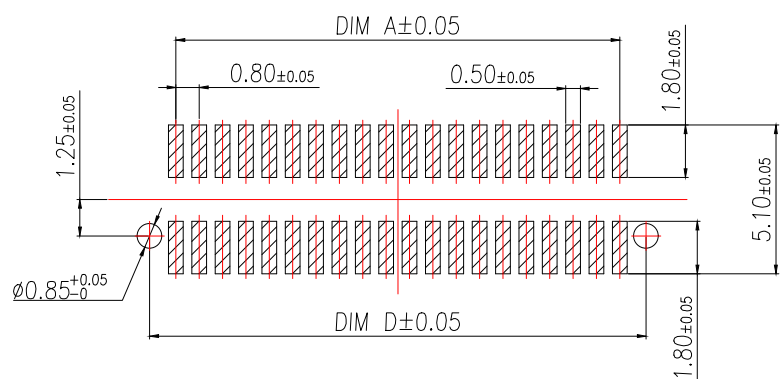


技术指标:

1. 塑件表面应光洁、无毛边、无明显收缩、缺陷、裂纹等现象。
2. 温度范围： $-40^{\circ}\text{C}\sim 85^{\circ}\text{C}$ 。
3. 额定电压： 125V, AC 。
4. 接触电阻： $\leq 0.02\Omega$ 。
5. 绝缘电阻： $\geq 100\text{M}\Omega$

Part No	CKT	A	B	C	D
BX-BTB0.8-35HGE1-4PCZ	2*2	0.80	2.35	3.35	2.60
BX-BTB0.8-35HGE1-6PCZ	2*3	1.60	3.15	4.15	3.40
BX-BTB0.8-35HGE1-8PCZ	2*4	2.40	3.95	4.95	4.20
BX-BTB0.8-35HGE1-10PCZ	2*5	3.20	4.75	5.75	5.00
BX-BTB0.8-35HGE1-12PCZ	2*6	4.00	5.55	6.55	5.80
BX-BTB0.8-35HGE1-14PCZ	2*7	4.80	6.35	7.35	6.60
BX-BTB0.8-35HGE1-16PCZ	2*8	5.60	7.15	8.15	7.40
BX-BTB0.8-35HGE1-18PCZ	2*9	6.40	7.95	8.95	8.20
BX-BTB0.8-35HGE1-20PCZ	2*10	7.20	8.75	9.75	9.00
BX-BTB0.8-35HGE1-22PCZ	2*11	8.00	9.55	10.55	9.80
BX-BTB0.8-35HGE1-24PCZ	2*12	8.80	10.35	11.35	10.60
BX-BTB0.8-35HGE1-26PCZ	2*13	9.60	11.15	12.15	11.40
BX-BTB0.8-35HGE1-28PCZ	2*14	10.40	11.95	12.95	12.20
BX-BTB0.8-35HGE1-30PCZ	2*15	11.20	12.75	13.75	13.00
BX-BTB0.8-35HGE1-32PCZ	2*16	12.00	13.55	14.55	13.80
BX-BTB0.8-35HGE1-34PCZ	2*17	12.80	14.35	15.35	14.60
BX-BTB0.8-35HGE1-36PCZ	2*18	13.60	15.15	16.15	15.40
BX-BTB0.8-35HGE1-38PCZ	2*19	14.40	15.95	16.95	16.20
BX-BTB0.8-35HGE1-40PCZ	2*20	15.20	16.75	17.75	17.00
.....	...	...	...	...	...
BX-BTB0.8-35HGE1-80PCZ	2*40	31.20	32.75	33.75	33.00

[illegible]