

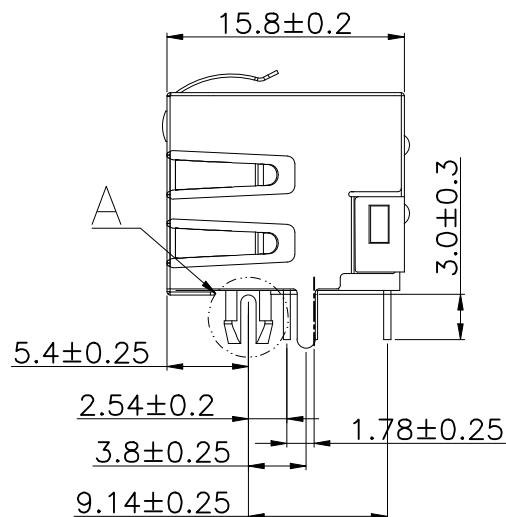
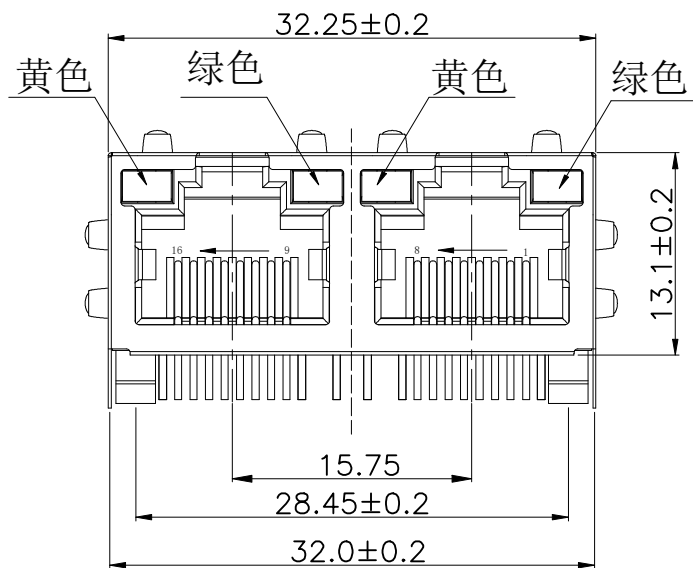
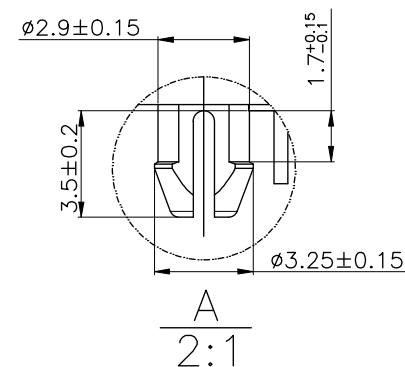


ROHS

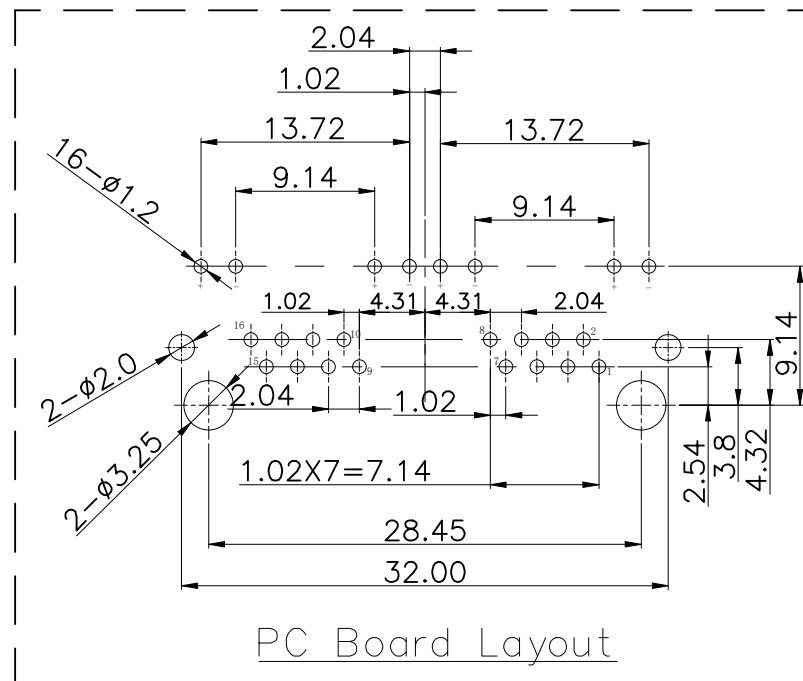

Parameters

1. Rated Voltage & Current: 125V/1.5A max.
2. Contact Resistance: 40mΩ Max.
3. Insulation Resistance: 500MΩ Min.
4. Dielectric Withstand Test: DC 500V for 1 minute.
5. Salt Spray Test: 8±0.5H.
6. Soldering Temperature: 260±5℃, 3±0.5s.

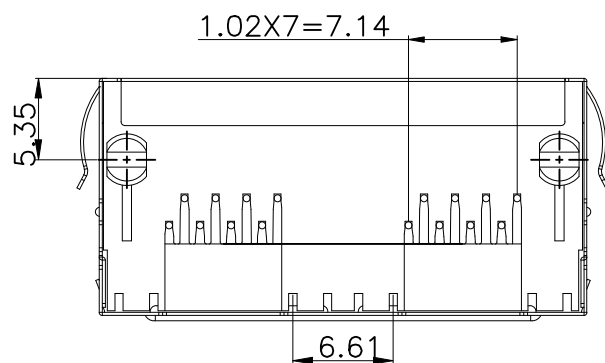

CUSTOMER DRAWING		LAILIAN 深圳市莱联电子有限公司					
DRAWING		SHENZHEN LAILIAN ELECTRONICS CO., LTD					
CHECKED							
APPROVED							
TOLERANCES ARE							
30-150	±0.35	ANGLE	TITLE		网络插座2端口带屏蔽带弹片带灯	REV.	A
10-30	±0.2		PART NO.		LAIL-RJ45-2P-LED4-BY-01G-WC	UNITS	mm
5-10	±0.15		DWG. NO.			Projection	
0-5	±0.1						