





CHIP COMMON MODE CHOKE

- High common mode impedance at high frequency effects excellent excellent noise suppression performance
- Comply with RoHS requirements
- Operating temperature range: -40°C to +105°C
- Storage temperature range: -40°C to +105°C

Electrical Specifications @ 25°C

Part Number	Inductance(uH) 100KHz/0.1v Min	DC Resistance (Ω) max.	Rated Current (mA)	Rated Volt (Vdc)	Withstand Volt. (Vdc)	IR (Ω) min.
CM04002ST-CND	60	1.80	200	50	125	10M


MECHANICAL

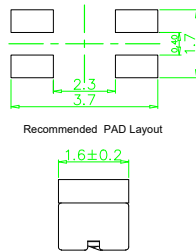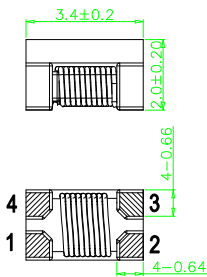


Recommended PAD Layout

Unless otherwise specified all tolerances are ±0.25mm

 
SCHEMATICS




IMPEDEANCE FREQUENCY

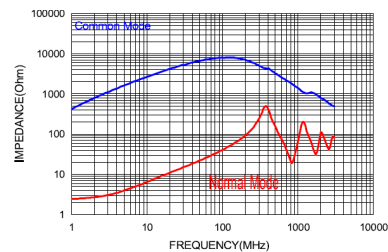

TAPING AND PACKING

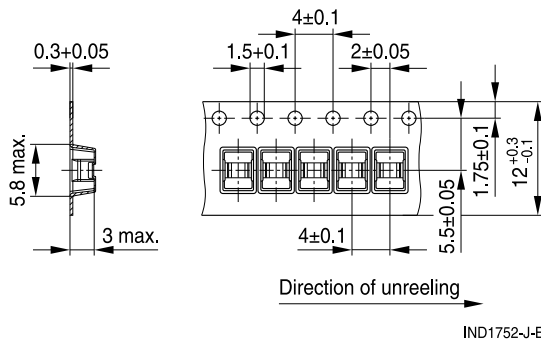

IND1752-J-E

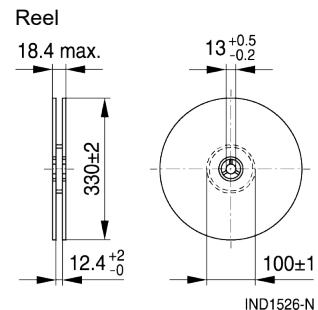

IND1526-N

Dimensions in mm

Quantity (pcs):
3000 PCS PER REEL
10 REELS PER CARTON
30000PCS PER CARTON

Shenzhen magnetic Lianda Electronics Co., LTD

Address: 505, West Block, No. 221, Niucheng Road, Niucheng Village, Baiwang Community, Xili Street, Nanshan District, Shenzhen
Tel: 0755-27652992 29016433 E-mail: sales1@cd-tek.com Website: www.cd-tek.com