

Operation: 立插式/全塑阻燃级主体 大电流 DC 电源连接器**ITEM NO.:**DC-008B (Series)

(L8.5×W7.0×H10.5mm DC-CONNECTORS)

精密部品 NICETY

可靠 STABILIZE


適合環保 RoHS

Technical parameter


LEVEL		A[better product]	B[average product]
PROJECT			
Electrical Properties	Contact Rating	3A, 24V DC	
	Initial Contact Resistance	50mΩ max.	
Durable Performance	Insulation Resistance	100MΩ min.500V DC Skey/PD: 100MΩ min.300V DC	
	Withstand Voltage	500V AC for 1 minute	350 V AC for 1 minute
Storage temp.	There No Load	6,000 Cycles	5,000 Cycles
	Rated Load	5,000 Cycles	4,000 Cycles
Operating Force		IF:35N MAX. (EF:10.0N MIN.)	
Heat Rrsistance		IR Reflow:235℃, 5sec. Manual:350℃, 3sec.	

Material declaration		
No.	NAME	Description
① A	内芯针	H62 黄铜 Φ1.6/2[镀锡 50u" min]
② B	基座	PPA 热塑性塑胶[黑色]
③ C	动态端子	不锈钢 SUS-304 [t=0.25 镀银]
④ D	静态端子	磷铜 C2680/SPCC[镀锡 50u" min]
⑤ E	连接片	磷铜 C2680/SPCC[镀锡 50u" min]

CIRCUIT DIAGRAM

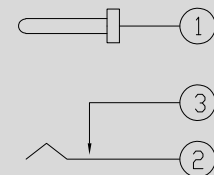

Unit:mm

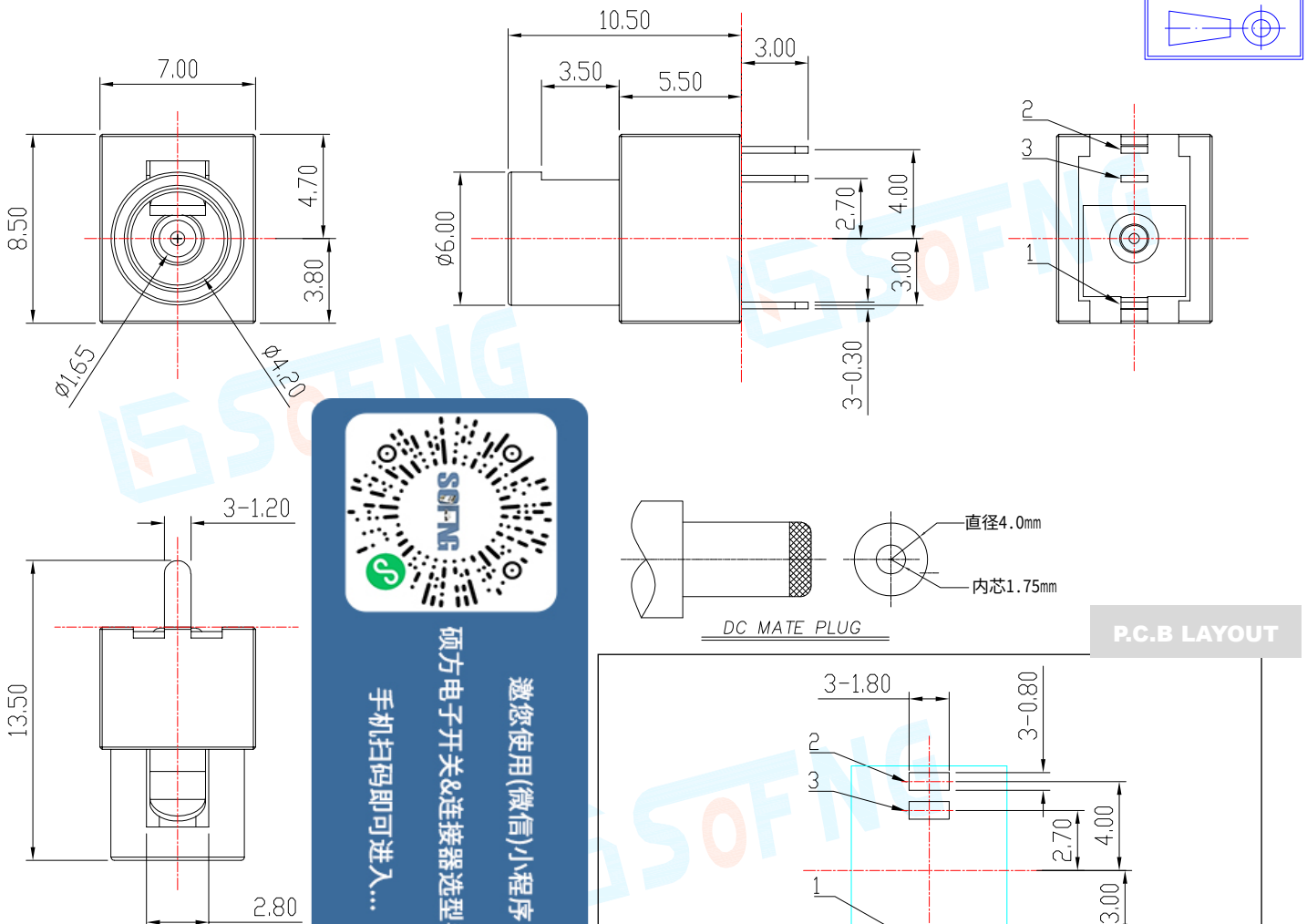

邀您使用(微信)小程序
手机扫码即可进入...

硕方电子开关&连接器选型手册

P.C.B LAYOUT