

Technical parameter

		LEVEL	A[better product]	B[average product]
PROJECT				
Properties	Contact Rating		1.0A, 24V DC	
	Electrical Initial Contact Resistance		50mΩ max.	
	Insulation Resistance		100MΩ min.500V DC	Skey/PD: 100MΩ min.300V DC
	Withstand Voltage		500V AC for 1 minute	350 V AC for 1 minut
	Durable Performance	There No Load	6,000 Cycles	5,000 Cycles
	Rated Load	5,000 Cycles	4,000 Cycles	
	Storage temp.	-35℃～+75℃(Operating Temp:)		
	Operating Force	IF:5～15N MAX. (EF:10. ON MIN.)		
	Heat Rrsistance	IR Reflow:255℃, 5sec. Manual:350℃, 3sec.		

金阻燃) 小型 DC 电源连接器

LTEM NO.:DC-018D-T13 (Series)

(L10.5×W6.5×H4.6 DC-CONNECTORS)

側向操作

 
精密部品 NICETY

可靠 STABILIZE




適合環保 RoHS

No.	NAME	Description
① A	基座	ABS 热塑性塑胶[黑色]
② B	动态端子	H62 黄铜[50u" min 锡基镀金]
③ C	内芯针	H59 黄铜棒[50u" min 锡基镀金]


CIRCUIT DIAGRAM




Unit:mm

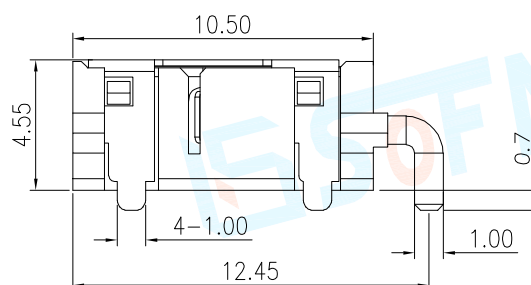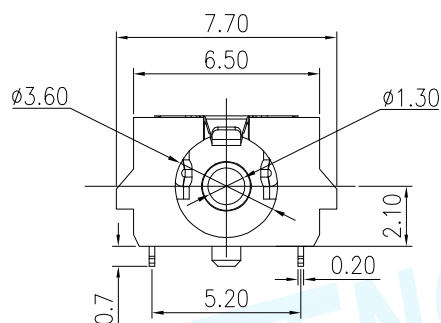 


P.C.B LAYOUT

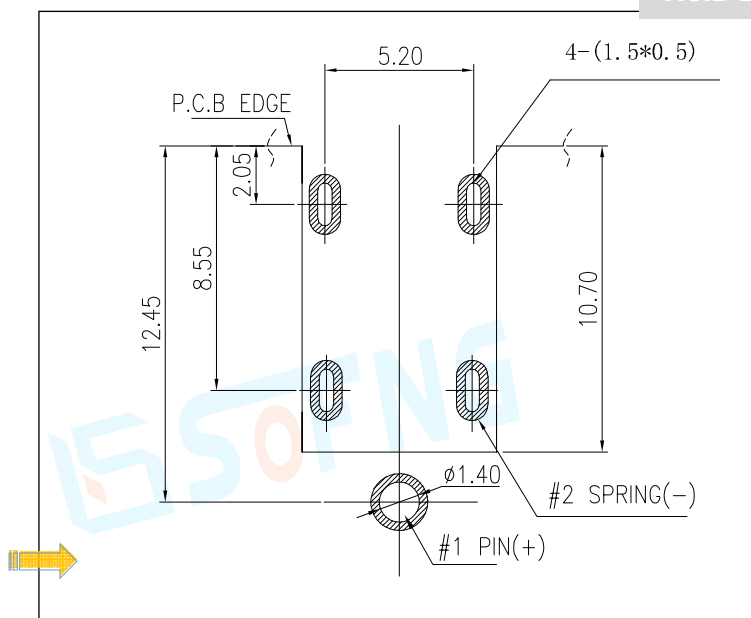

DC JACK INSERT DEPTH

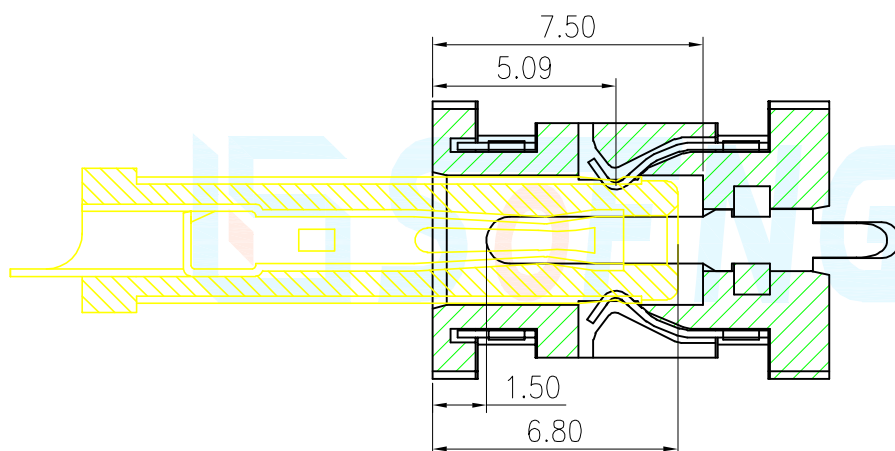

邀您使用(微信)小程序
 硕方电子开关&连接器选型手册
 手机扫码即可进入...

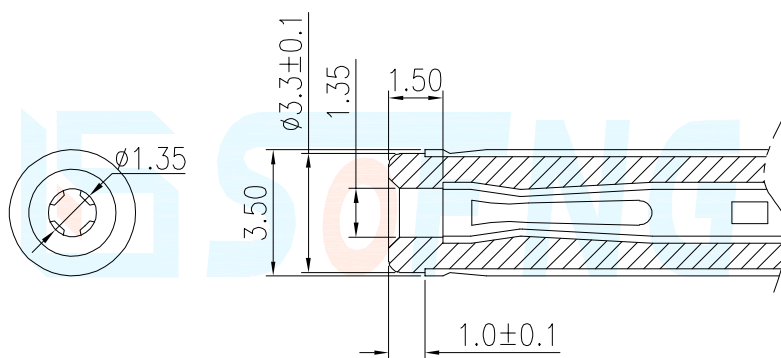

MATE PLUG



本品不屬於危害性廢棄物,須丟棄時可以委託
 回收商予以回收再生處理。
 Products do not belong to •

注記 NOTICE

1. 碩方公司擁有最終解釋權; The company reserves the right of final interpretation;
2. 文件禁止外洩、轉載; Leaked and reproduced prohibited;
3. 未經授權修改無效。Modify is invalid.

運送時本產品不要直接與水、酸鹼性化學物質
 接觸,或放置於含有以上氣體環境中,並且需要
 注意會有滑落、側翻的危險發生; 運輸過程中
 不能有碰撞或者擠壓,須保證溫度與濕度適中
 [常溫 25℃,濕度在 50℃以內],不可導致材料變
 形或氧化。