


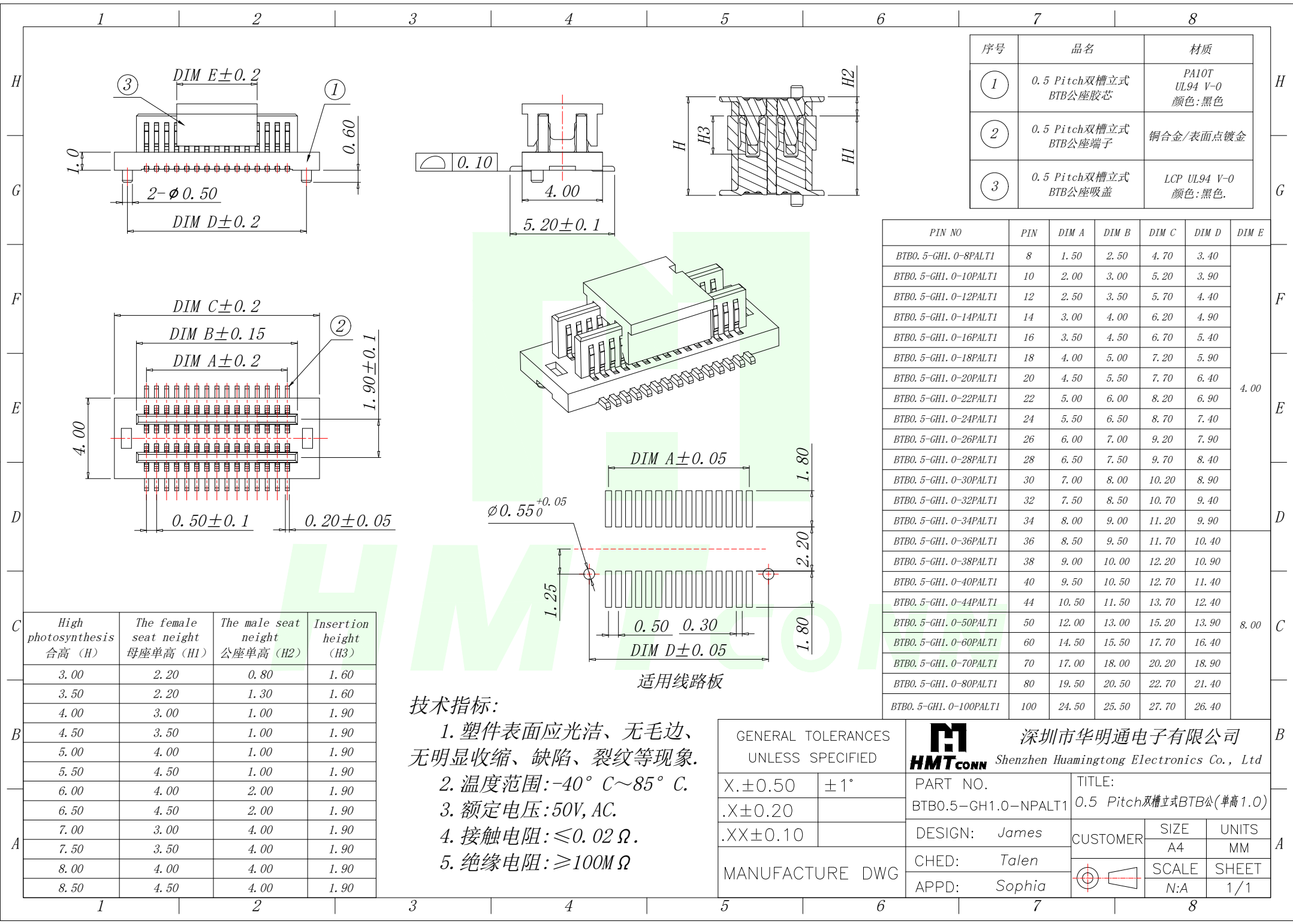

序号	品名	材质
1	0.5 Pitch双槽立式BTB公座胶芯	PA10T UL94 V-0 颜色:黑色
2	0.5 Pitch双槽立式BTB公座端子	铜合金/表面点镀金
3	0.5 Pitch双槽立式BTB公座吸盖	LCP UL94 V-0 颜色:黑色.

PIN NO	PIN	DIM A	DIM B	DIM C	DIM D	DIM E
BTB0.5-GH1.0-8PALT1	8	1.50	2.50	4.70	3.40	4.00
BTB0.5-GH1.0-10PALT1	10	2.00	3.00	5.20	3.90	
BTB0.5-GH1.0-12PALT1	12	2.50	3.50	5.70	4.40	
BTB0.5-GH1.0-14PALT1	14	3.00	4.00	6.20	4.90	
BTB0.5-GH1.0-16PALT1	16	3.50	4.50	6.70	5.40	
BTB0.5-GH1.0-18PALT1	18	4.00	5.00	7.20	5.90	
BTB0.5-GH1.0-20PALT1	20	4.50	5.50	7.70	6.40	
BTB0.5-GH1.0-22PALT1	22	5.00	6.00	8.20	6.90	
BTB0.5-GH1.0-24PALT1	24	5.50	6.50	8.70	7.40	
BTB0.5-GH1.0-26PALT1	26	6.00	7.00	9.20	7.90	
BTB0.5-GH1.0-28PALT1	28	6.50	7.50	9.70	8.40	8.00
BTB0.5-GH1.0-30PALT1	30	7.00	8.00	10.20	8.90	
BTB0.5-GH1.0-32PALT1	32	7.50	8.50	10.70	9.40	
BTB0.5-GH1.0-34PALT1	34	8.00	9.00	11.20	9.90	
BTB0.5-GH1.0-36PALT1	36	8.50	9.50	11.70	10.40	
BTB0.5-GH1.0-38PALT1	38	9.00	10.00	12.20	10.90	
BTB0.5-GH1.0-40PALT1	40	9.50	10.50	12.70	11.40	
BTB0.5-GH1.0-44PALT1	44	10.50	11.50	13.70	12.40	
BTB0.5-GH1.0-50PALT1	50	12.00	13.00	15.20	13.90	
BTB0.5-GH1.0-60PALT1	60	14.50	15.50	17.70	16.40	
BTB0.5-GH1.0-70PALT1	70	17.00	18.00	20.20	18.90	
BTB0.5-GH1.0-80PALT1	80	19.50	20.50	22.70	21.40	
BTB0.5-GH1.0-100PALT1	100	24.50	25.50	27.70	26.40	

技术指标:

1. 塑件表面应光洁、无毛边、无明显收缩、缺陷、裂纹等现象。
2. 温度范围: -40° C ~ 85° C.
3. 额定电压: 50V, AC.
4. 接触电阻: ≤ 0.02 Ω.
5. 绝缘电阻: ≥ 100M Ω

GENERAL TOLERANCES UNLESS SPECIFIED		深圳市华明通电子有限公司 HMTconn Shenzhen Huamingtong Electronics Co., Ltd	
X. ± 0.50	± 1°	PART NO. BTB0.5-GH1.0-NPALT1	TITLE: 0.5 Pitch双槽立式BTB公座(单高1.0)
.X ± 0.20		DESIGN: James	CUSTOMER
.XX ± 0.10		CHED: Talen	SIZE A4
MANUFACTURE DWG		APPD: Sophia	UNITS MM
			SCALE N:A
			SHEET 1/1