


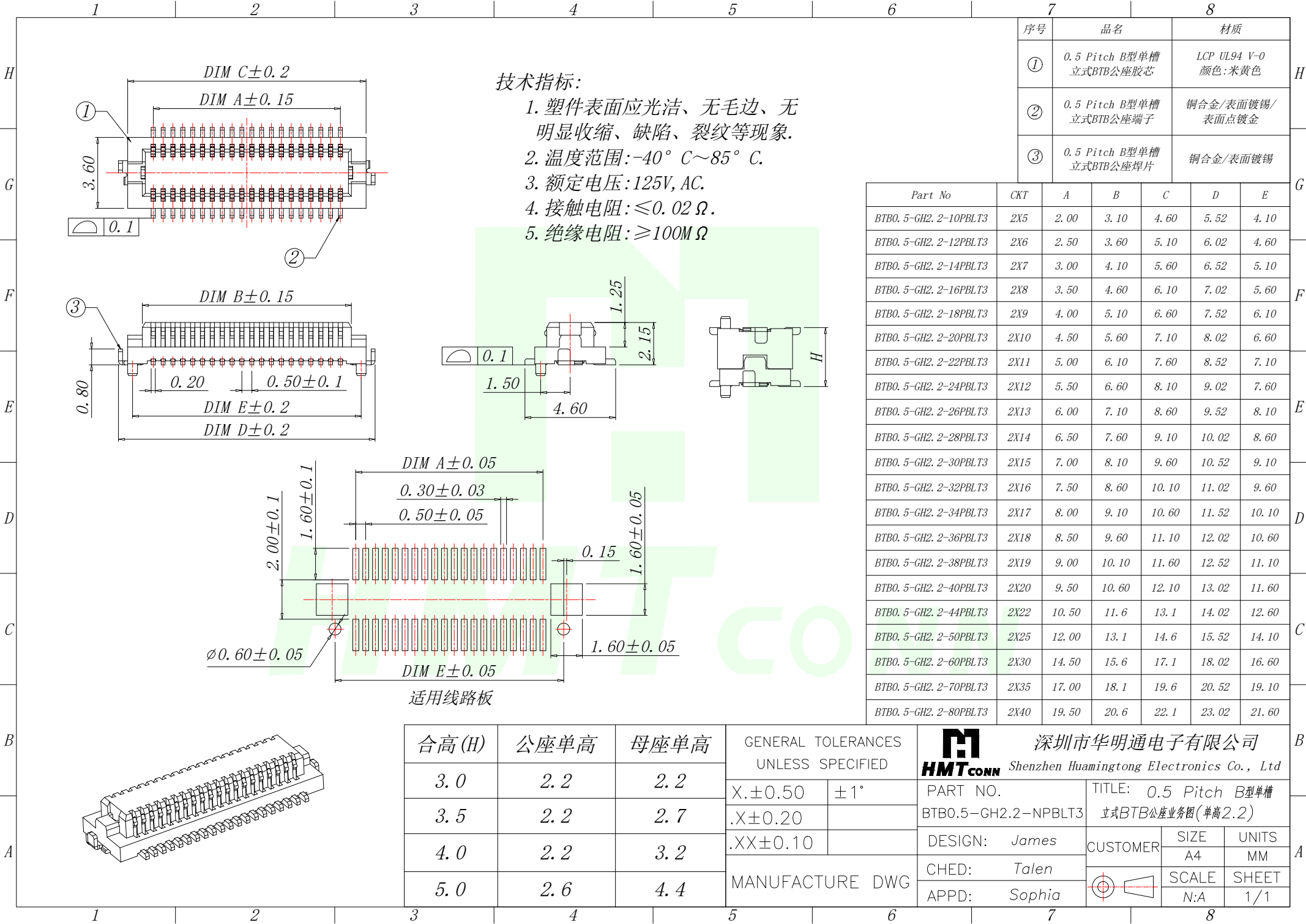

- 技术指标:
- 1. 塑件表面应光洁、无毛边、无明显收缩、缺陷、裂纹等现象.
 - 2. 温度范围: $-40^{\circ}\text{C}\sim 85^{\circ}\text{C}$.
 - 3. 额定电压: 125V, AC.
 - 4. 接触电阻: $\leq 0.02\ \Omega$.
 - 5. 绝缘电阻: $\geq 100\text{M}\ \Omega$

序号	品名	材质
①	0.5 Pitch B型单槽立式BTB公座胶芯	LCP UL94 V-0 颜色:米黄色
②	0.5 Pitch B型单槽立式BTB公座端子	铜合金/表面镀锡/ 表面点镀金
③	0.5 Pitch B型单槽立式BTB公座焊片	铜合金/表面镀锡

Part No	CKT	A	B	C	D	E
BTB0. 5-GH2. 2-10PBLT3	2X5	2.00	3.10	4.60	5.52	4.10
BTB0. 5-GH2. 2-12PBLT3	2X6	2.50	3.60	5.10	6.02	4.60
BTB0. 5-GH2. 2-14PBLT3	2X7	3.00	4.10	5.60	6.52	5.10
BTB0. 5-GH2. 2-16PBLT3	2X8	3.50	4.60	6.10	7.02	5.60
BTB0. 5-GH2. 2-18PBLT3	2X9	4.00	5.10	6.60	7.52	6.10
BTB0. 5-GH2. 2-20PBLT3	2X10	4.50	5.60	7.10	8.02	6.60
BTB0. 5-GH2. 2-22PBLT3	2X11	5.00	6.10	7.60	8.52	7.10
BTB0. 5-GH2. 2-24PBLT3	2X12	5.50	6.60	8.10	9.02	7.60
BTB0. 5-GH2. 2-26PBLT3	2X13	6.00	7.10	8.60	9.52	8.10
BTB0. 5-GH2. 2-28PBLT3	2X14	6.50	7.60	9.10	10.02	8.60
BTB0. 5-GH2. 2-30PBLT3	2X15	7.00	8.10	9.60	10.52	9.10
BTB0. 5-GH2. 2-32PBLT3	2X16	7.50	8.60	10.10	11.02	9.60
BTB0. 5-GH2. 2-34PBLT3	2X17	8.00	9.10	10.60	11.52	10.10
BTB0. 5-GH2. 2-36PBLT3	2X18	8.50	9.60	11.10	12.02	10.60
BTB0. 5-GH2. 2-38PBLT3	2X19	9.00	10.10	11.60	12.52	11.10
BTB0. 5-GH2. 2-40PBLT3	2X20	9.50	10.60	12.10	13.02	11.60
BTB0. 5-GH2. 2-44PBLT3	2X22	10.50	11.6	13.1	14.02	12.60
BTB0. 5-GH2. 2-50PBLT3	2X25	12.00	13.1	14.6	15.52	14.10
BTB0. 5-GH2. 2-60PBLT3	2X30	14.50	15.6	17.1	18.02	16.60
BTB0. 5-GH2. 2-70PBLT3	2X35	17.00	18.1	19.6	20.52	19.10
BTB0. 5-GH2. 2-80PBLT3	2X40	19.50	20.6	22.1	23.02	21.60

合高(H)	公座单高	母座单高
3.0	2.2	2.2
3.5	2.2	2.7
4.0	2.2	3.2
5.0	2.6	4.4

GENERAL TOLERANCES
UNLESS SPECIFIED

X.±0.50

±1°

.X±0.20

.XX±0.10

MANUFACTURE DWG

**HMT**conn

深圳市华明通电子有限公司
Shenzhen Huamingtong Electronics Co., Ltd

PART NO.
BTB0.5-GH2.2-NPBLT3

DESIGN: James

CHED: Talen

APPD: Sophia

TITLE: 0.5 Pitch B型单槽
立式BTB公座业务图(单高2.2)

CUSTOMER

SIZE
A4

UNITS
MM

SCALE
N:A

SHEET
1/1

