


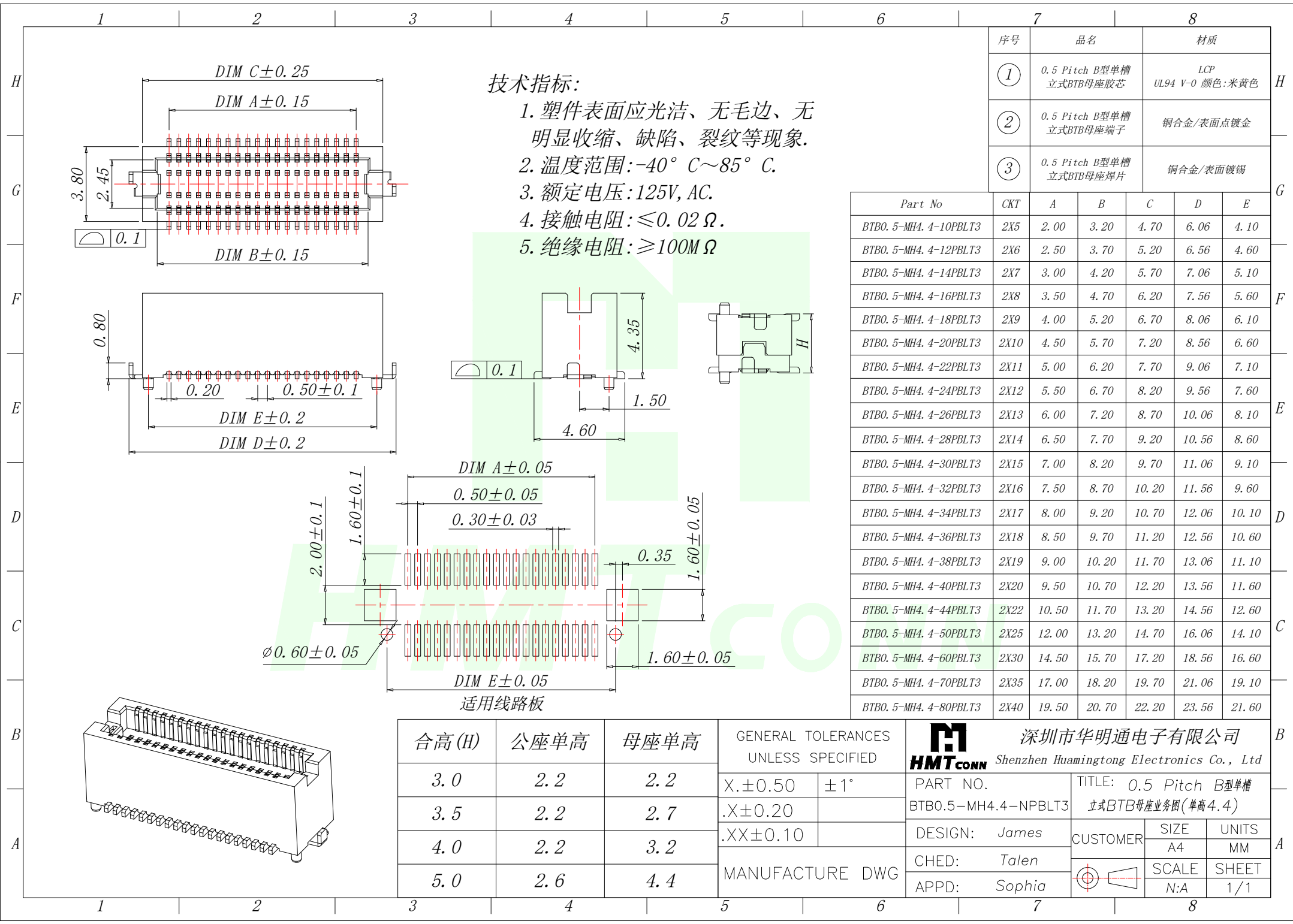

技术指标:

- 1. 塑件表面应光洁、无毛边、无明显收缩、缺陷、裂纹等现象.
- 2. 温度范围: $-40^{\circ}\text{C} \sim 85^{\circ}\text{C}$.
- 3. 额定电压: 125V, AC.
- 4. 接触电阻: $\leq 0.02\ \Omega$.
- 5. 绝缘电阻: $\geq 100\text{M}\ \Omega$

序号	品名	材质
①	0.5 Pitch B型单槽立式BTB母座胶芯	LCP UL94 V-0 颜色:米黄色
②	0.5 Pitch B型单槽立式BTB母座端子	铜合金/表面点镀金
③	0.5 Pitch B型单槽立式BTB母座焊片	铜合金/表面镀锡

Part No	CKT	A	B	C	D	E
BTB0. 5-MH4. 4-10PBLT3	2X5	2.00	3.20	4.70	6.06	4.10
BTB0. 5-MH4. 4-12PBLT3	2X6	2.50	3.70	5.20	6.56	4.60
BTB0. 5-MH4. 4-14PBLT3	2X7	3.00	4.20	5.70	7.06	5.10
BTB0. 5-MH4. 4-16PBLT3	2X8	3.50	4.70	6.20	7.56	5.60
BTB0. 5-MH4. 4-18PBLT3	2X9	4.00	5.20	6.70	8.06	6.10
BTB0. 5-MH4. 4-20PBLT3	2X10	4.50	5.70	7.20	8.56	6.60
BTB0. 5-MH4. 4-22PBLT3	2X11	5.00	6.20	7.70	9.06	7.10
BTB0. 5-MH4. 4-24PBLT3	2X12	5.50	6.70	8.20	9.56	7.60
BTB0. 5-MH4. 4-26PBLT3	2X13	6.00	7.20	8.70	10.06	8.10
BTB0. 5-MH4. 4-28PBLT3	2X14	6.50	7.70	9.20	10.56	8.60
BTB0. 5-MH4. 4-30PBLT3	2X15	7.00	8.20	9.70	11.06	9.10
BTB0. 5-MH4. 4-32PBLT3	2X16	7.50	8.70	10.20	11.56	9.60
BTB0. 5-MH4. 4-34PBLT3	2X17	8.00	9.20	10.70	12.06	10.10
BTB0. 5-MH4. 4-36PBLT3	2X18	8.50	9.70	11.20	12.56	10.60
BTB0. 5-MH4. 4-38PBLT3	2X19	9.00	10.20	11.70	13.06	11.10
BTB0. 5-MH4. 4-40PBLT3	2X20	9.50	10.70	12.20	13.56	11.60
BTB0. 5-MH4. 4-44PBLT3	2X22	10.50	11.70	13.20	14.56	12.60
BTB0. 5-MH4. 4-50PBLT3	2X25	12.00	13.20	14.70	16.06	14.10
BTB0. 5-MH4. 4-60PBLT3	2X30	14.50	15.70	17.20	18.56	16.60
BTB0. 5-MH4. 4-70PBLT3	2X35	17.00	18.20	19.70	21.06	19.10
BTB0. 5-MH4. 4-80PBLT3	2X40	19.50	20.70	22.20	23.56	21.60

合高(H)	公座单高	母座单高
3.0	2.2	2.2
3.5	2.2	2.7
4.0	2.2	3.2
5.0	2.6	4.4

GENERAL TOLERANCES
UNLESS SPECIFIED

X.±0.50

±1°

.X±0.20

.XX±0.10

MANUFACTURE DWG

**HMTCONN**

深圳市华明通电子有限公司
Shenzhen Huamingtong Electronics Co., Ltd

PART NO.
BTB0.5-MH4.4-NPBLT3

DESIGN: James

CHED: Talen

APPD: Sophia

TITLE: 0.5 Pitch B型单槽
立式BTB母座业务图(单高4.4)

CUSTOMER

SIZE
A4

UNITS
MM

SCALE
N:A

SHEET
1/1

适用线路板