


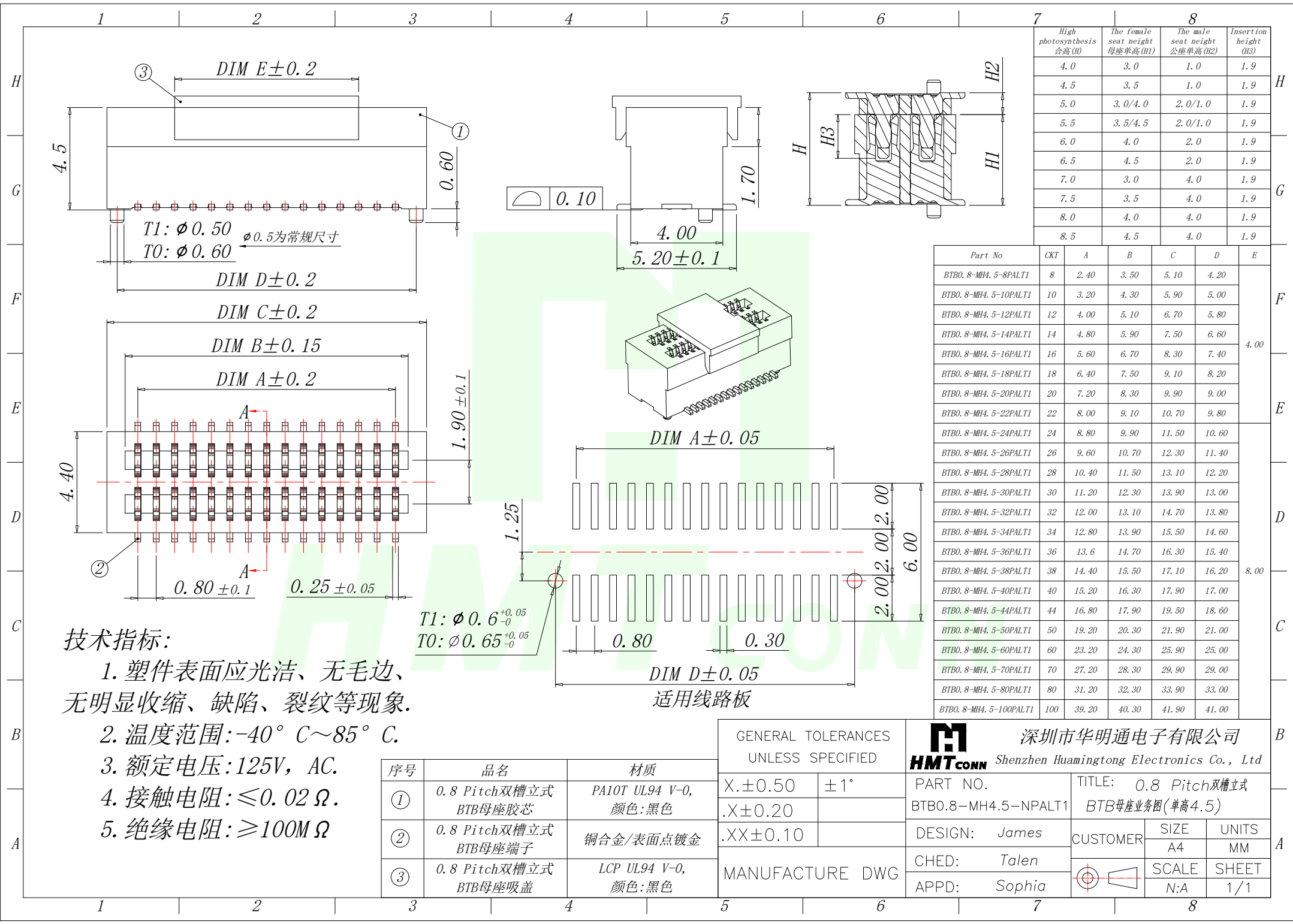

High photosynthesis 合高(H)	The female seat height 母座单高(H1)	The male seat height 公座单高(H2)	Insertion height (H3)
4.0	3.0	1.0	1.9
4.5	3.5	1.0	1.9
5.0	3.0/4.0	2.0/1.0	1.9
5.5	3.5/4.5	2.0/1.0	1.9
6.0	4.0	2.0	1.9
6.5	4.5	2.0	1.9
7.0	3.0	4.0	1.9
7.5	3.5	4.0	1.9
8.0	4.0	4.0	1.9
8.5	4.5	4.0	1.9

Part No	CKT	A	B	C	D	E
BTB0.8-MH4.5-8PALT1	8	2.40	3.50	5.10	4.20	4.00
BTB0.8-MH4.5-10PALT1	10	3.20	4.30	5.90	5.00	
BTB0.8-MH4.5-12PALT1	12	4.00	5.10	6.70	5.80	
BTB0.8-MH4.5-14PALT1	14	4.80	5.90	7.50	6.60	
BTB0.8-MH4.5-16PALT1	16	5.60	6.70	8.30	7.40	
BTB0.8-MH4.5-18PALT1	18	6.40	7.50	9.10	8.20	
BTB0.8-MH4.5-20PALT1	20	7.20	8.30	9.90	9.00	
BTB0.8-MH4.5-22PALT1	22	8.00	9.10	10.70	9.80	
BTB0.8-MH4.5-24PALT1	24	8.80	9.90	11.50	10.60	8.00
BTB0.8-MH4.5-26PALT1	26	9.60	10.70	12.30	11.40	
BTB0.8-MH4.5-28PALT1	28	10.40	11.50	13.10	12.20	
BTB0.8-MH4.5-30PALT1	30	11.20	12.30	13.90	13.00	
BTB0.8-MH4.5-32PALT1	32	12.00	13.10	14.70	13.80	
BTB0.8-MH4.5-34PALT1	34	12.80	13.90	15.50	14.60	
BTB0.8-MH4.5-36PALT1	36	13.6	14.70	16.30	15.40	
BTB0.8-MH4.5-38PALT1	38	14.40	15.50	17.10	16.20	
BTB0.8-MH4.5-40PALT1	40	15.20	16.30	17.90	17.00	21.00
BTB0.8-MH4.5-44PALT1	44	16.80	17.90	19.50	18.60	
BTB0.8-MH4.5-50PALT1	50	19.20	20.30	21.90	21.00	
BTB0.8-MH4.5-60PALT1	60	23.20	24.30	25.90	25.00	
BTB0.8-MH4.5-70PALT1	70	27.20	28.30	29.90	29.00	
BTB0.8-MH4.5-80PALT1	80	31.20	32.30	33.90	33.00	
BTB0.8-MH4.5-100PALT1	100	39.20	40.30	41.90	41.00	

- 技术指标:
- 塑件表面应光洁、无毛边、无明显收缩、缺陷、裂纹等现象。
 - 温度范围: -40° C ~ 85° C.
 - 额定电压: 125V, AC.
 - 接触电阻: $\leq 0.02 \Omega$.
 - 绝缘电阻: $\geq 100M \Omega$

序号	品名	材质
①	0.8 Pitch双槽立式BTB母座胶芯	PA10T UL94 V-0, 颜色: 黑色
②	0.8 Pitch双槽立式BTB母座端子	铜合金/表面点镀金
③	0.8 Pitch双槽立式BTB母座吸盖	LCP UL94 V-0, 颜色: 黑色

GENERAL TOLERANCES
UNLESS SPECIFIED

X. ± 0.50	± 1°
.X ± 0.20	
.XX ± 0.10	

MANUFACTURE DWG

深圳市华明通电子有限公司
HMTconn Shenzhen Huamingtong Electronics Co., Ltd

PART NO.
BTB0.8-MH4.5-NPALT1

DESIGN: James

CHED: Talen

APPD: Sophia

TITLE: 0.8 Pitch双槽立式BTB母座业务图(单高4.5)

CUSTOMER	SIZE	UNITS
	A4	MM
SCALE	SHEET	
N:A	1/1	